


Pressure Relief



Pressure Reducing Valves

X(C)G-(H)03-**-30

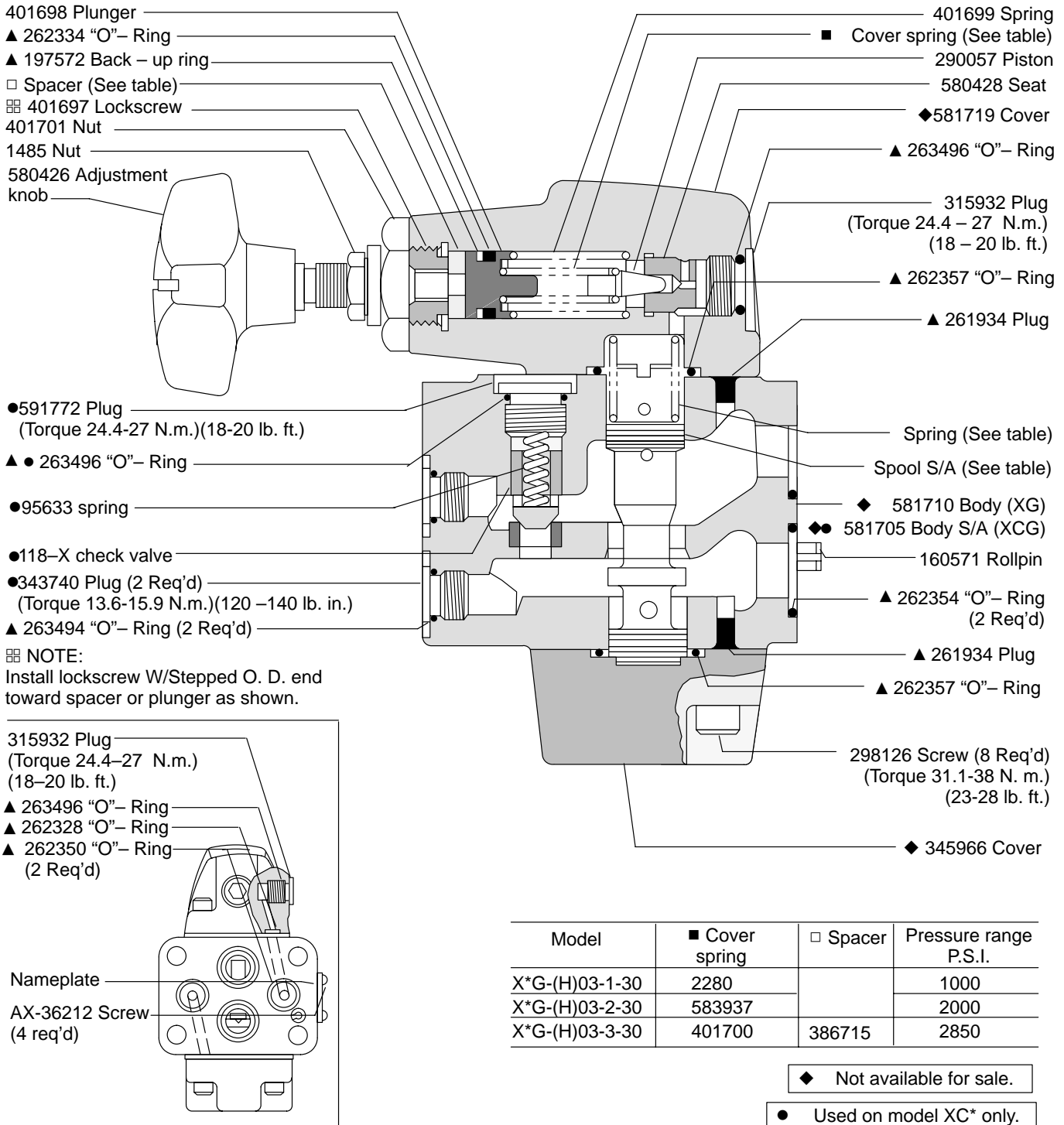

Model	■ Cover spring	□ Spacer	Pressure range P.S.I.
X*G-(H)03-1-30	2280		1000
X*G-(H)03-2-30	583937		2000
X*G-(H)03-3-30	401700	386715	2850

 
◆ Not available for sale.

● Used on model XC* only.

▲ Service all units with F3 seal kit 919836.

Model Code

(F3) - X (C) G - (H) 03 - * * - 30



1 Seals

F3 - Seals for mineral oil and fire resistant fluids

2 Pressure Reducing Valve

3 Integral Check Valve

Omitted – no check valve

4 Manifold or Subplate Mounted

5 Rated Flow @ 30 USgpm

Omit for “B” & “F” models

6 Nominal valve size $\frac{3}{4}$ inch

03 - $\frac{3}{8}$ inch

7 Maximum adjustable pressure

1 – 1000 PSI
2 – 2000 PSI
3 – 2850 PSI

8 Maximum rated flow capacity

B -7 USgpm
F -14 USgpm

9 Design

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 18/15 or cleaner. Selections from Eaton OFP, OFR and OFRS filter series are recommended.