

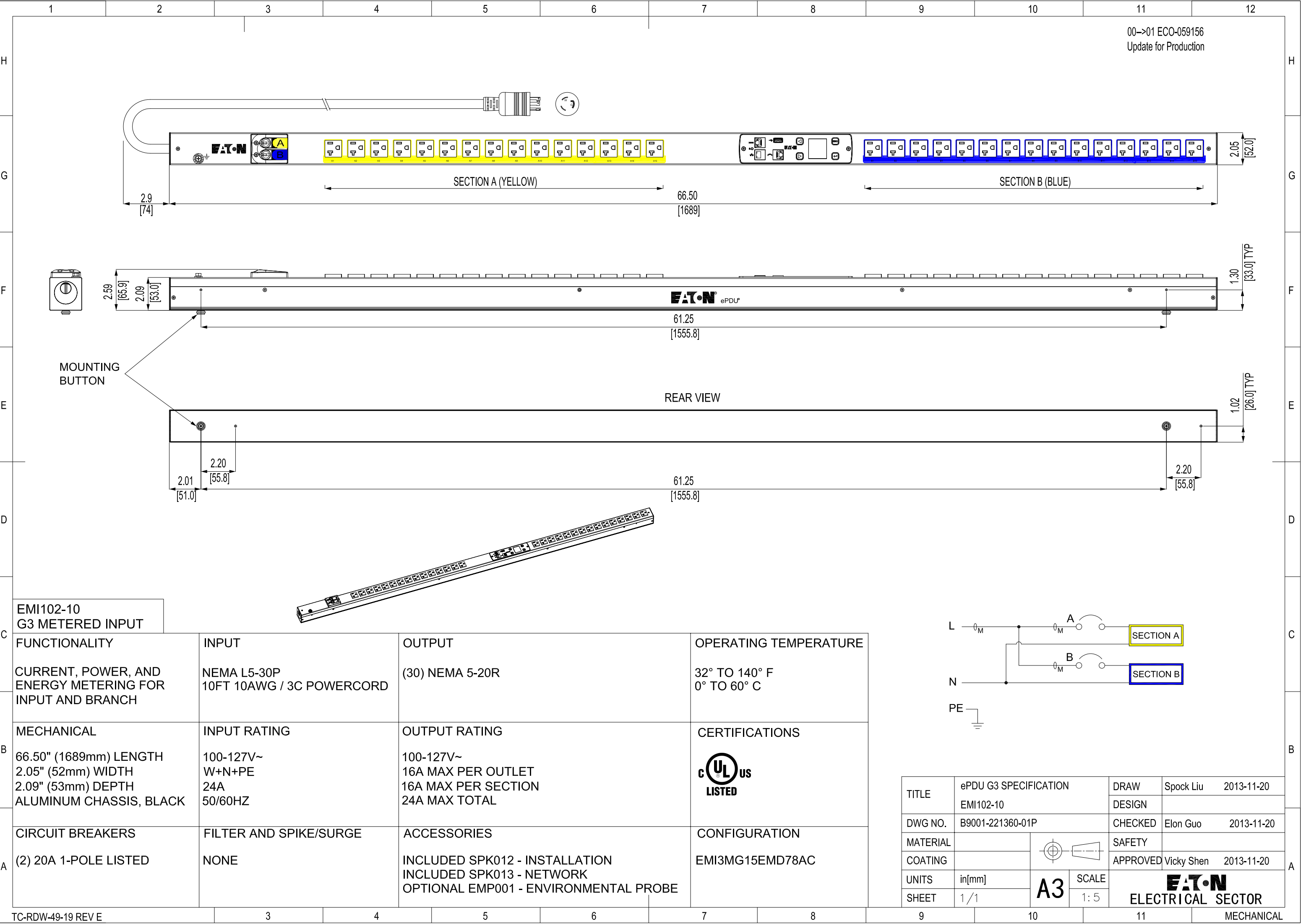


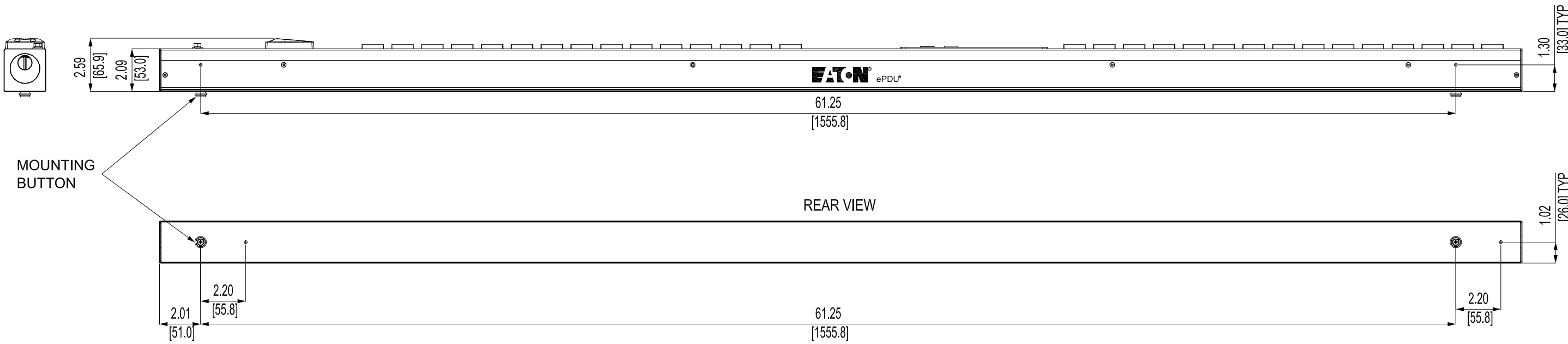


00-->01 ECO-059156
Update for Production

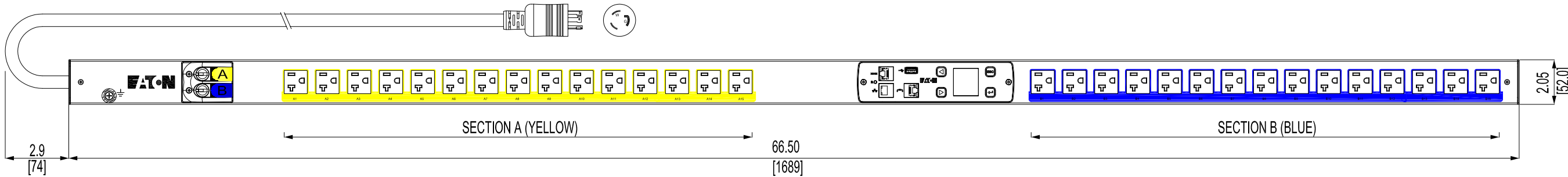

EMI102-10
G3 METERED INPUT

FUNCTIONALITY	INPUT	OUTPUT	OPERATING TEMPERATURE
CURRENT, POWER, AND ENERGY METERING FOR INPUT AND BRANCH	NEMA L5-30P 10FT 10AWG / 3C POWERCORD	(30) NEMA 5-20R	32° TO 140° F 0° TO 60° C
MECHANICAL	INPUT RATING	OUTPUT RATING	CERTIFICATIONS
66.50" (1689mm) LENGTH 2.05" (52mm) WIDTH 2.09" (53mm) DEPTH ALUMINUM CHASSIS, BLACK	100-127V~ W+N+PE 24A 50/60HZ	100-127V~ 16A MAX PER OUTLET 16A MAX PER SECTION 24A MAX TOTAL	
CIRCUIT BREAKERS	FILTER AND SPIKE/SURGE	ACCESSORIES	CONFIGURATION
(2) 20A 1-POLE LISTED	NONE	INCLUDED SPK012 - INSTALLATION INCLUDED SPK013 - NETWORK OPTIONAL EMP001 - ENVIRONMENTAL PROBE	EMI3MG15EMD78AC

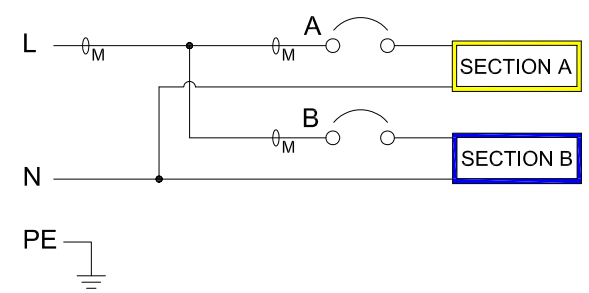

TITLE	ePDU G3 SPECIFICATION EMI102-10	DRAW	Spock Liu	2013-11-20
DWG NO.	B9001-221360-01P	CHECKED	Elon Guo	2013-11-20
MATERIAL		SAFETY		
COATING		APPROVED	Vicky Shen	2013-11-20
UNITS	in[mm]	SCALE		
SHEET	1/1	SCALE		

**ELECTRICAL SECTOR**