

Rack PDU plugs and receptacles

 
 


 









This cheat sheet provides an overview of the different styles of plugs and receptacles for Eaton rackmount PDUs.

5-15R 	5-15P 	5-20R 	5-20P
L5-20R 	L5-20P 	L5-30R 	L5-30P
6-15R 	6-15P 	L6-20R 	L6-20P
L6-30R 	L6-30P 	L14-30R 	L14-30P
16A 	32A 	<p>R indicates receptacle P indicates plug L indicates locking plug or receptacle</p>	

General PDU environment specifications

- Operating temperature is 0 to 50°C (32 to 122°F)
- Storage temperature is -40 to 70°C (-40 to 158°F)
- Altitude maximum 10,000 ft.
- Relative humidity is 95% max non-condensing


Standard NEMA plugs

 5-15 120V 15A 1 phase straight blade	 6-20 208V 20A 1 phase straight blade	 L21-20 120/208V 20A, 3 phase wye twist lock	 L22-20 277/480V 20A 3 phase wye twist lock
 5-20 120V 20A 1 phase straight blade	 L6-20 208V 20A 1 phase twist lock	 L21-30 120/208V 30A 3 phase wye twist lock	 L22-30 277/480V 30A 3 phase wye twist lock
 L5-20 120V 20A 1 phase twist lock	 L6-30 208V 30A, 1 phase twist lock	 L15-20 208V 20A 3 phase delta twist lock	
 L5-30 120V 30A 1 phase twist lock	 L14-30 120/240V 30A 2 phase (split phase)	 L15-30 208V 30A 3 phase delta twist lock	



The IEC advantage:

The IEC320 and IEC309 connectors described below are the most commonly specified. The IEC connector system is used throughout the world. By utilizing an Eaton PDU with the IEC connectors, you can attach the correct cable assembly for British, Australian, Continental European, North American and many other cable/connector configurations. This allows you to purchase and inventory one PDU for shipment anywhere in the world.

IEC320

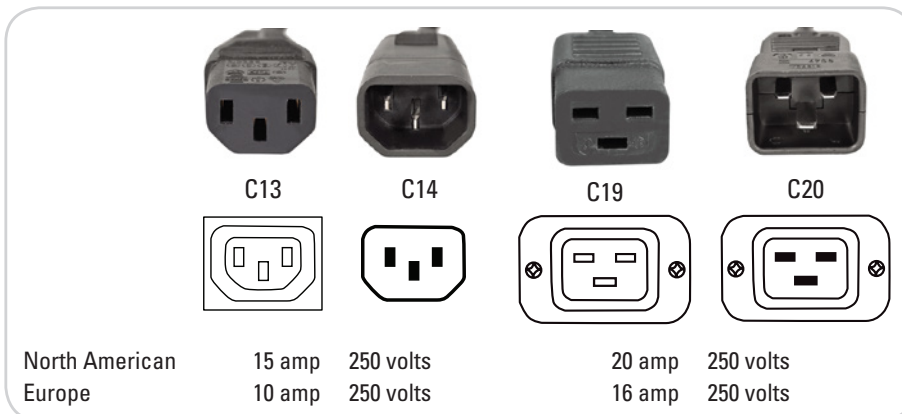

IEC309

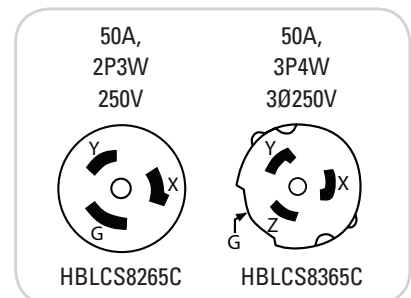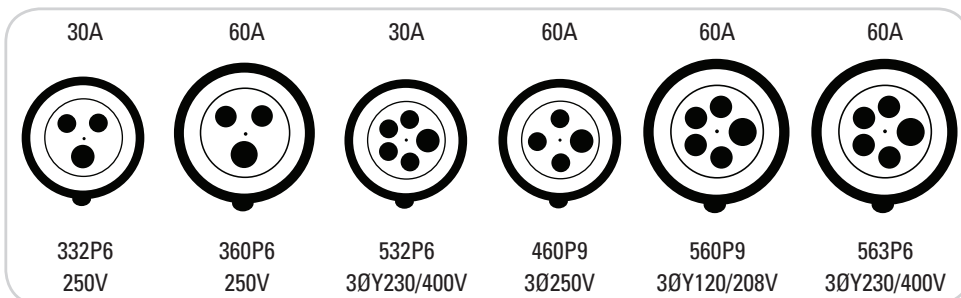

Eaton
 1000 Eaton Boulevard
 Cleveland, OH 44122
 United States
 Eaton.com

Powerquality.eaton.com

©2018 Eaton
 All Rights Reserved
 Printed in USA
 PDU37FXA / GG
 March 2018