


Commercial solutions

CROUSE-HINDS  
SERIES

# Quick-Lok

Outlet boxes and assemblies

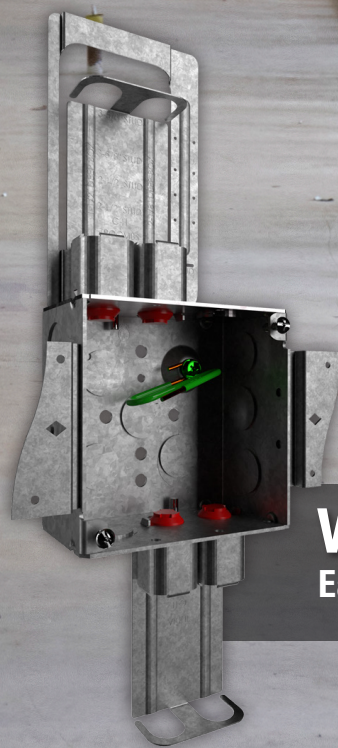


**WORK FASTER. SMARTER.**  
Easy install assemblies for every application

**EAT•N**

*Powering Business Worldwide*



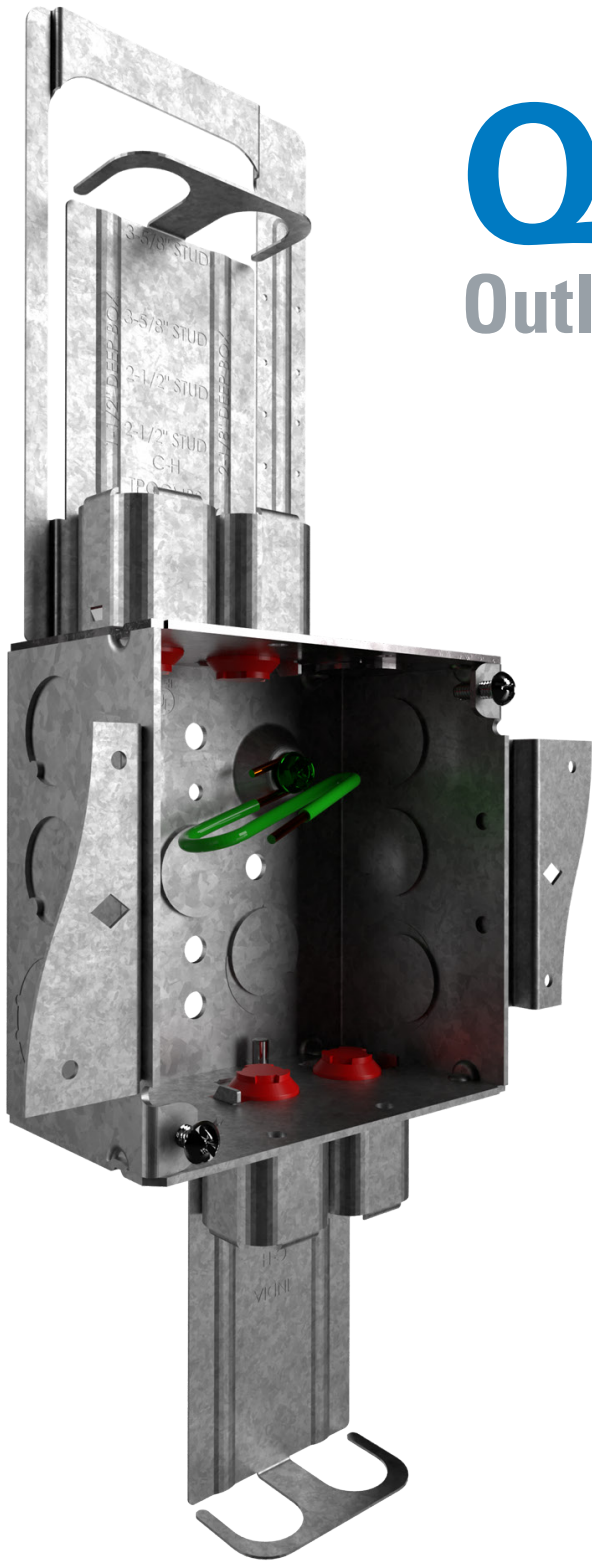

# Quick-Lok

## Outlet boxes & assemblies

### Lock up

more productivity on every in-wall rough in.

### Spend less time


managing and assembling pieces.

### Fast & accurate

installation and mounting for every application.



# Features

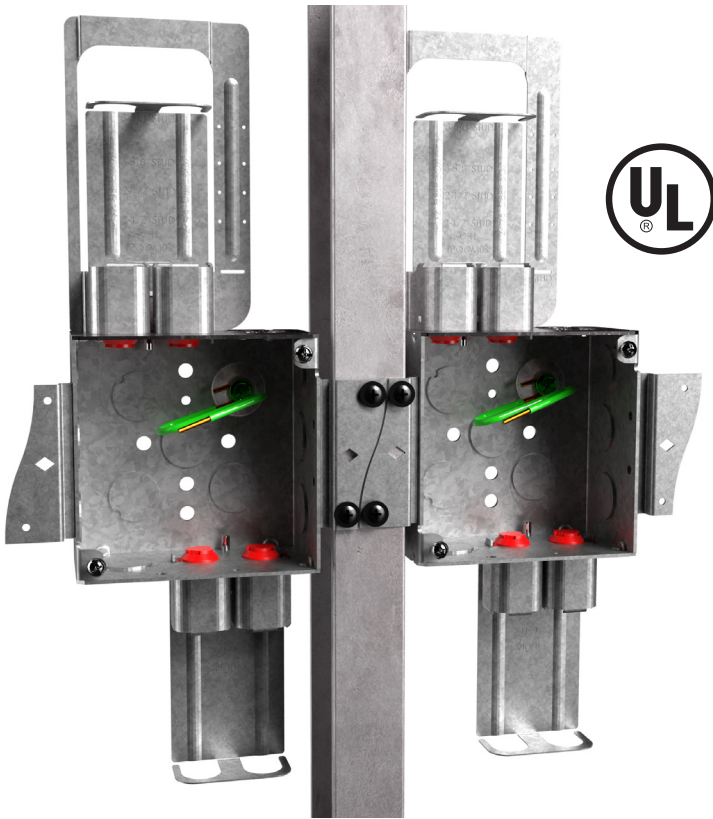


### Easy to mount

- Patented S-curved shaped allows 2 brackets interlocked and mounted side by side on same stud
- Available with single or double sided options
- Assemblies without flat face bracket can be installed in conjunction with B-Line series stud mounting brackets


## Patented pre-installed external connectors

- 4" square:  
(2) top only cable entries or (2) top & (2) bottom cable entry options
- 4-11/16" square:  
(2-4) top only cable entries or (2-4) top & (2-4) bottom cable entry options
- Extra 1/2" and 3/4" eccentric knockouts available on select models
- Integral insulator and easily removable knockout plug

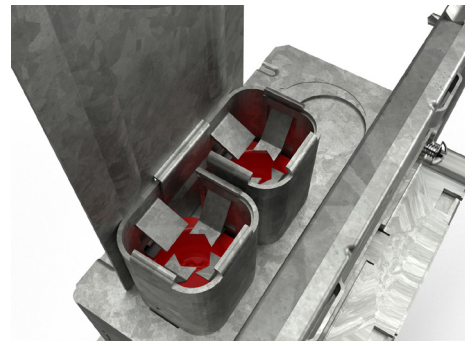


## Cable management & support

- Patented field installable cable management & backside support accessories

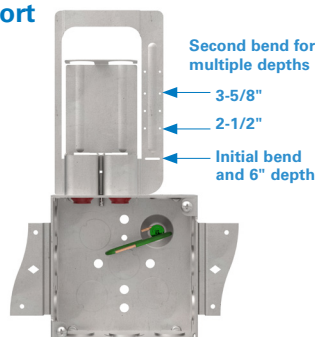

# The ultimate pre-fab solution

## Quick-Lok box & telescoping open bracket

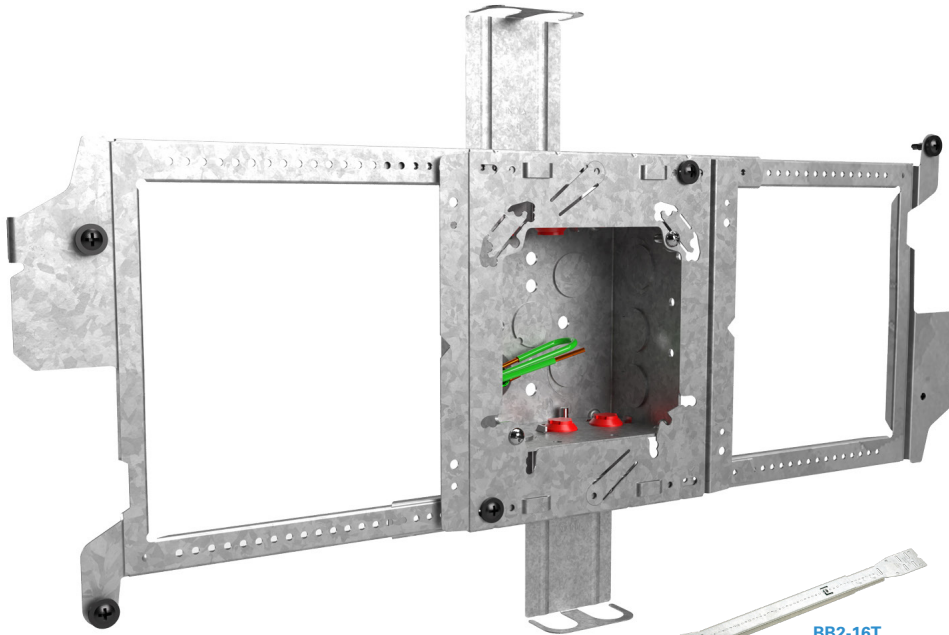


### Versatility

- Quick-Lok outlet boxes are optimized for BBT-HF telescoping bracket and work with all B-Line series bracket options




### Telescoping bracket

- The Quick-lok box mounted to a BBT-HF bracket using the BBA mounting plate provides an incredibly flexible, labor saving rough-in platform
- BBT-HF telescoping open bracket adjusts to accommodate stud widths from 14.5" to 25". Continuous hole pattern allows for fixing the BBA anywhere along the length of the bracket. Ideal for specific dimension locations and "back to back" installations.
- Telescoping bracket snaps to the stud, freeing a hand to ease installation. The bracket can be installed in adjacent stud cavities, and interlocking nature helps ensure identical mounting height.
- The BBA mounting plate can be used to mount the Quick-Lok box directly to a stud. Backside support can be added to the Quick-lok box using the TPQCMBS accessory for wall depths up to 6" deep. Perfect for installation where exact dimensions are not required.

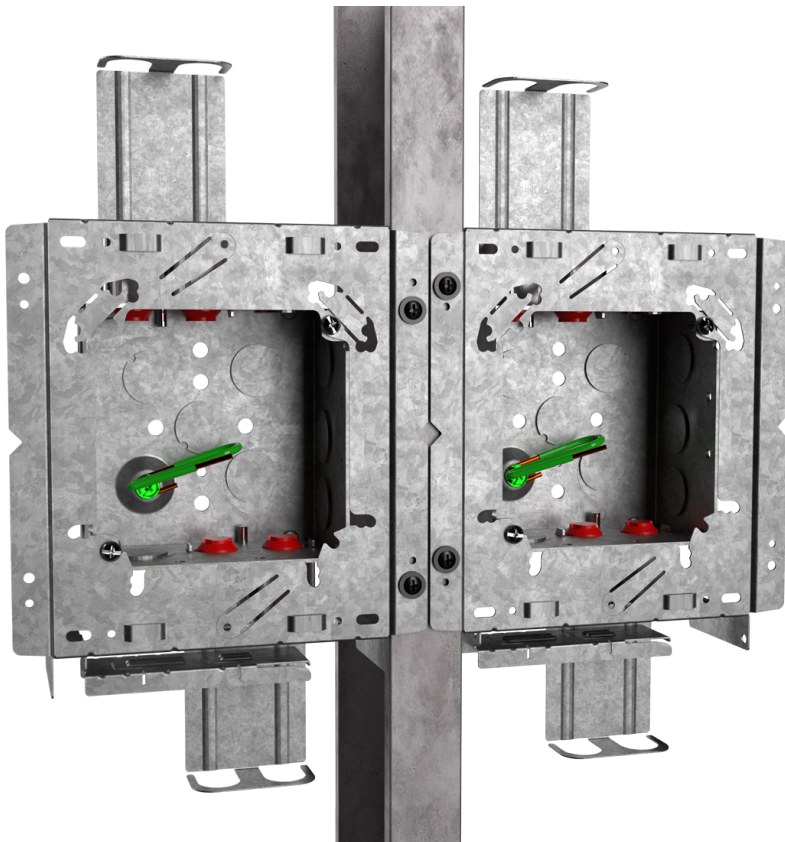


### Stud mount option

- Easily mount 4" or 4-11/16" boxes without S-curve brackets directly to studs using BBA-4 box mounts

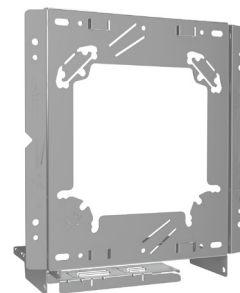


BBA-4

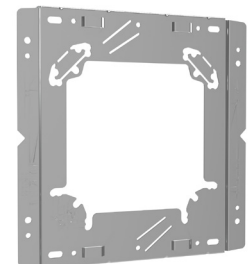

BBA




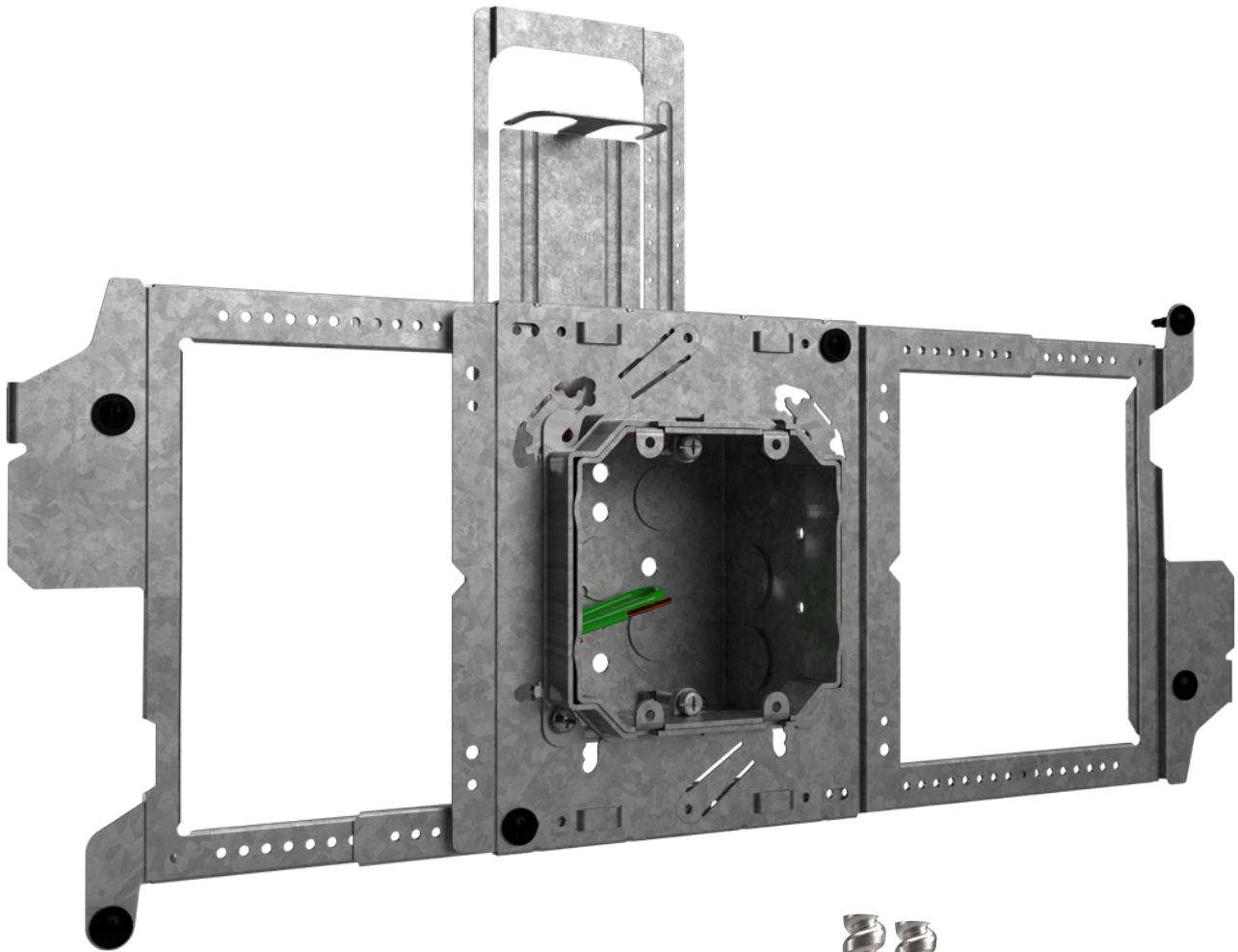


Add custom length  
MC cable whips to  
any assembly for  
faster installations

### ETO compete solutions


- Easily adjusts to stud widths of 14.5" thru 25"
- Simply take bracket off the adapter plate and box for stud mounting
- Backside support can be added in as accessory for stud mounting, BBA-4 is rigid enough with between stud mounting
- Easy to identify center line on both sides of the bracket
- Designed to mount boxes at the exact height on either side of the stud without overlap of adjacent brackets
- Continuous hole pattern allows for positioning of the box mounting bracket anywhere along the length of the bracket

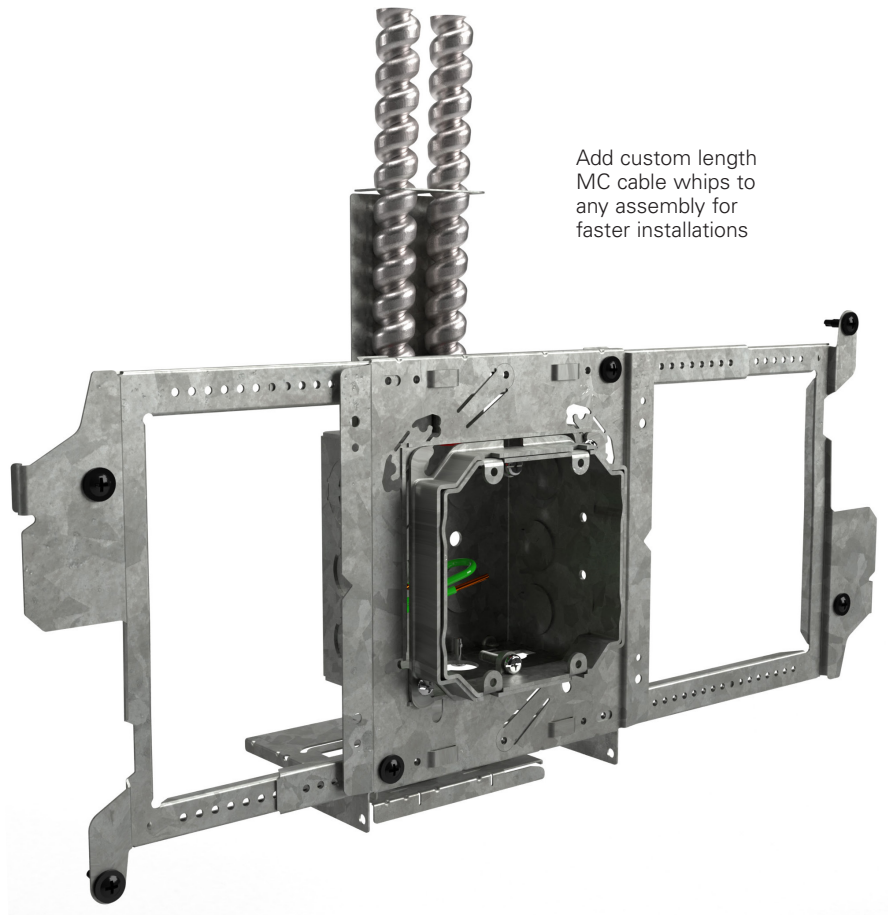


# Simple installation

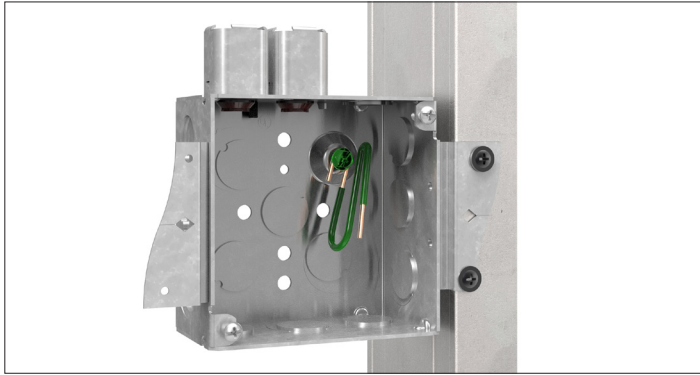


**Step 1.** Mount box to stud.

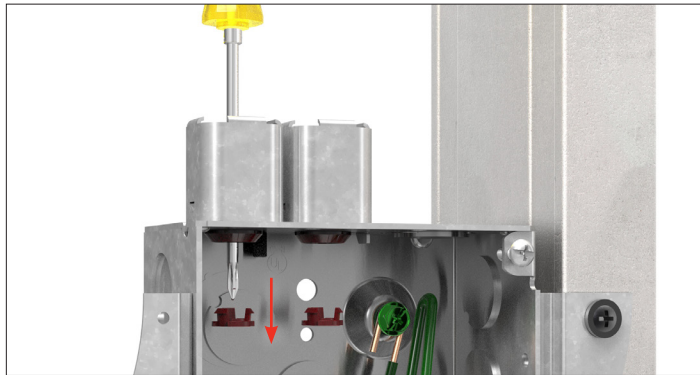


**Step 2.** Pop out the plug by inserting a screwdriver through the top of the Quick-Lok connector in the location where cable will be installed. If you accidentally pop out too many plugs, you can reinstall.

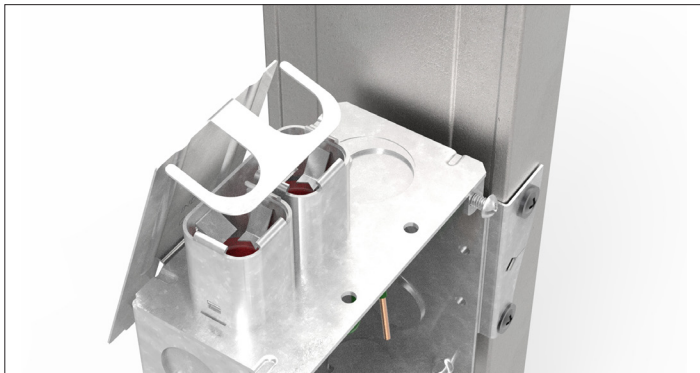

**Step 3.** Align the cable openings on the cable management with the top of the Quick-Lok connector.

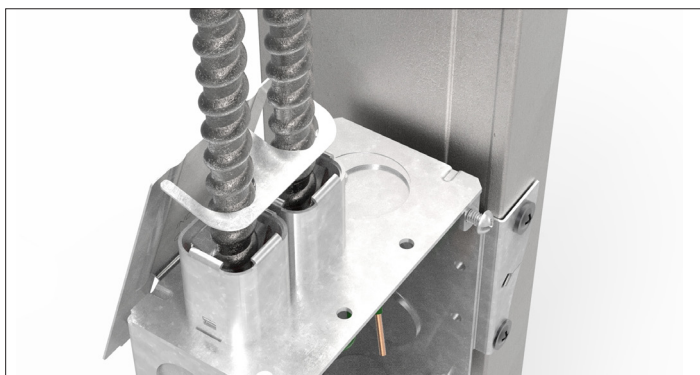


**Step 4.** Insert cable through the cable management and quick-lok connector simultaneously.

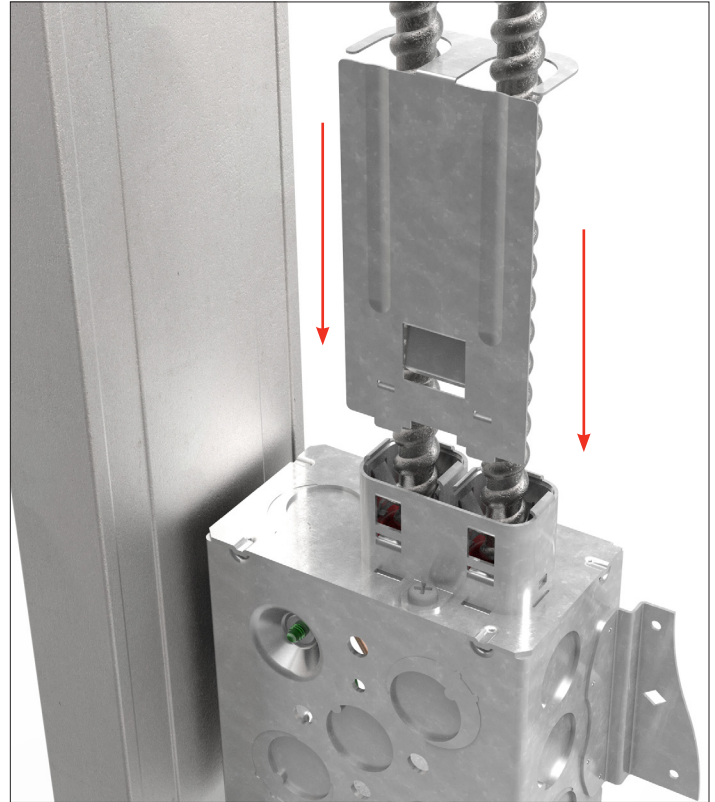

**Step 5.** Slide cable management up and snap into the box and quick-lok connector after all cables are installed.

## Note:

For type MC-I cable (Southwire MCAP, Encore Smartground, or similar), the bare aluminum ground should be wrapped against the outside jacket and protrude from the top of the Quick-Lok connector 1/8". Any excess will be cut off.

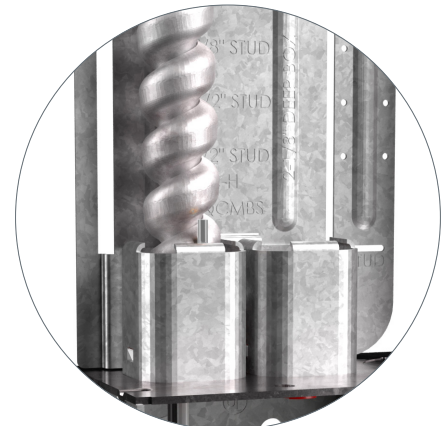



# Ordering information

Part number example

**TP4Q10CBMPF**

Quick-Lok 4" box . (1) top connector, backside support with cable management, double sided bracket, 8" insulated 12 AWG solid ground wire

**TP4Q**

**Box style: 2-1/8" deep**

|             |                 |
|-------------|-----------------|
| <b>TP4Q</b> | 4" square       |
| <b>TP5Q</b> | 4-11/16" square |

**10**

**Quantity & position of cable entries**

|            |                     |
|------------|---------------------|
| <b>10</b>  | (2) top             |
| <b>11</b>  | (2) top, (2) bottom |
| <b>20*</b> | (4) top             |
| <b>21*</b> | (4) top, (2) bottom |
| <b>22*</b> | (4) top, (4) bottom |

\*Available with 4-11/16" only.

**CB**

**Cable management & backside support**

|              |                                                                                                                  |
|--------------|------------------------------------------------------------------------------------------------------------------|
| <b>BLANK</b> | None                                                                                                             |
| <b>B</b>     | (1) backside support (BB12)                                                                                      |
| <b>C</b>     | (1) cable management per connector (TPQCM)                                                                       |
| <b>CB</b>    | (1) cable management backside support (TPQCMBS), (1) cable management connector (TPQCM) per additional connector |

**M**

**Flat face stud mounting**

|              |                      |
|--------------|----------------------|
| <b>BLANK</b> | None                 |
| <b>H</b>     | Single sided bracket |
| <b>M</b>     | Double sided bracket |

**PF**

**Box grounding wire**

|              |                                 |
|--------------|---------------------------------|
| <b>BLANK</b> | None                            |
| <b>PF</b>    | 8" insulated #12, solid wire    |
| <b>PA</b>    | 8" insulated #12, stranded wire |


## Accessories (ordered separately)

**Cable management & backside support**

|                |                                       |
|----------------|---------------------------------------|
| <b>TPQCMBS</b> | Cable management and backside support |
| <b>TPQCM</b>   | Cable management                      |


**Mounting brackets**

|               |                                                                       |
|---------------|-----------------------------------------------------------------------|
| <b>BBT-HF</b> | Telescoping bracket                                                   |
| <b>BBA</b>    | Box mount for telescoping bracket or stud mount                       |
| <b>BBA-4</b>  | Box mount with backside support for telescoping bracket or stud mount |

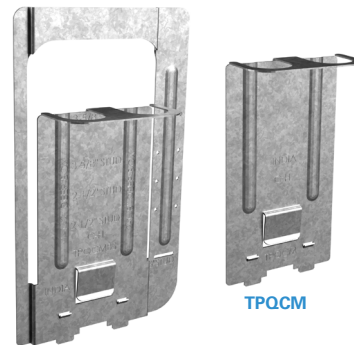

TPQCMBS

TPQCM

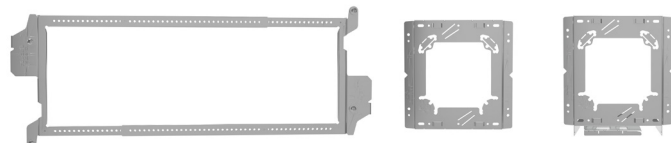


BBT-HF

BBA

BBA-4

## Knockouts

| Type          | Cable entries | Knockouts (dimensions in inches) |                                |                                |
|---------------|---------------|----------------------------------|--------------------------------|--------------------------------|
|               |               | Sides                            | Ends                           | Bottom                         |
| <b>TP4Q10</b> | 2             | (2) 1/2+3/4 eccentric, (4) 1/2   | (2) 1/2+3/4 eccentric, (2) 1/2 | (2) 1/2+3/4 eccentric, (4) 1/2 |
| <b>TP4Q11</b> | 4             | (2) 1/2+3/4 eccentric, (4) 1/2   | (2) 1/2+3/4 eccentric          | (2) 1/2+3/4 eccentric, (4) 1/2 |
| <b>TP5Q10</b> | 2             | (6) 1/2+3/4 eccentric            | (4) 1/2+3/4 eccentric          | (2) 1/2+3/4 eccentric, (2) 1/2 |
| <b>TP5Q11</b> | 4             | (6) 1/2+3/4 eccentric            | (2) 1/2+3/4 eccentric          | (2) 1/2+3/4 eccentric, (2) 1/2 |
| <b>TP5Q20</b> | 4             | (6) 1/2+3/4 eccentric            | (3) 1/2+3/4 eccentric          | (2) 1/2+3/4 eccentric, (2) 1/2 |
| <b>TP5Q21</b> | 6             | (6) 1/2+3/4 eccentric            | (1) 1/2+3/4 eccentric          | (2) 1/2+3/4 eccentric, (2) 1/2 |
| <b>TP5Q22</b> | 6             | (6) 1/2+3/4 eccentric            | —                              | (2) 1/2+3/4 eccentric, (2) 1/2 |

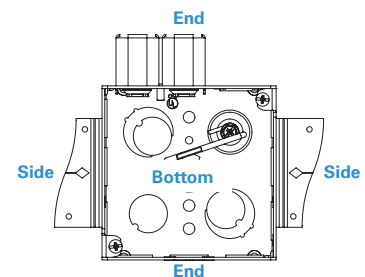

TP4Q series shown in positional diagram

## Listed cable type and range

**Cable range:** .430" diameter minimum to .649" diameter maximum


**Cable types & ranges for connector**

| Cable type             | Range                                        |
|------------------------|----------------------------------------------|
| AC steel & aluminum    | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3,10-4 |
| HCF AC steel           | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3,10-4 |
| HCF AC aluminum        | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3,10-4 |
| MC steel               | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3,10-4 |
| MC aluminum            | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3      |
| MCI-A steel & aluminum | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3      |

| Cable type                  | Range                                   |
|-----------------------------|-----------------------------------------|
| HCF MCI-A steel             | 12-2,12-3,10-2, 10-3                    |
| HCF MCI-A aluminum          | 14-2,14-3,14-4,12-2,12-3,12-4,10-2,10-3 |
| MC-PCS aluminum             | 12-2, 12-3, 10-2                        |
| HCF-PCS aluminum            | 12-2, 12-3                              |
| FLEX RWFMC steel & aluminum | 3/8                                     |


# Configurations – TP4Q

4" square, 2-1/8" deep, eccentric knockouts

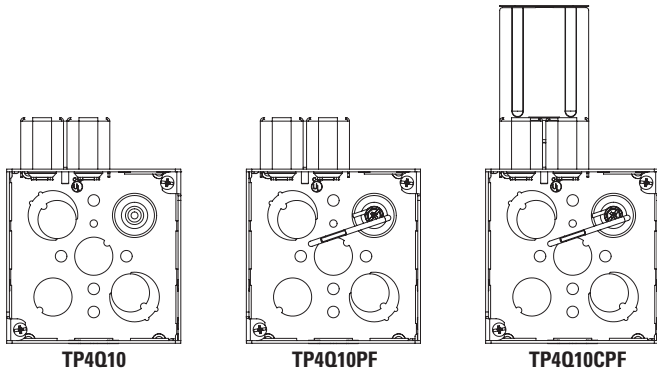


## 4" square Quick-lok configurations with top cable entries only

|                  |                                                                            |
|------------------|----------------------------------------------------------------------------|
| <b>TP4Q10</b>    | (2) cable entries on top, ground bump                                      |
| <b>TP4Q10PF</b>  | (2) cable entries on top, 8" solid #12 ground wire                         |
| <b>TP4Q10CPF</b> | (2) cable entries on top, TPQCM cable management, 8" solid #12 ground wire |

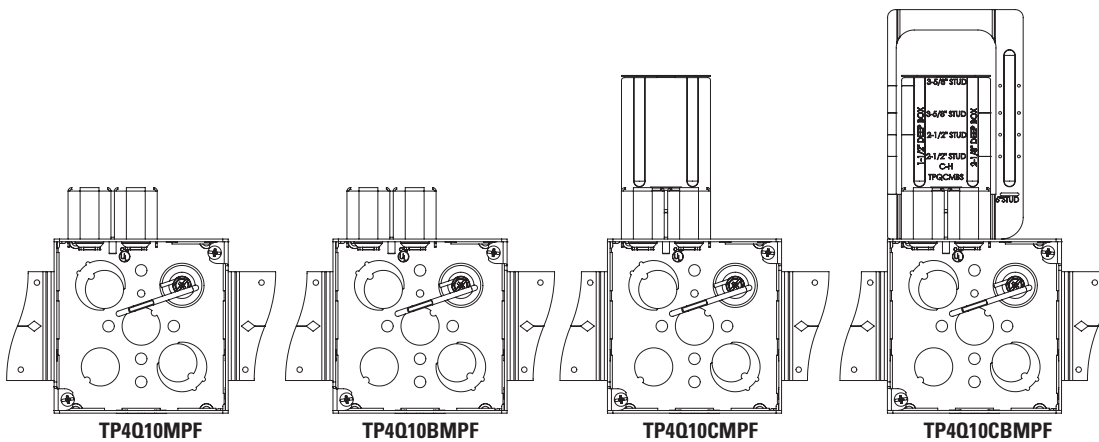

## 4" square Quick-lok configurations with top cable entries and stud brackets

|                    |                                                                                                                     |
|--------------------|---------------------------------------------------------------------------------------------------------------------|
| <b>TP4Q10MPF</b>   | (2) cable entries on top, double sided bracket, 8" solid #12 ground wire                                            |
| <b>TP4Q10BMPF</b>  | (2) cable entries on top, double sided bracket, BB12 backside support, 8" solid #12 ground wire                     |
| <b>TP4Q10CMPF</b>  | (2) cable entries on top, double sided bracket, TPQCM cable management, 8" solid #12 ground wire                    |
| <b>TP4Q10CBMPF</b> | (2) cable entries on top, double sided bracket, TPQCMBS cable management backside support, 8" solid #12 ground wire |

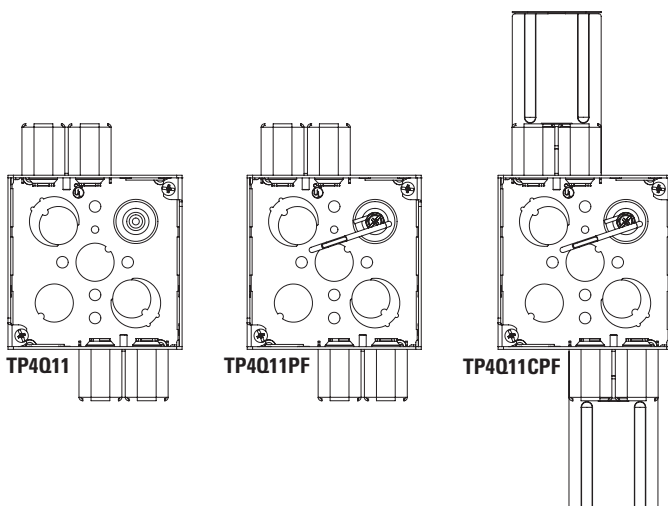


## 4" square Quick-lok configurations with top and bottom cable entries

|                  |                                                                                                         |
|------------------|---------------------------------------------------------------------------------------------------------|
| <b>TP4Q11</b>    | (2) cable entries on top, (2) cable entries on bottom, ground bump                                      |
| <b>TP4Q11PF</b>  | (2) cable entries on top, (2) cable entries on bottom, 8" solid #12 ground wire                         |
| <b>TP4Q11CPF</b> | (2) cable entries on top, (2) cable entries on bottom, TPQCM cable management, 8" solid #12 ground wire |



# Configurations – TP4Q

4" square, 2-1/8" deep, eccentric knockouts

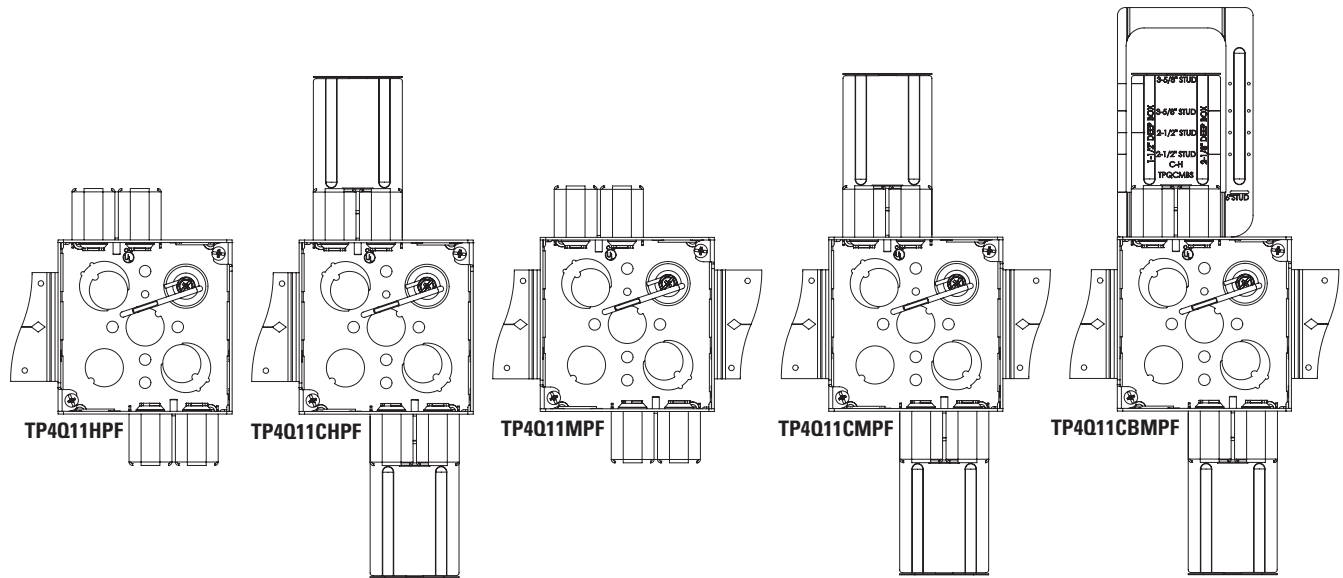


## 4" square Quick-lok configurations with top and bottom cable entries and stud brackets

|                    |                                                                                                                                                                          |
|--------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>TP4Q11HPF</b>   | (2) cable entries on top, (2) cable entries on bottom, single sided bracket, 8" solid #12 ground wire                                                                    |
| <b>TP4Q11BHPF</b>  | (2) cable entries on top, (2) cable entries on bottom, single sided bracket, BB12 backside support, 8" solid #12 ground wire                                             |
| <b>TP4Q11CHPF</b>  | (2) cable entries on top, (2) cable entries on bottom, single sided bracket, TPQCM cable management, 8" solid #12 ground wire                                            |
| <b>TP4Q11CBHPF</b> | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCMBS cable management backside support, TPQCM cable management, 8" solid #12 ground wire |
| <b>TP4Q11MPF</b>   | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, 8" solid #12 ground wire                                                                    |
| <b>TP4Q11CMPF</b>  | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCM cable management, 8" solid #12 ground wire                                            |
| <b>TP4Q11CBMPF</b> | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCMBS cable management backside support, TPQCM cable management, 8" solid #12 ground wire |


## Bulk Options

For contractors that have high volume prefab shops, less management, less packing waste and easy mobility

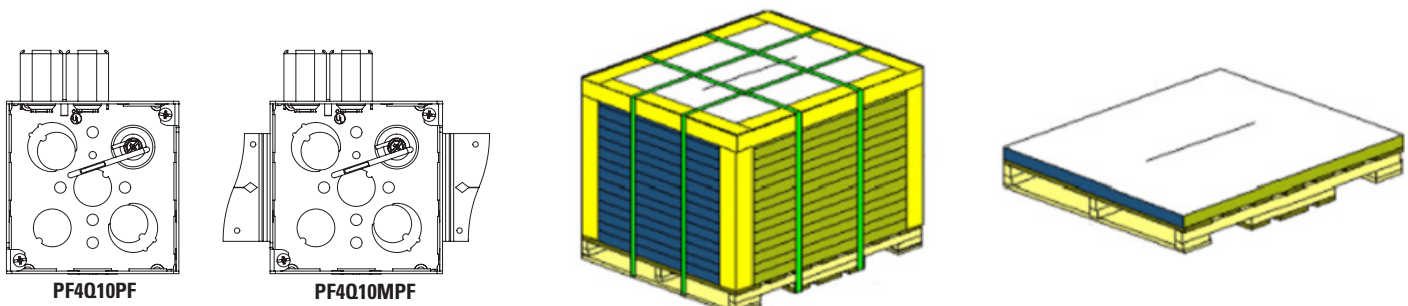


| Part #           | Description                                                              | Pallet dimension (inches) |       |       | Per pallet units |              |             | Gross weight (lbs.) |
|------------------|--------------------------------------------------------------------------|---------------------------|-------|-------|------------------|--------------|-------------|---------------------|
|                  |                                                                          | Length                    | Width | Depth | Total units      | Total layers | Units/layer |                     |
| <b>PF4Q10PF</b>  | (2) cable entries on top, 8" solid #12 ground wire                       | 48.00                     | 40.00 | 42.25 | 1080             | 15           | 72          | 1,100               |
| <b>PF4Q10MPF</b> | (2) cable entries on top, double sided bracket, 8" solid #12 ground wire | 48.00                     | 40.00 | 42.25 | 720              | 15           | 48          | 815                 |

Dimensions—TP4Q

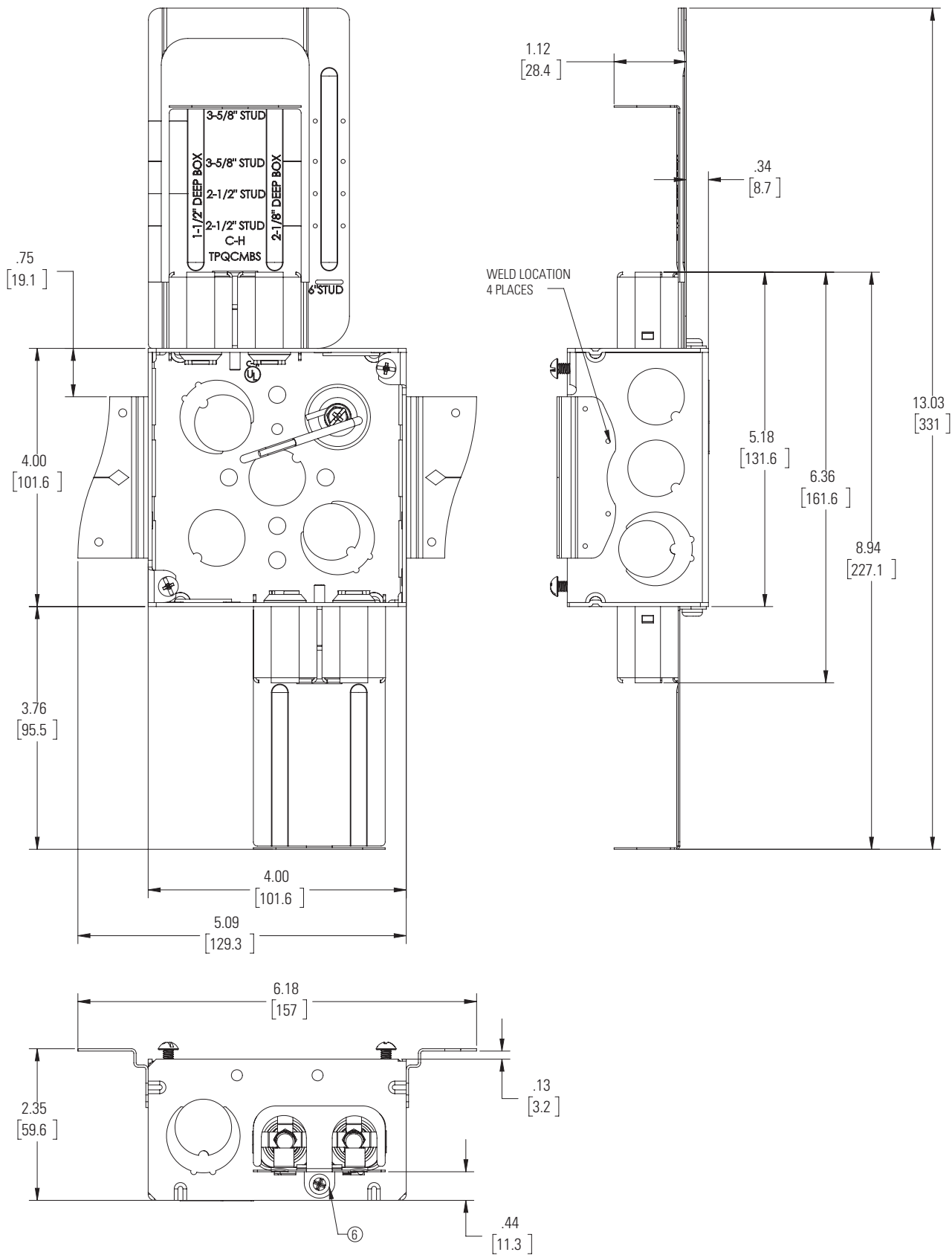


# Configurations – TP5Q

4-11/16" square, 2-1/8" deep, eccentric knockouts

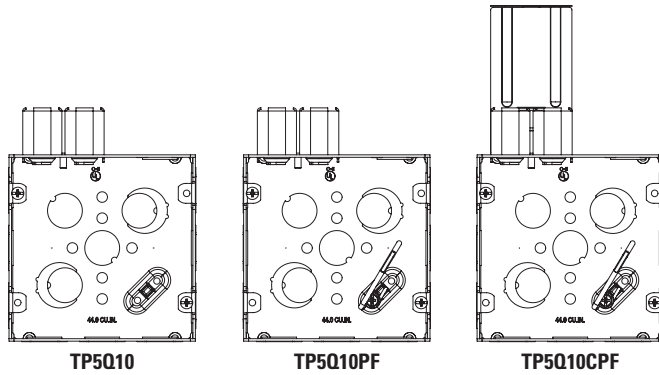


## 4-11/16" square Quick-Lok with top cable entries only

|           |                                                                            |
|-----------|----------------------------------------------------------------------------|
| TP5Q10    | (2) cable entries on top, ground bump                                      |
| TP5Q10PF  | (2) cable entries on top, 8" solid #12 ground wire                         |
| TP5Q10CPF | (2) cable entries on top, TPQCM cable management, 8" solid #12 ground wire |

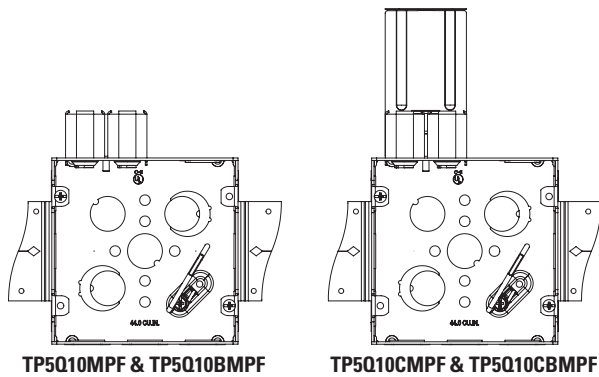

## 4-11/16" square Quick-Lok with top cable entries and double sided stud brackets

|             |                                                                                                  |
|-------------|--------------------------------------------------------------------------------------------------|
| TP5Q10MPF   | (2) cable entries on top, double sided bracket, 8" solid #12 ground wire                         |
| TP5Q10BMPF  | (2) cable entries on top, double sided bracket, BB12 backside support, 8" solid #12 ground wire  |
| TP5Q10CMPF  | (2) cable entries on top, double sided bracket, TPQCM cable management, 8" solid #12 ground wire |
| TP5Q10CBMPF | (2) cable entries on top, double sided bracket, TPQCM cable management, 8" solid #12 ground wire |

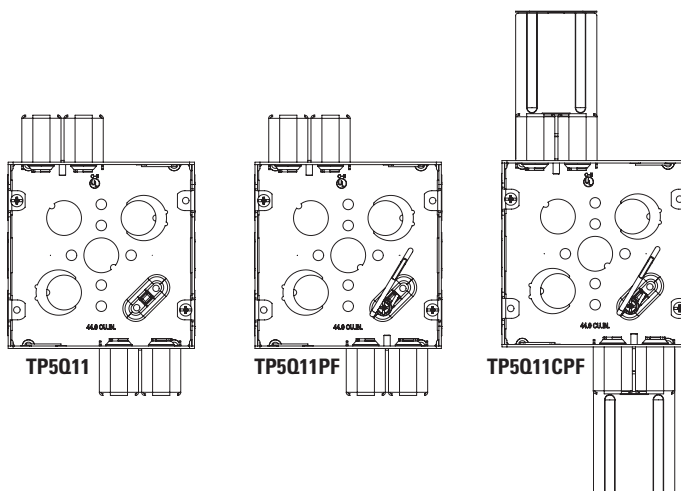


## 4-11/16" square Quick-Lok with top & bottom cable entries only

|           |                                                                                                           |
|-----------|-----------------------------------------------------------------------------------------------------------|
| TP5Q11    | (2) cable entries on top, (2) cable entries on bottom, ground bump                                        |
| TP5Q11PF  | (2) cable entries on top, (2) cable entries on bottom, 8" solid #12 ground wire                           |
| TP5Q11CPF | (2) cable entries on top, (2) cable entries on bottom, TPQCMBS cable management, 8" solid #12 ground wire |




# Configurations – TP5Q

4-11/16" square, 2-1/8" deep, eccentric knockouts

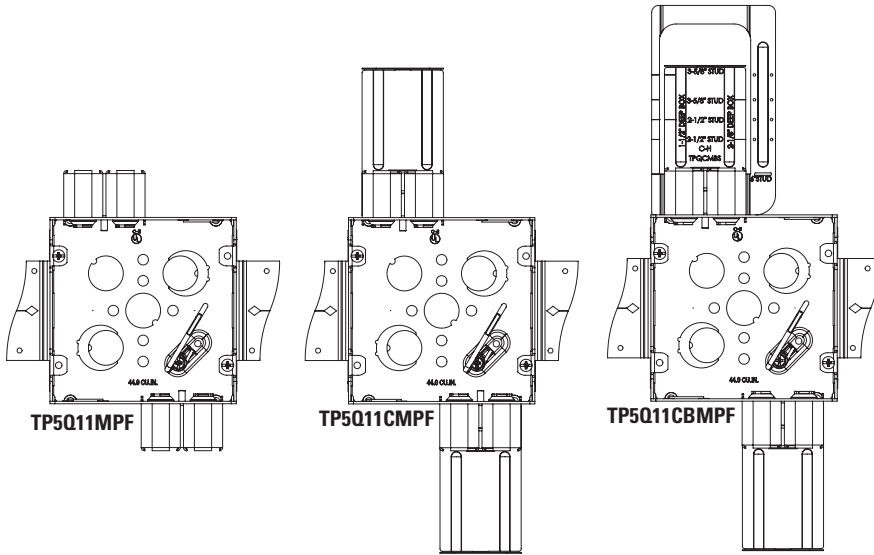


## 4-11/16" square Quick-lok configurations with top and bottom cable entries and stud brackets

|                    |                                                                                                                                                                          |
|--------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>TP5Q11MPF</b>   | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, 8" solid #12 ground wire                                                                    |
| <b>TP5Q11CMPF</b>  | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCM cable management, 8" solid #12 ground wire                                            |
| <b>TP5Q11CBMPF</b> | (2) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCMBS cable management backside support, TPQCM cable management, 8" solid #12 ground wire |

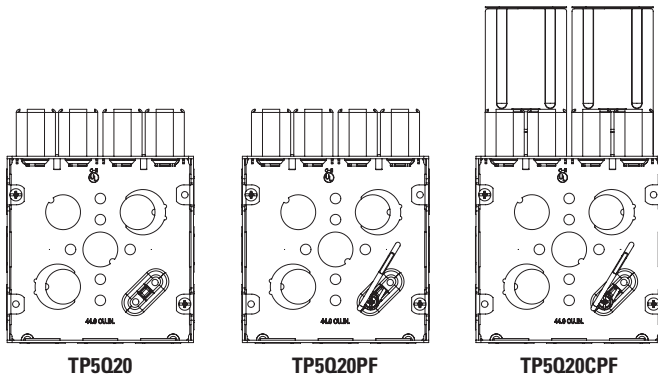

## 4-11/16" square Quick-lok configurations with top cable entries

|                  |                                                                            |
|------------------|----------------------------------------------------------------------------|
| <b>TP5Q20</b>    | (4) cable entries on top, ground bump                                      |
| <b>TP5Q20PF</b>  | (4) cable entries on top, ground bump, solid #12 ground wire               |
| <b>PF5Q20PF</b>  | (4) cable entries on top, ground bump, solid #12 ground wire               |
| <b>TP5Q20CPF</b> | (4) cable entries on top, TPQCM cable management, 8" solid #12 ground wire |

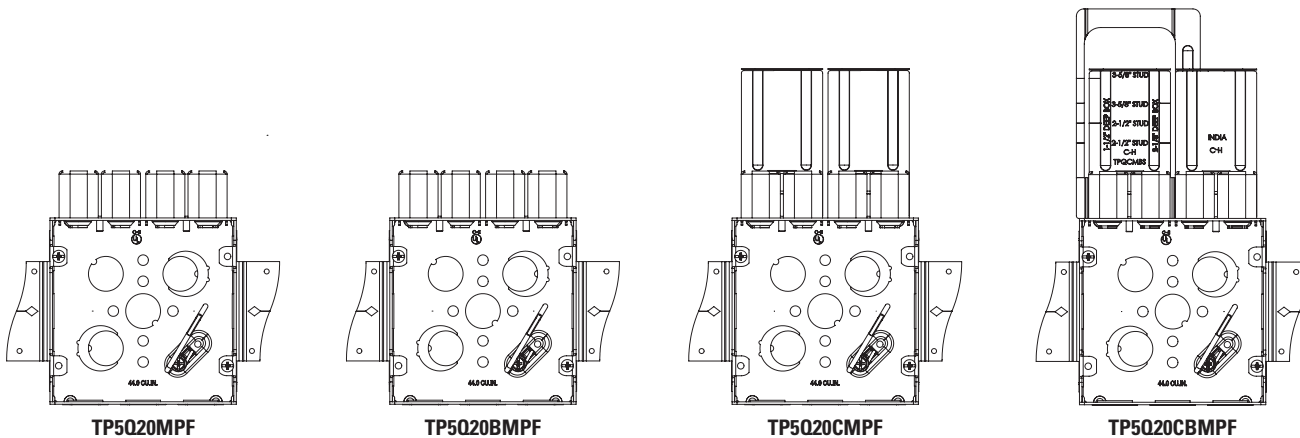


## 4-11/16" square Quick-lok configurations with top cable entries and stud brackets

|                    |                                                                                                                                             |
|--------------------|---------------------------------------------------------------------------------------------------------------------------------------------|
| <b>TP5Q20MPF</b>   | (4) cable entries on top, double sided bracket, 8" solid #12 ground wire                                                                    |
| <b>PF5Q20MPF</b>   | (4) cable entries on top, double sided bracket, 8" solid #12 ground wire                                                                    |
| <b>TP5Q20BMPF</b>  | (4) cable entries on top, double sided bracket, BB12 backside support, 8" solid #12 ground wire                                             |
| <b>TP5Q20CMPF</b>  | (4) cable entries on top, double sided bracket, TPQCM cable management, 8" solid #12 ground wire                                            |
| <b>TP5Q20CBMPF</b> | (4) cable entries on top, double sided bracket, TPQCMBS cable management backside support, TPQCM cable management, 8" solid #12 ground wire |


# Configurations – TP5Q

4-11/16" square, 2-1/8" deep, eccentric knockouts

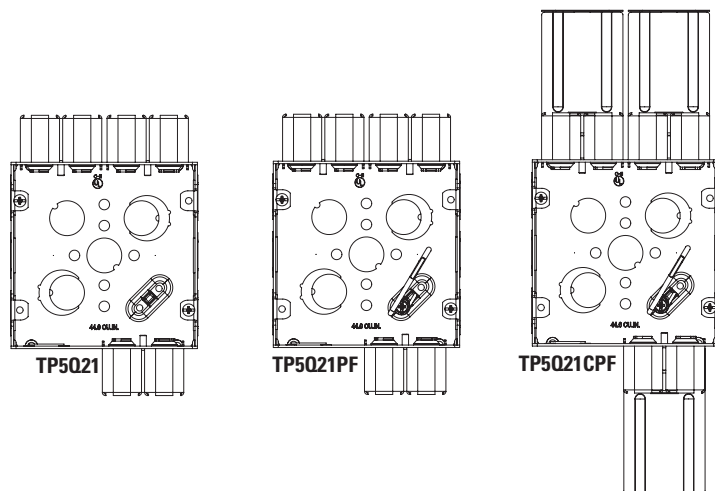


## 4-11/16" square Quick-lok configurations with top and bottom cable entries

|                  |                                                                                                         |
|------------------|---------------------------------------------------------------------------------------------------------|
| <b>TP5Q21</b>    | (4) cable entries on top, (2) cable entries on bottom, ground bump                                      |
| <b>TP5Q21PF</b>  | (4) cable entries on top, (2) cable entries on bottom, 8" solid #12 ground wire                         |
| <b>TP5Q21CPF</b> | (4) cable entries on top, (2) cable entries on bottom, TPQCM cable management, 8" solid #12 ground wire |

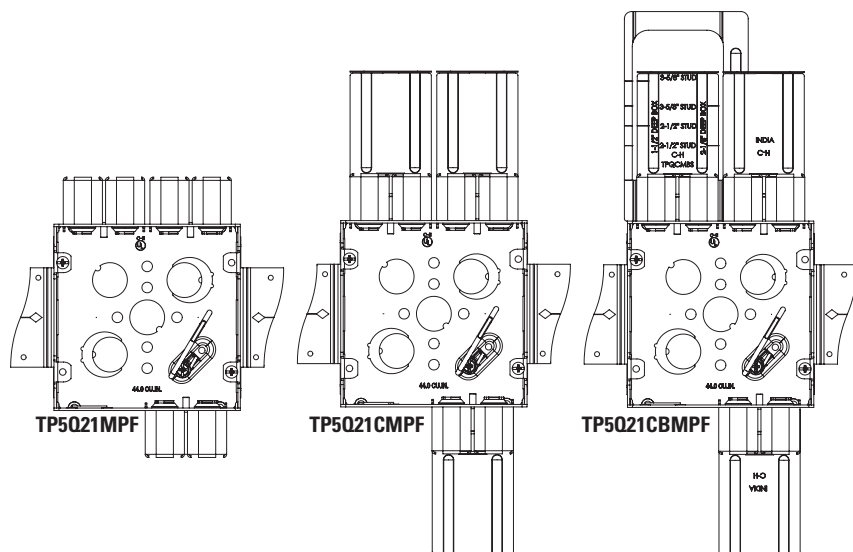

## 4-11/16" square Quick-lok configurations with top and bottom connectors and stud brackets


|                    |                                                                                                                                                                          |
|--------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>TP5Q21MPF</b>   | (4) cable entries on top, (2) cable entries on bottom, double sided bracket, 8" solid #12 ground wire                                                                    |
| <b>TP5Q21CMPF</b>  | (4) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCM cable management, 8" solid #12 ground wire                                            |
| <b>TP5Q21CBMPF</b> | (4) cable entries on top, (2) cable entries on bottom, double sided bracket, TPQCMBS cable management backside support, TPQCM cable management, 8" solid #12 ground wire |

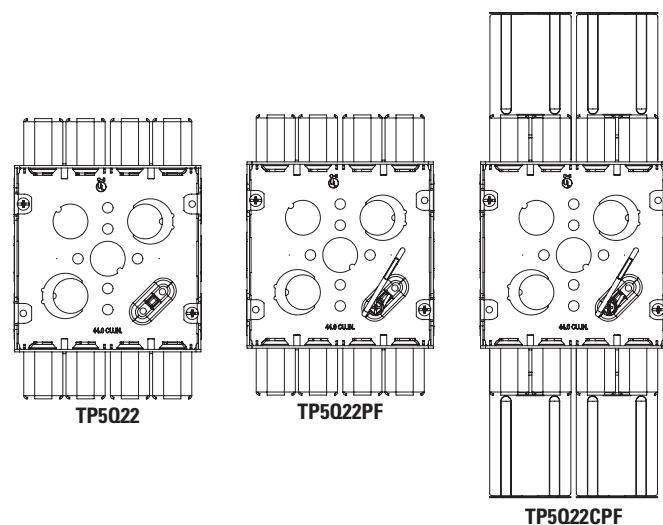

## 4-11/16" square Quick-lok configurations with top and bottom cable entries only

|                  |                                                                                                         |
|------------------|---------------------------------------------------------------------------------------------------------|
| <b>TP5Q22</b>    | (4) cable entries on top, (4) cable entries on bottom, ground bump                                      |
| <b>TP5Q22PF</b>  | (4) cable entries on top, (4) cable entries on bottom, 8" solid #12 ground wire                         |
| <b>TP5Q22CPF</b> | (4) cable entries on top, (4) cable entries on bottom, TPQCM cable management, 8" solid #12 ground wire |

# Configurations – TP5Q

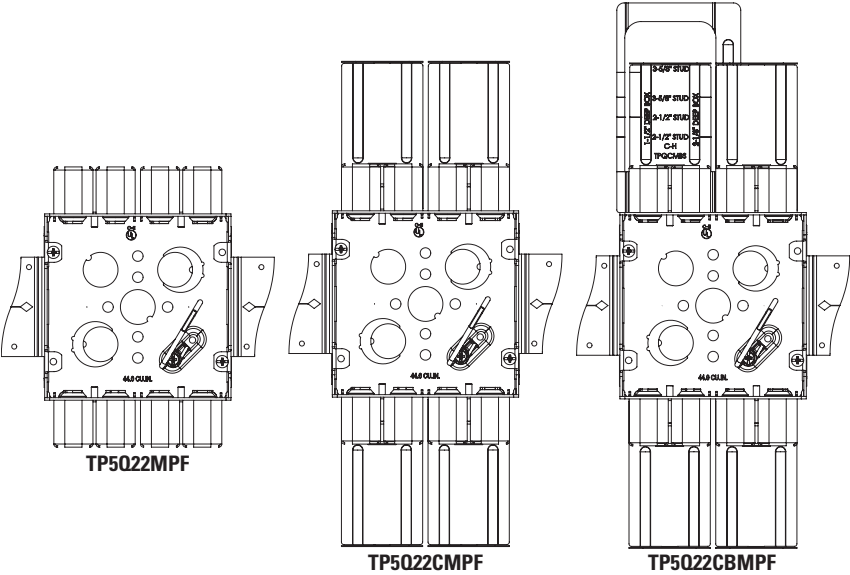


**4-11/16" square Quick-lok configurations with top and bottom connectors and stub brackets**

|             |                                                                                                                                                                          |
|-------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| TP5Q22MPF   | (4) cable entries on top, (4) cable entries on bottom, double sided bracket, 8" solid #12 ground wire                                                                    |
| TP5Q22CMPF  | (4) cable entries on top, (4) cable entries on bottom, double sided bracket, TPQCM cable management, 8" solid #12 ground wire                                            |
| TP5Q22CBMPF | (4) cable entries on top, (4) cable entries on bottom, double sided bracket, TPQCMBS cable management backside support, TPQCM cable management, 8" solid #12 ground wire |

## Bulk Options


For contractors that have high volume prefab shops, less management, less packing waste and easy mobility

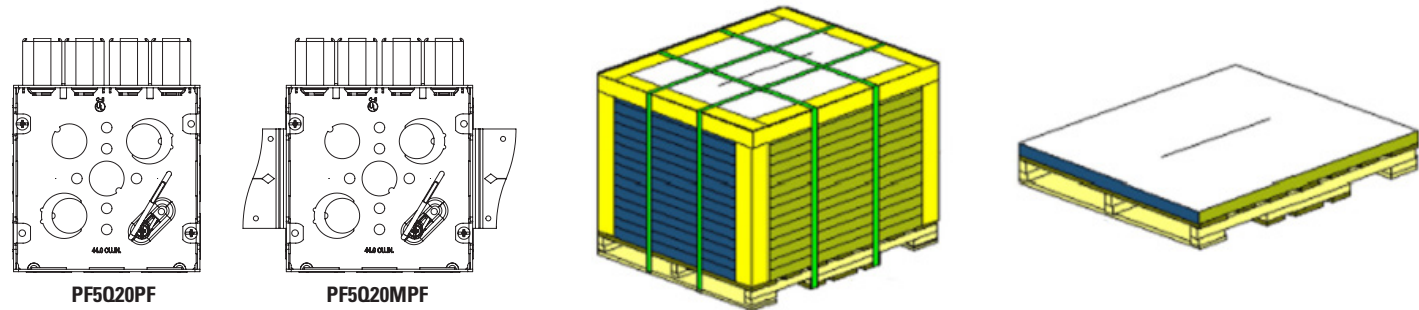

| Part #    | Description                                                              | Pallet dimension (inches) |       |       | Per pallet units |              |             | Gross weight (lbs) |
|-----------|--------------------------------------------------------------------------|---------------------------|-------|-------|------------------|--------------|-------------|--------------------|
|           |                                                                          | Length                    | Width | Depth | Total units      | Total layers | Units/layer |                    |
| PF5Q20PF  | (4) cable entries on top, ground bump, solid #12 ground wire             | 48.00                     | 40.00 | 42.25 | 960              | 15           | 64          | 1,230              |
| PF5Q20MPF | (4) cable entries on top, double sided bracket, 8" solid #12 ground wire | 48.00                     | 40.00 | 42.25 | 720              | 15           | 48          | 1,025              |



# Dimensions—TP5Q

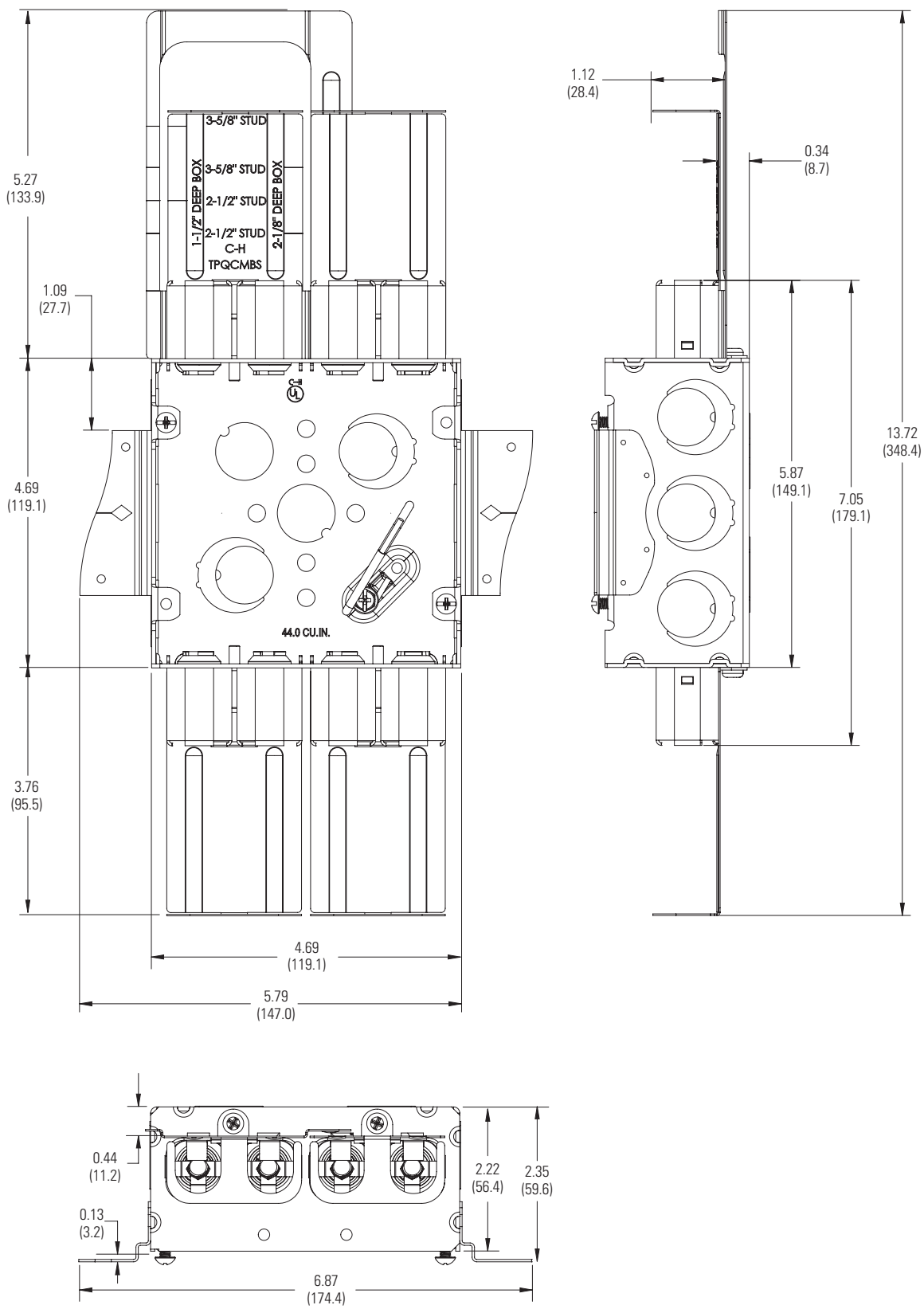

**U.S. (global headquarters):  
Eaton's Crouse-Hinds business**

1201 Wolf Street  
Syracuse, NY 13208

(866) 764-5454  
FAX: (315) 477-5179  
FAX Orders Only:  
(866) 653-0640

[crousecustomerctr@eaton.com](mailto:crousecustomerctr@eaton.com)

**Eaton's B-Line business**

509 West Monroe Street  
Highland, IL 62249

800-851-7415  
FAX: 618-654-1917  
[Eaton.com/b-lineseries](http://Eaton.com/b-lineseries)

**IEC Electrical**  
(CEAG products)

49 (0) 6271 806-500  
FAX: 49 (0) 6271 806-476

[Info-ex@eaton.com](mailto:Info-ex@eaton.com)

**Airport Lighting**

866-764-5454

[CrouseCustomerCTR@Eaton.com](mailto:CrouseCustomerCTR@Eaton.com)

**Mexico/Latin America/Caribbean**

52-555-804-4000  
FAX: 52-555-804-4020

[ventascentromex@eaton.com](mailto:ventascentromex@eaton.com)

**Haz Area Communications**  
(MEDC, Hernis, Oxalis, FHF Sonix)

44 (0) 1623 444400  
FAX: 44 (0) 1623 444531

[MEDCadmin@Eaton.com](mailto:MEDCadmin@Eaton.com)

**Canada**

Toll Free: 800-265-0502  
FAX: (800) 263-9504  
FAX Orders only: (866) 653-0645

**China**

86-21-2899-3600  
FAX: 86-21-2899-4055  
[echsales@eaton.com](mailto:echsales@eaton.com)

**Process instrumentation**  
(MTL products)

44 (0) 1582 723633  
FAX: 44 (0) 1582 422283

[enquiry@mtl-inst.com](mailto:enquiry@mtl-inst.com)

**Eaton Middle East**

9714-8066100  
FAX: 9714-8894813  
[CHBL-ME@eaton.com](mailto:CHBL-ME@eaton.com)

**Australia**

61-2-8787-2777  
FAX: 61-2-9609-2342  
[crousehindsanz@eaton.com](mailto:crousehindsanz@eaton.com)

**For more information:**

If further assistance is required, please contact an authorized Eaton Distributor, Sales Office, or Customer Service Department.

**Eaton**  
1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
[Eaton.com](http://Eaton.com)

© 2022 Eaton  
All Rights Reserved  
Printed in USA  
Publication No. BR406004EN  
April 2022

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.

