

DC (direct current) PD Series molded-case circuit breakers

Contents

Description	Page
Type PDK1 , 25 – 100 amperes, fixed thermal – fixed magnetic, curve No. TC012058EN	2
Type PDK2 , fixed thermal – fixed magnetic, 15 amperes, curve No. TC012059EN	3
20 amperes, curve No. TC012059EN	4
25 amperes, curve No. TC012059EN	5
30 amperes, curve No. TC012059EN	6
35 amperes, curve No. TC012059EN	7
40 amperes, curve No. TC012059EN	8
45 amperes, curve No. TC012059EN	9
50 amperes, curve No. TC012059EN	10
60 amperes, curve No. TC012059EN	11
70 amperes, curve No. TC012059EN	12
80 amperes, curve No. TC012059EN	13
90 amperes, curve No. TC012059EN	14
100 amperes, curve No. TC012059EN	15
110 amperes, curve No. TC012059EN	16
125 amperes, curve No. TC012059EN	17
150 amperes, curve No. TC012059EN	18
175 amperes, curve No. TC012059EN	19
200 amperes, curve No. TC012059EN	20
225 amperes, curve No. TC012059EN	21
Type PDK3 , 400A frame, 100 – 400 amperes, fixed thermal – adjustable magnetic, curve No. TC012060EN	22
Type PDK3 , 600A frame, 250 – 600 amperes, fixed thermal – adjustable magnetic, curve No. TC012060EN	23
Type PDK4 , 300 – 600 amperes, fixed thermal – adjustable magnetic, curve No. TC012061EN	24
Type PDK4 , 700 – 800 amperes, fixed thermal – adjustable magnetic, curve No. TC012061EN	25
Type PDK5 , 800 – 1200 amperes, fixed magnetic, curve No. TC012062EN	26
Type PDK6 , 1600 – 3000 amperes, fixed magnetic, curve No. TC012063EN	27



Powering Business Worldwide

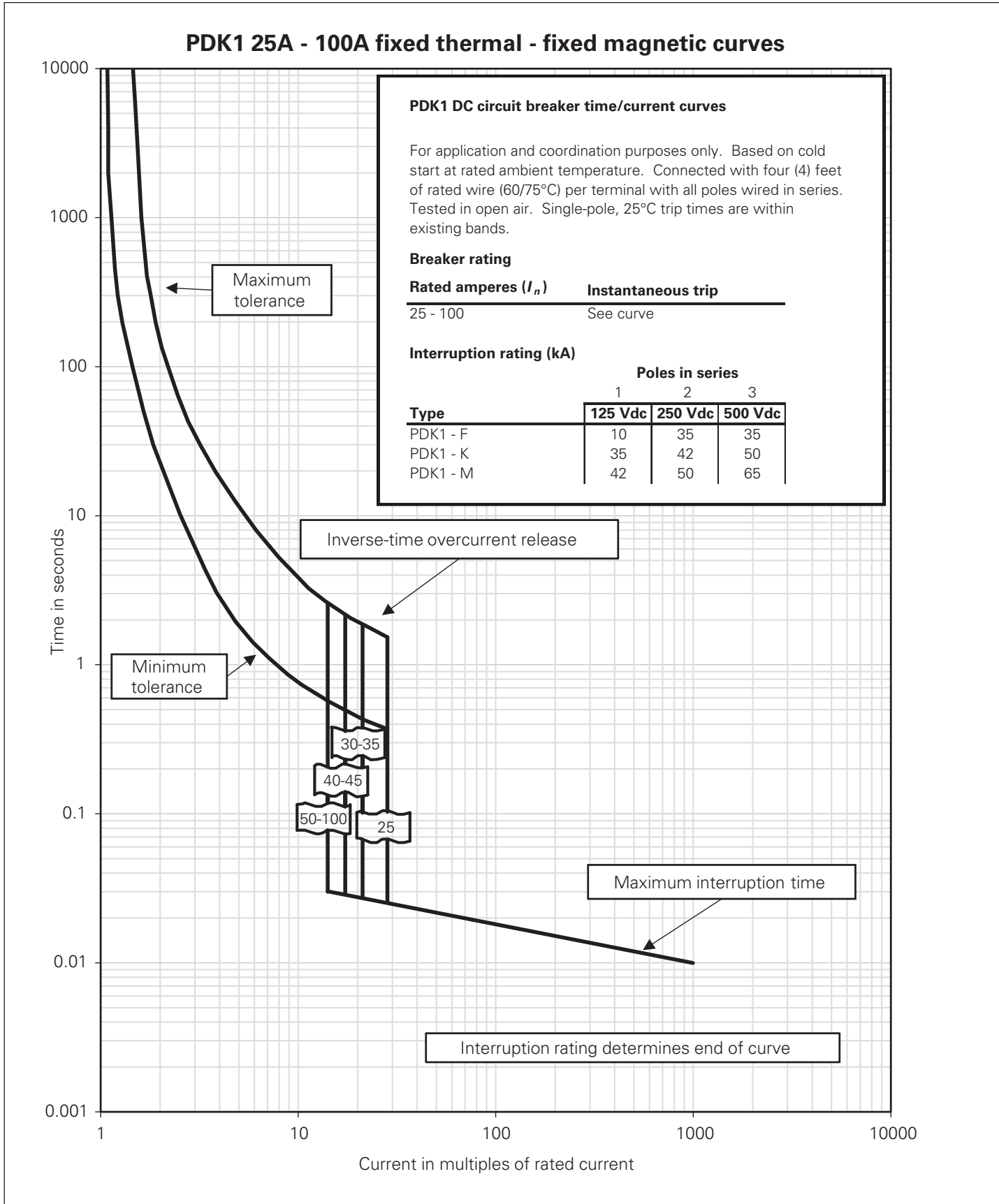


Figure 1. Type PDK1, 25 – 100 amperes, fixed thermal – fixed magnetic, curve No. TC012058EN

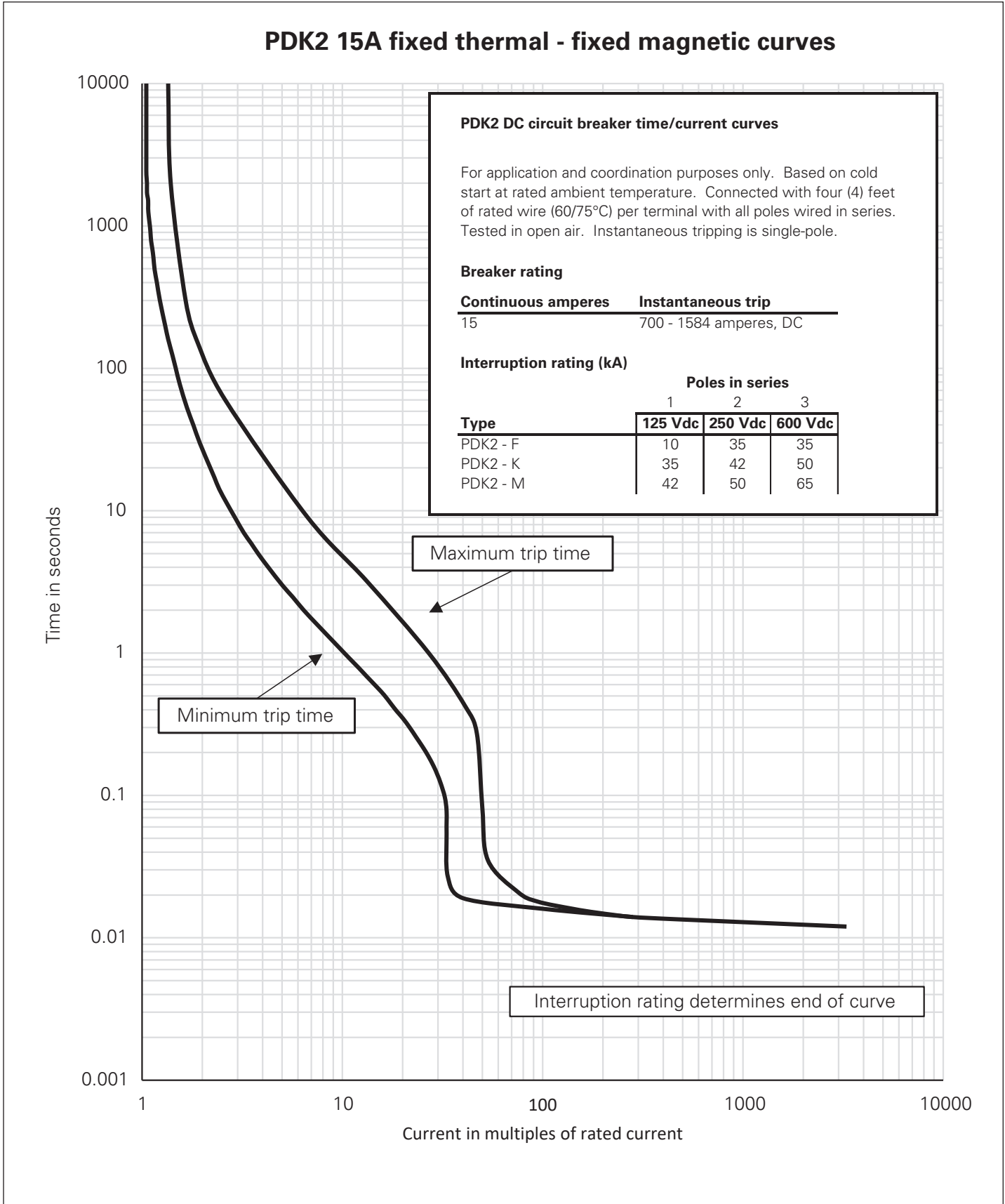


Figure 2. Type PDK2, 15 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

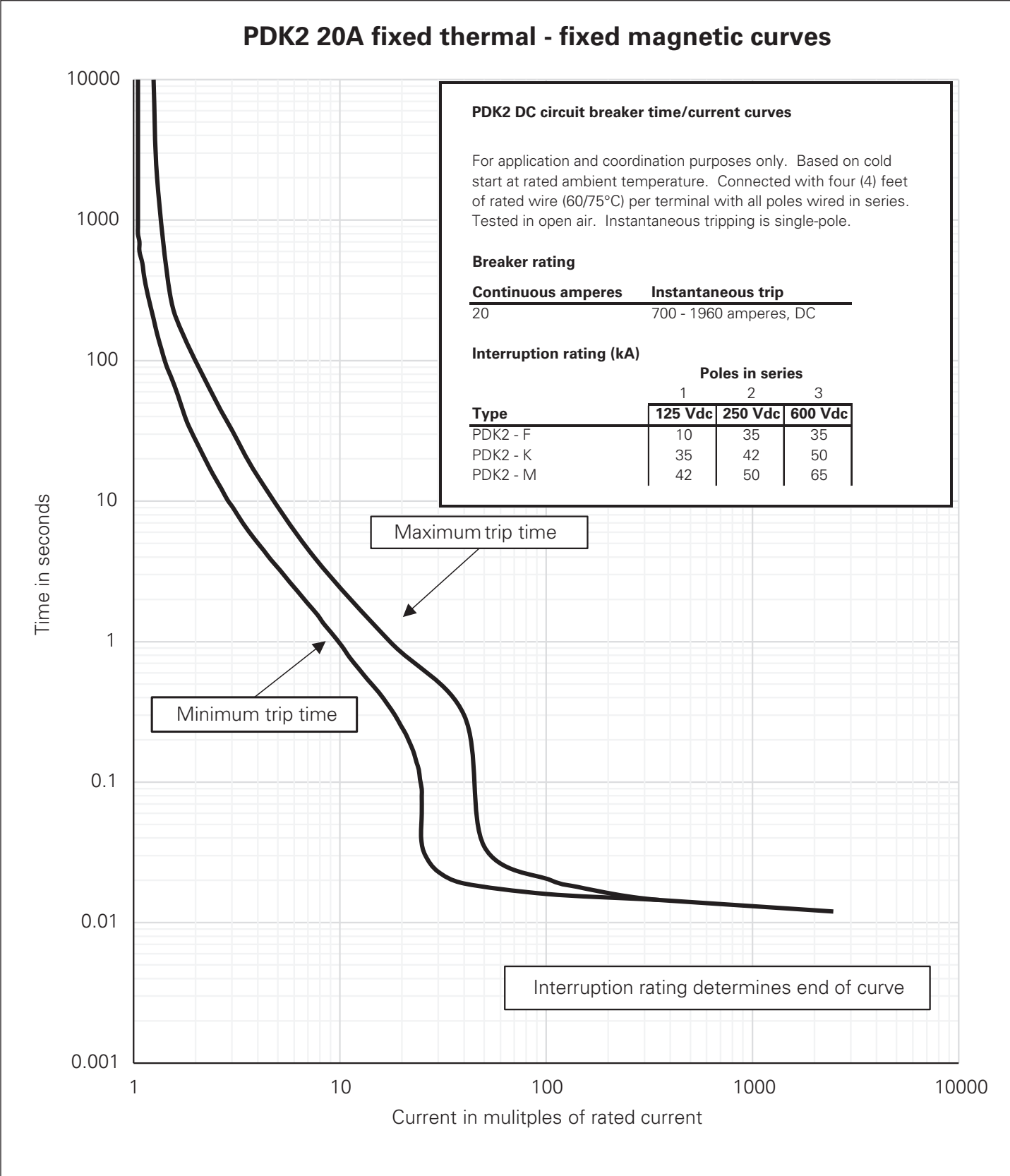


Figure 3. Type PDK2, 20 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

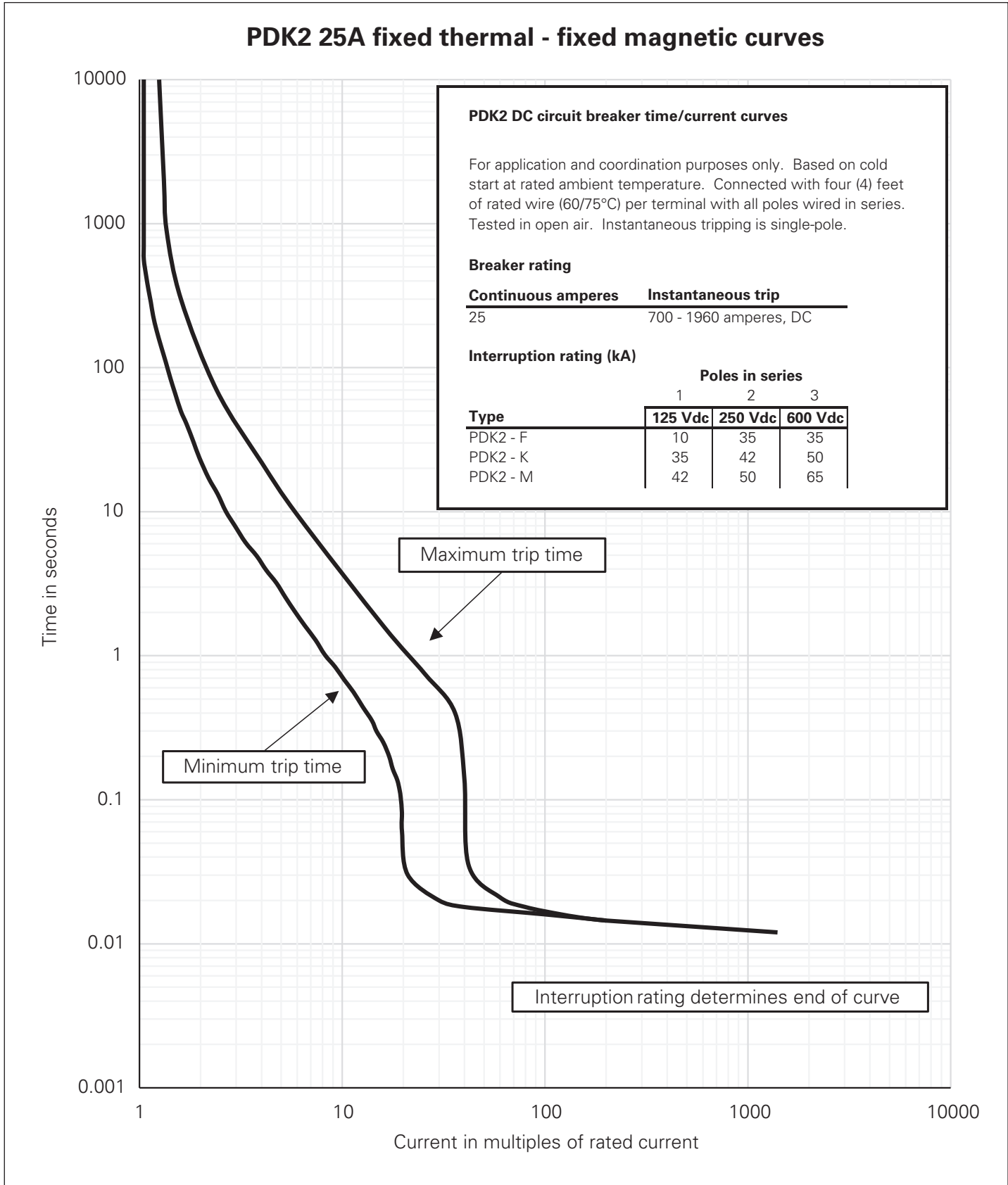


Figure 4. Type PDK2, 25 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

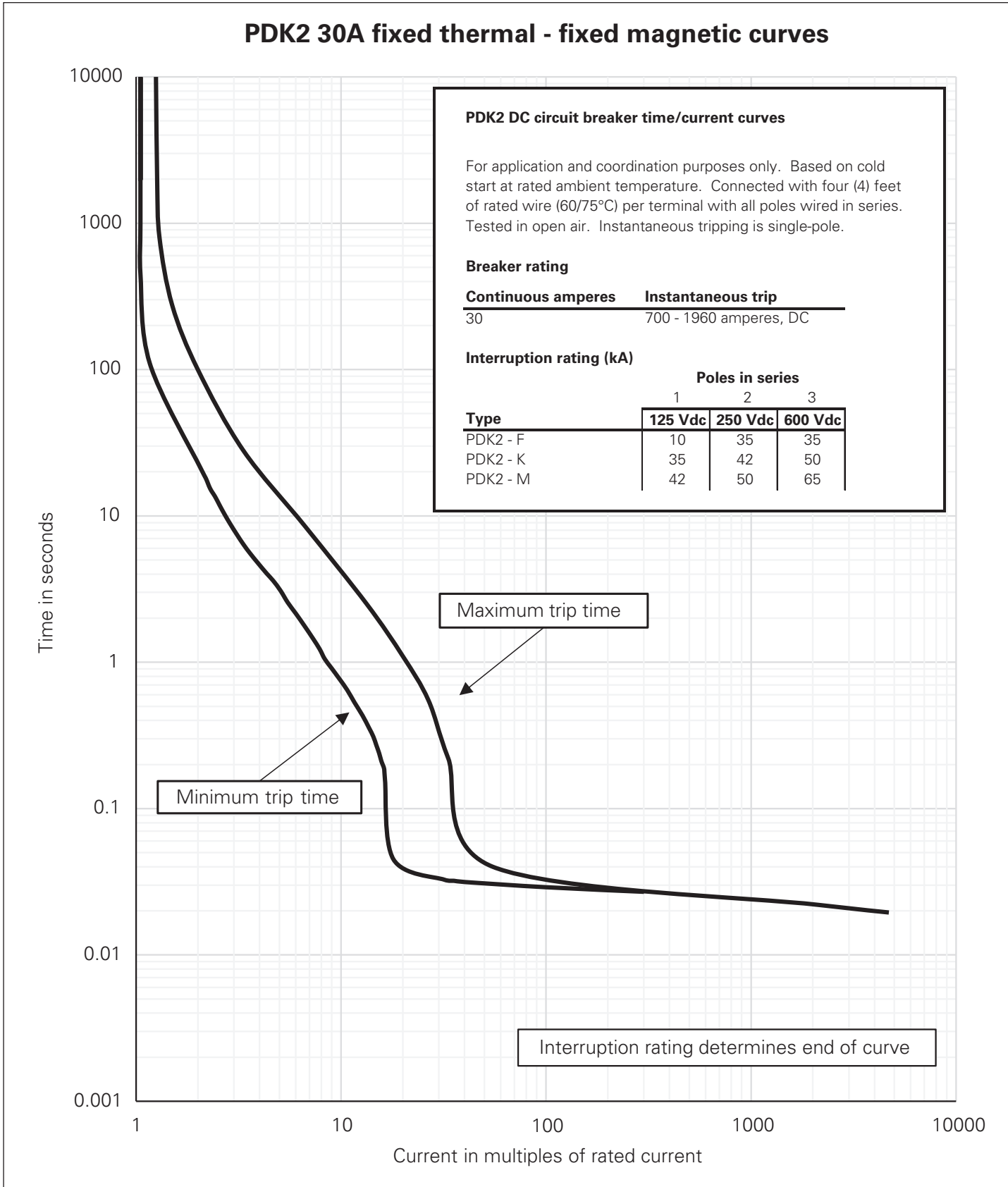


Figure 5. Type PDK2, 30 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

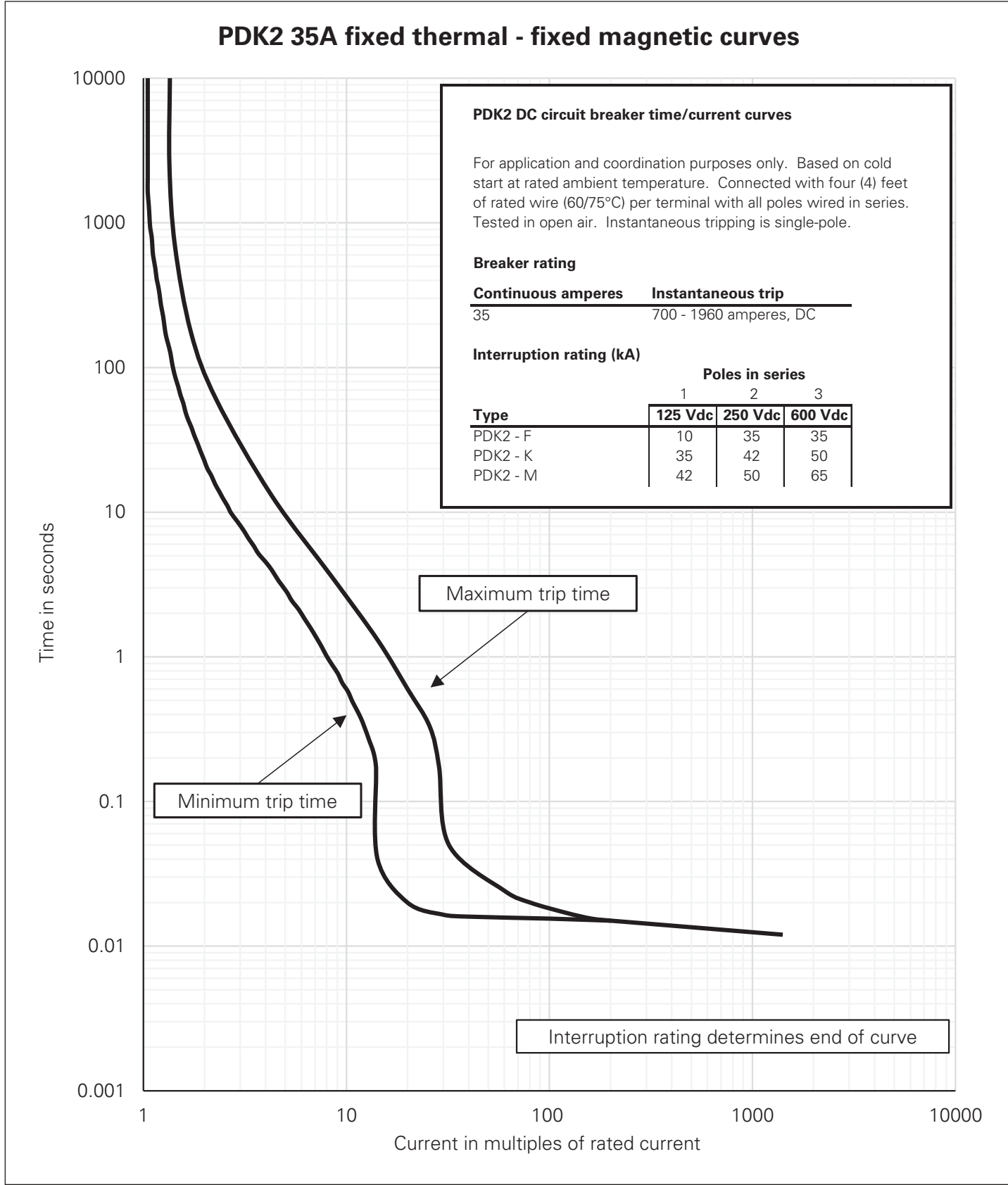


Figure 6. Type PDK2, 35 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

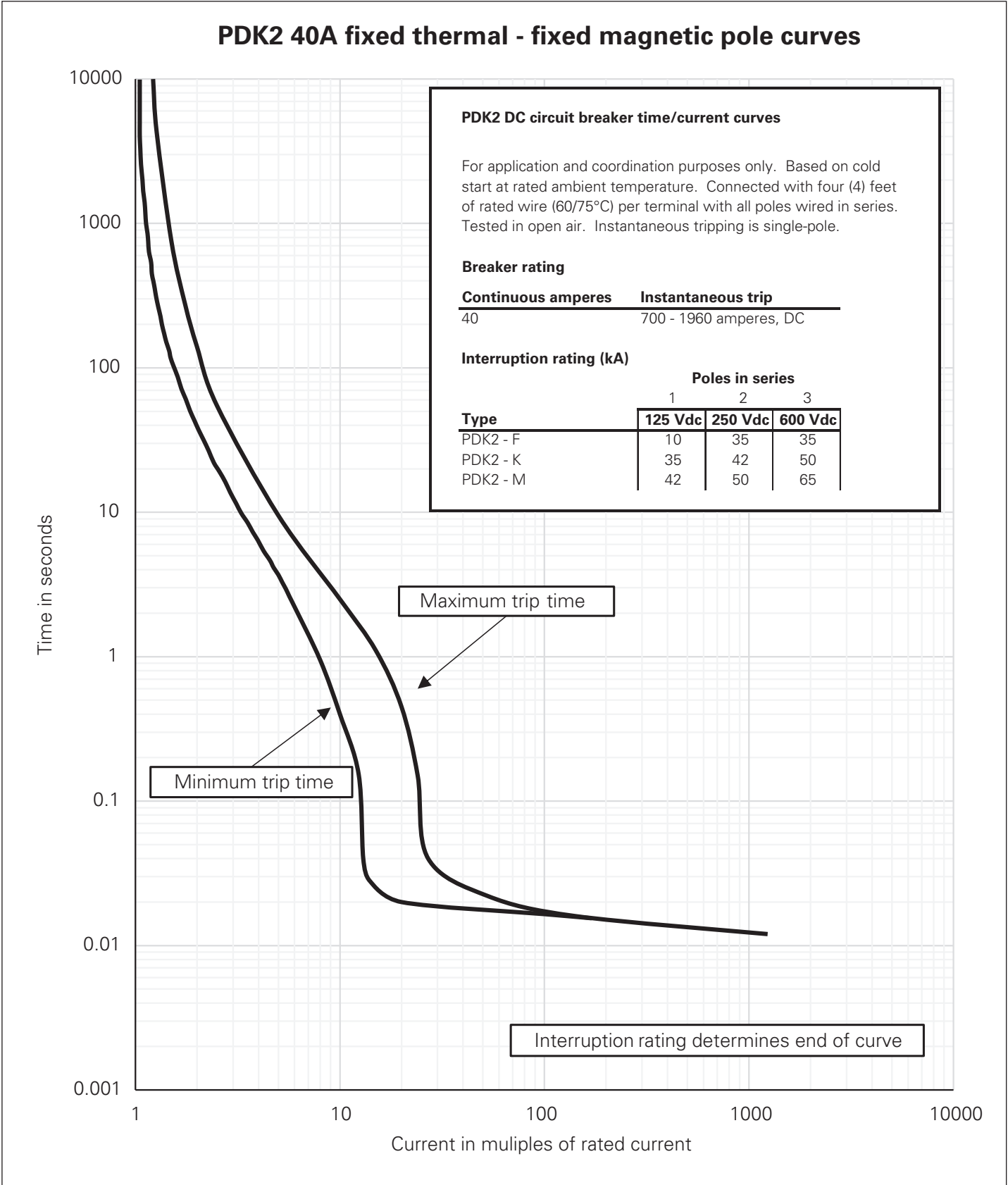


Figure 7. Type PDK2, 40 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

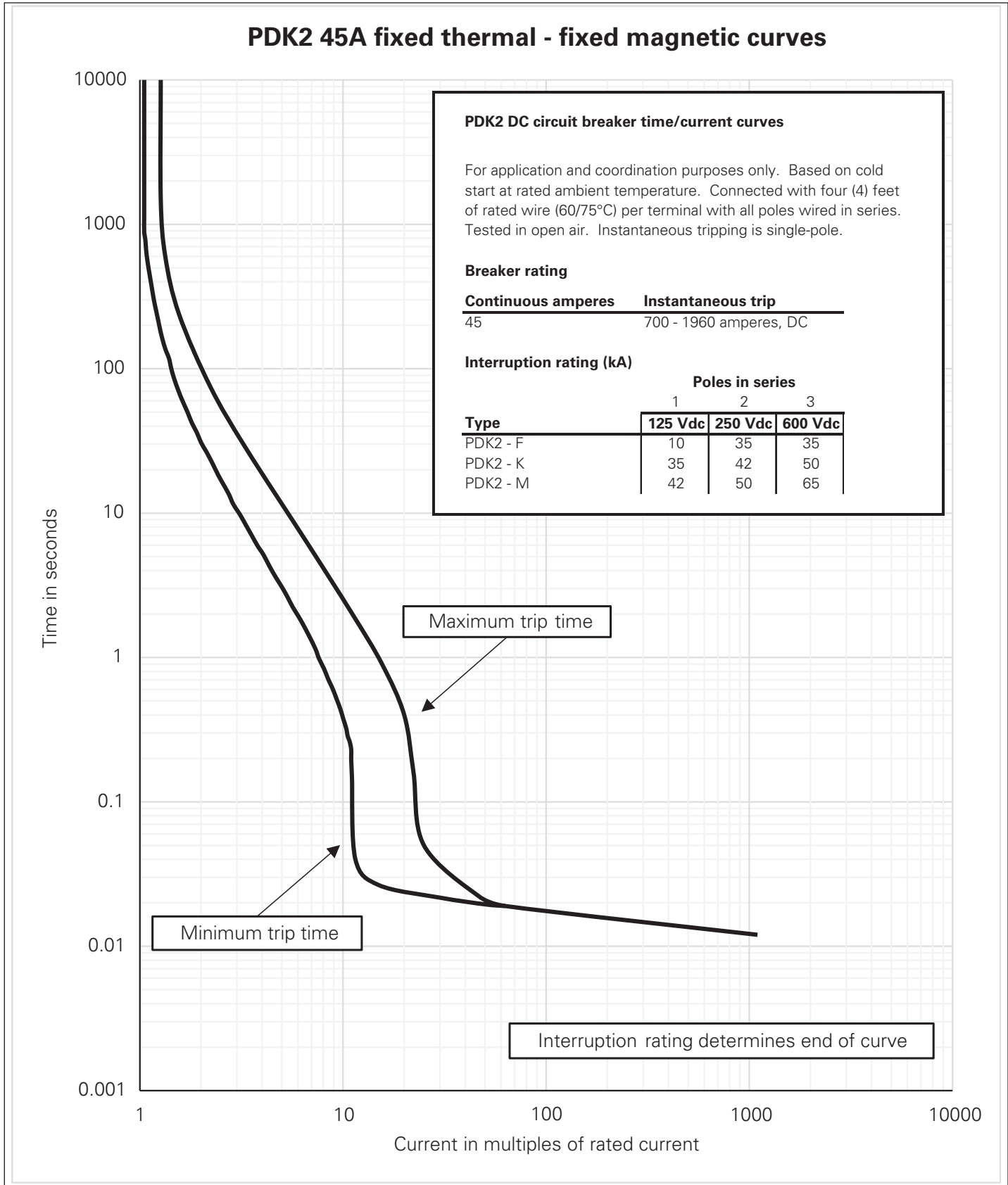


Figure 8. Type PDK2, 45 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

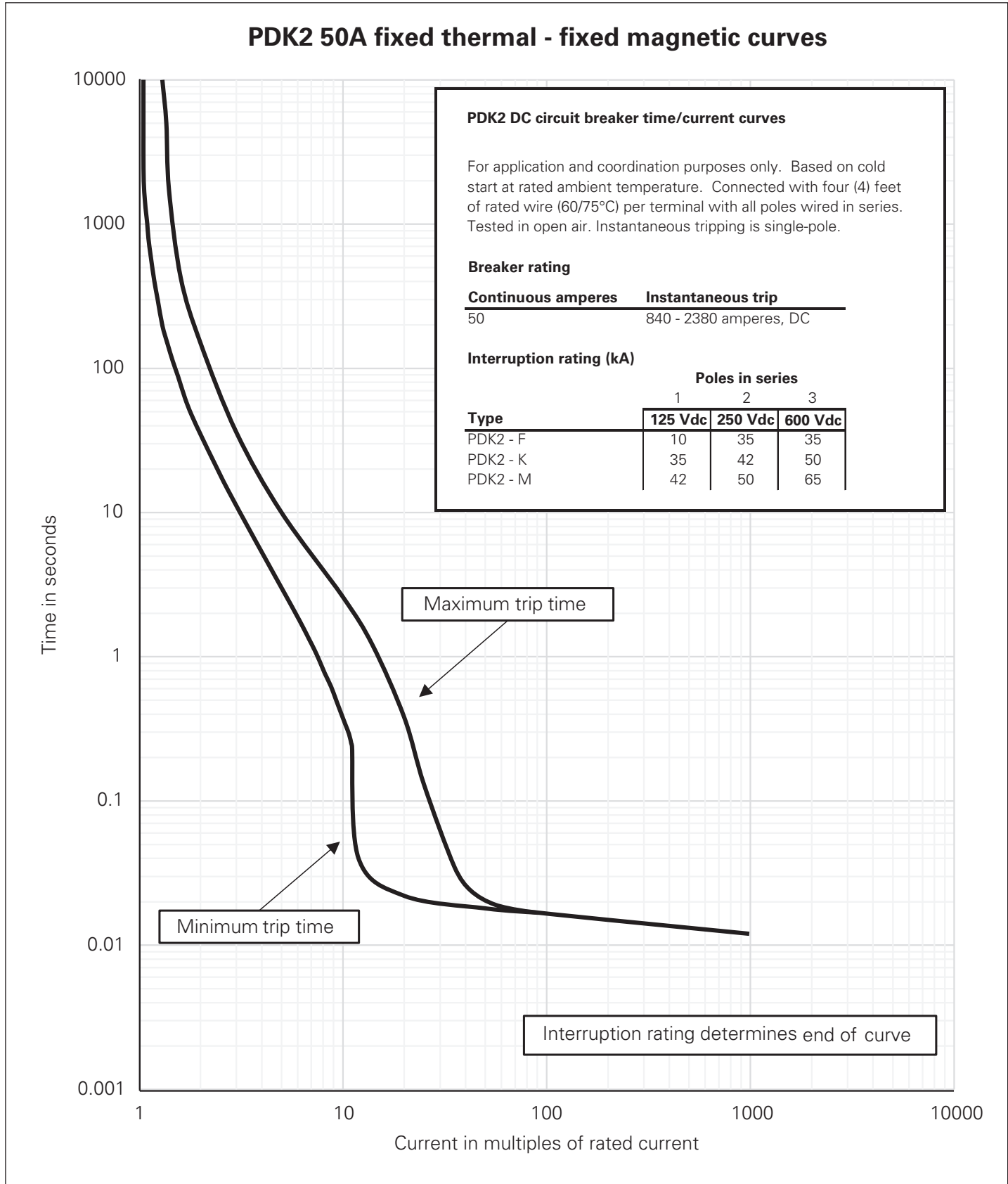


Figure 9. Type PDK2, 50 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

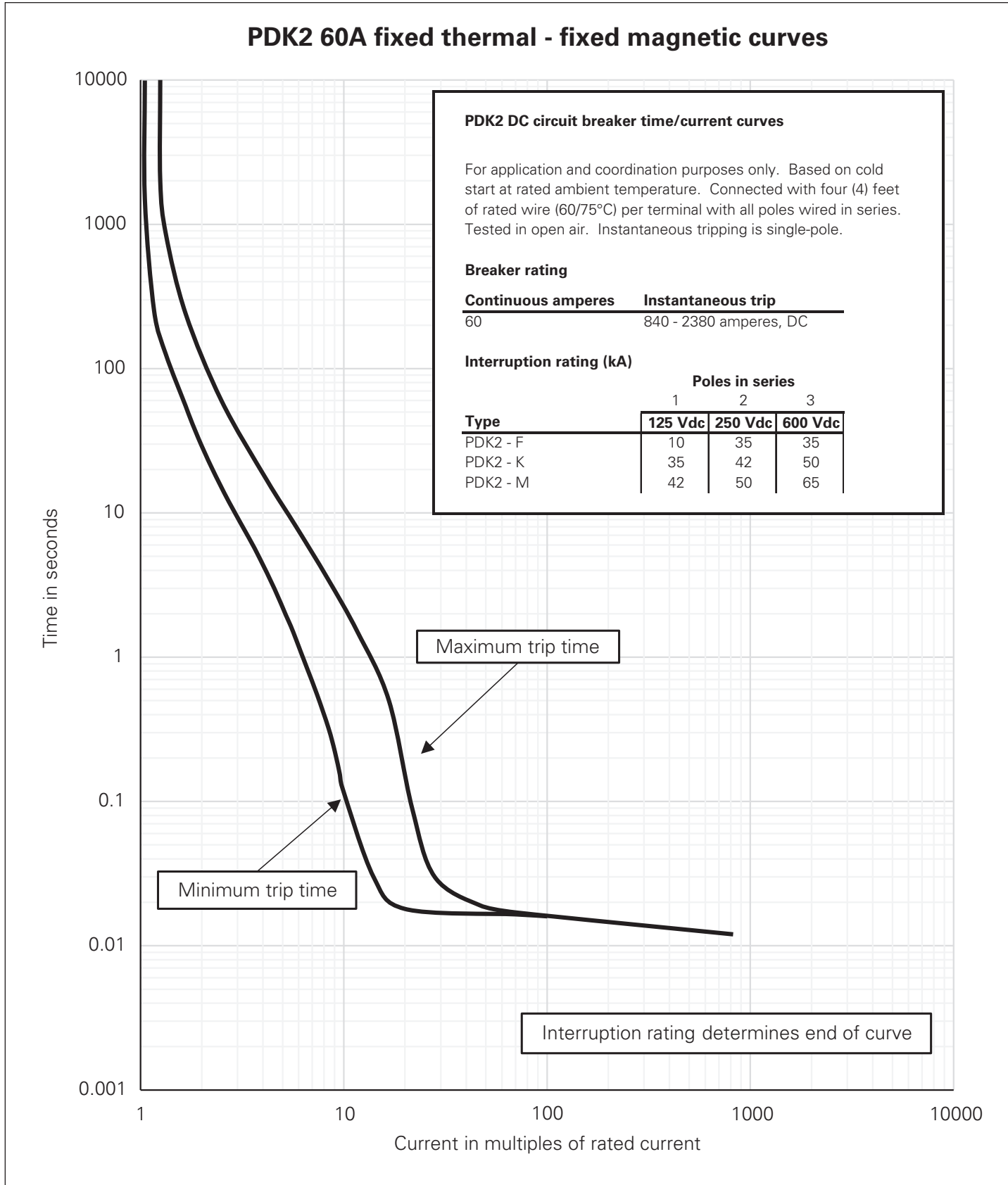


Figure 10. Type PDK2, 60 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

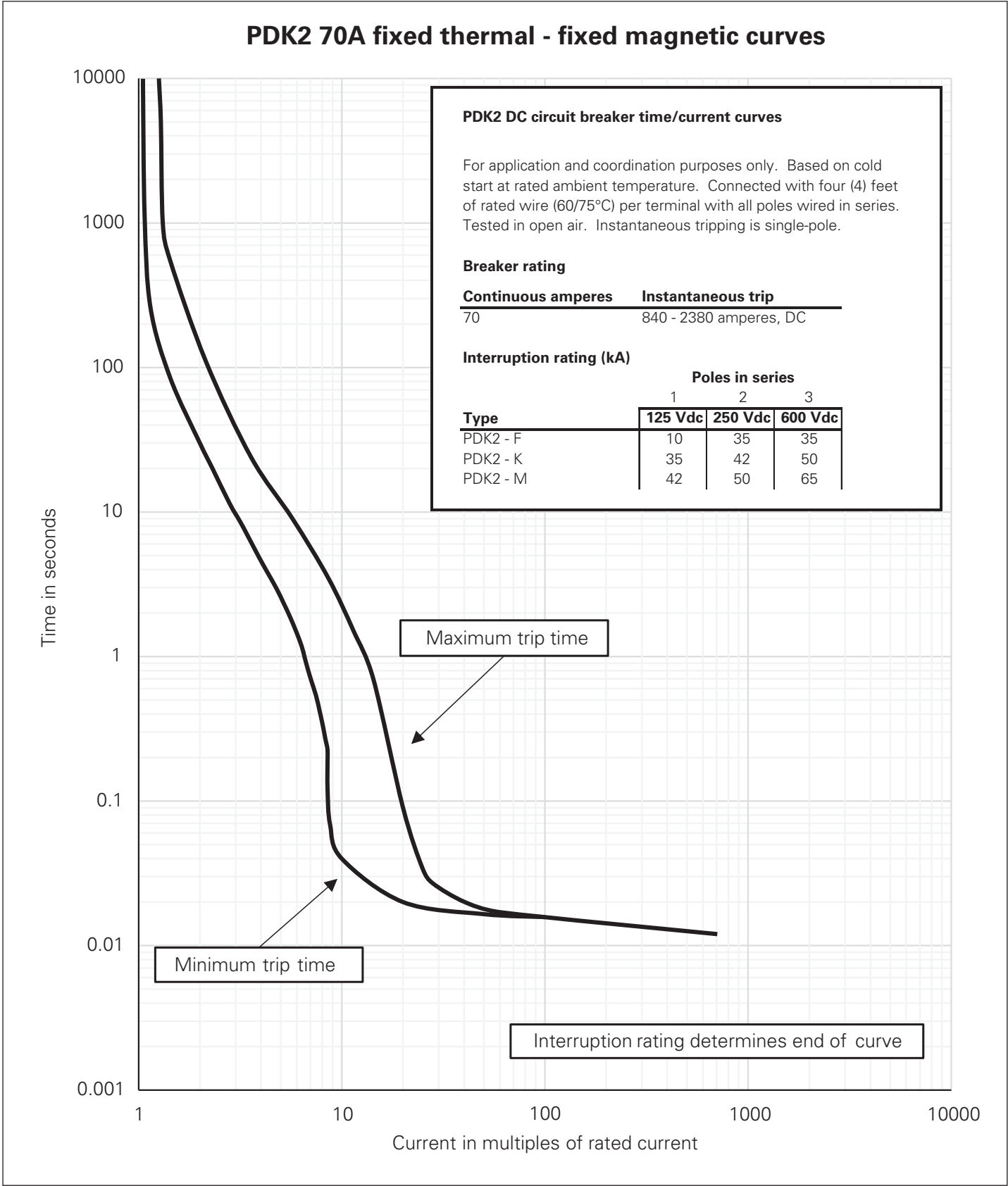


Figure 11. Type PDK2, 70 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

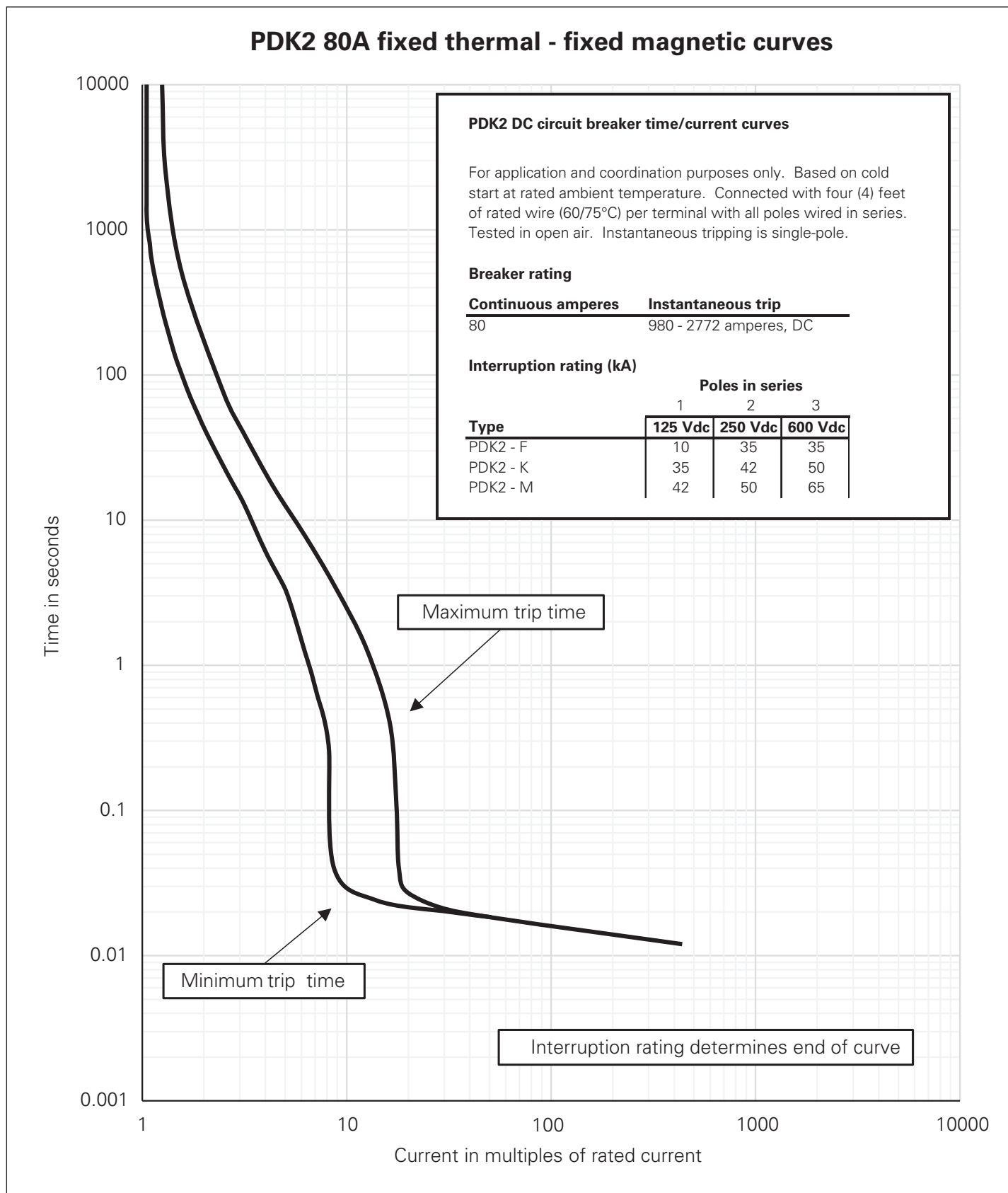


Figure 12. Type PDK2, 80 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

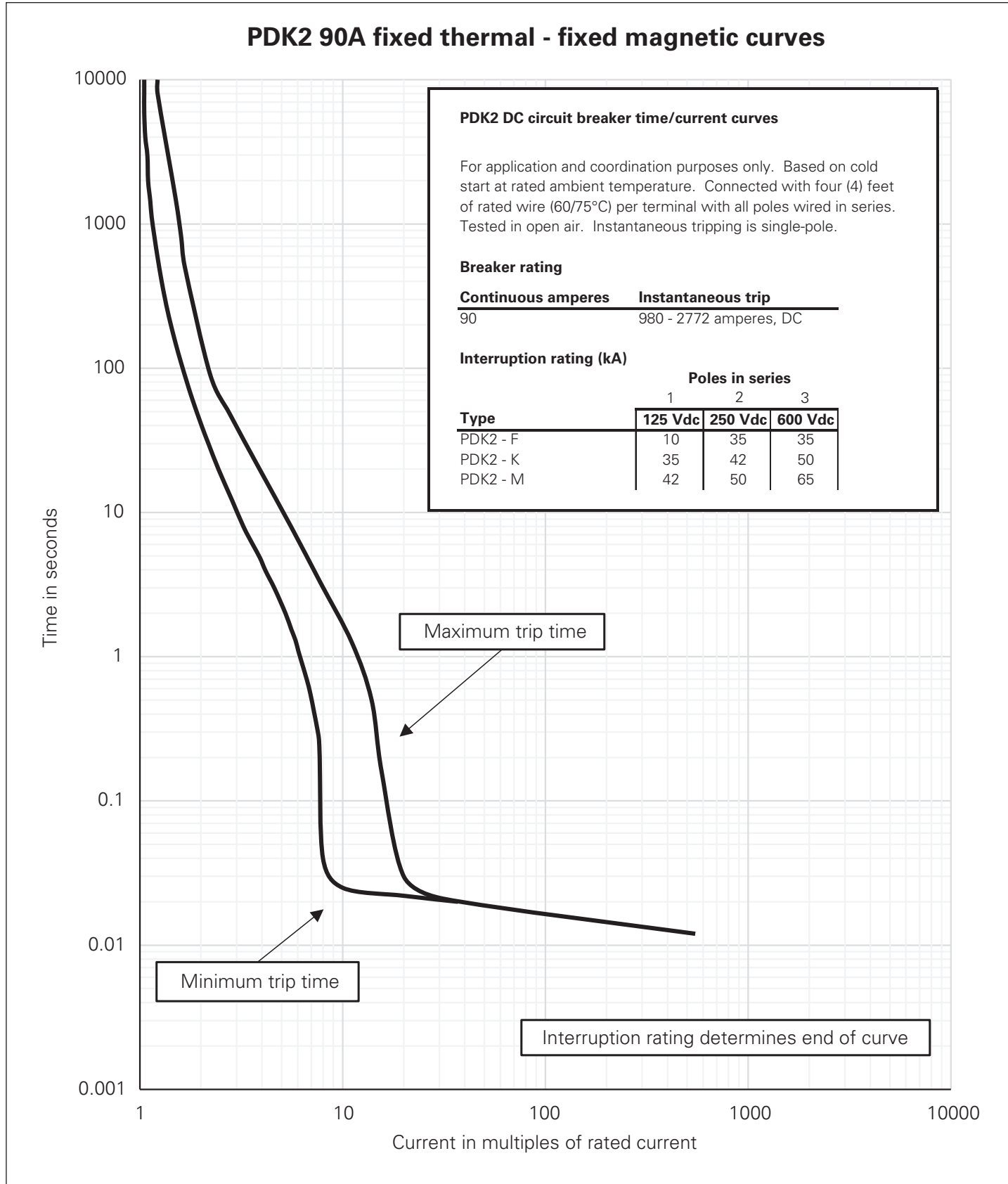


Figure 13. Type PDK2, 90 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

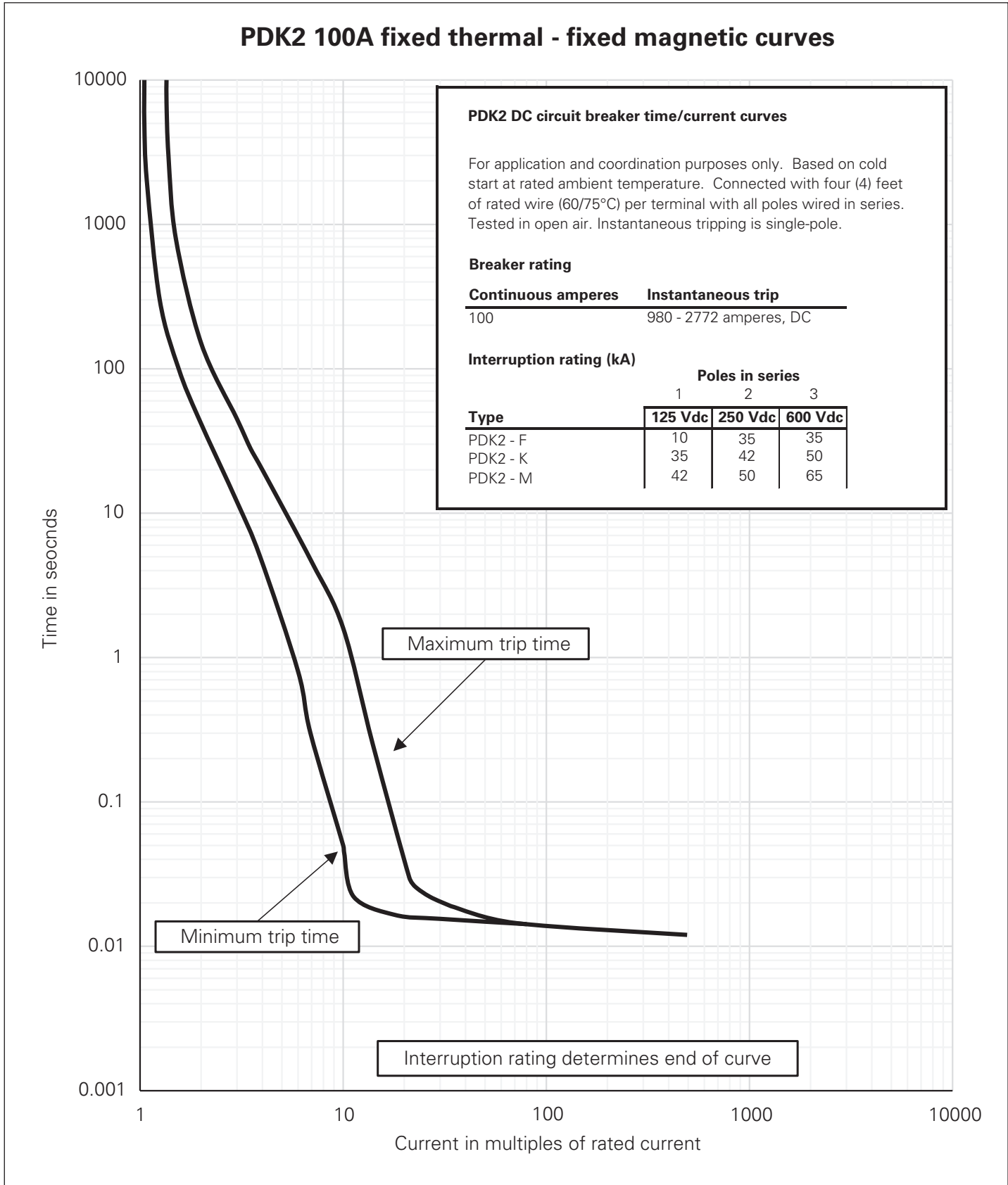


Figure 14. Type PDK2, 100 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

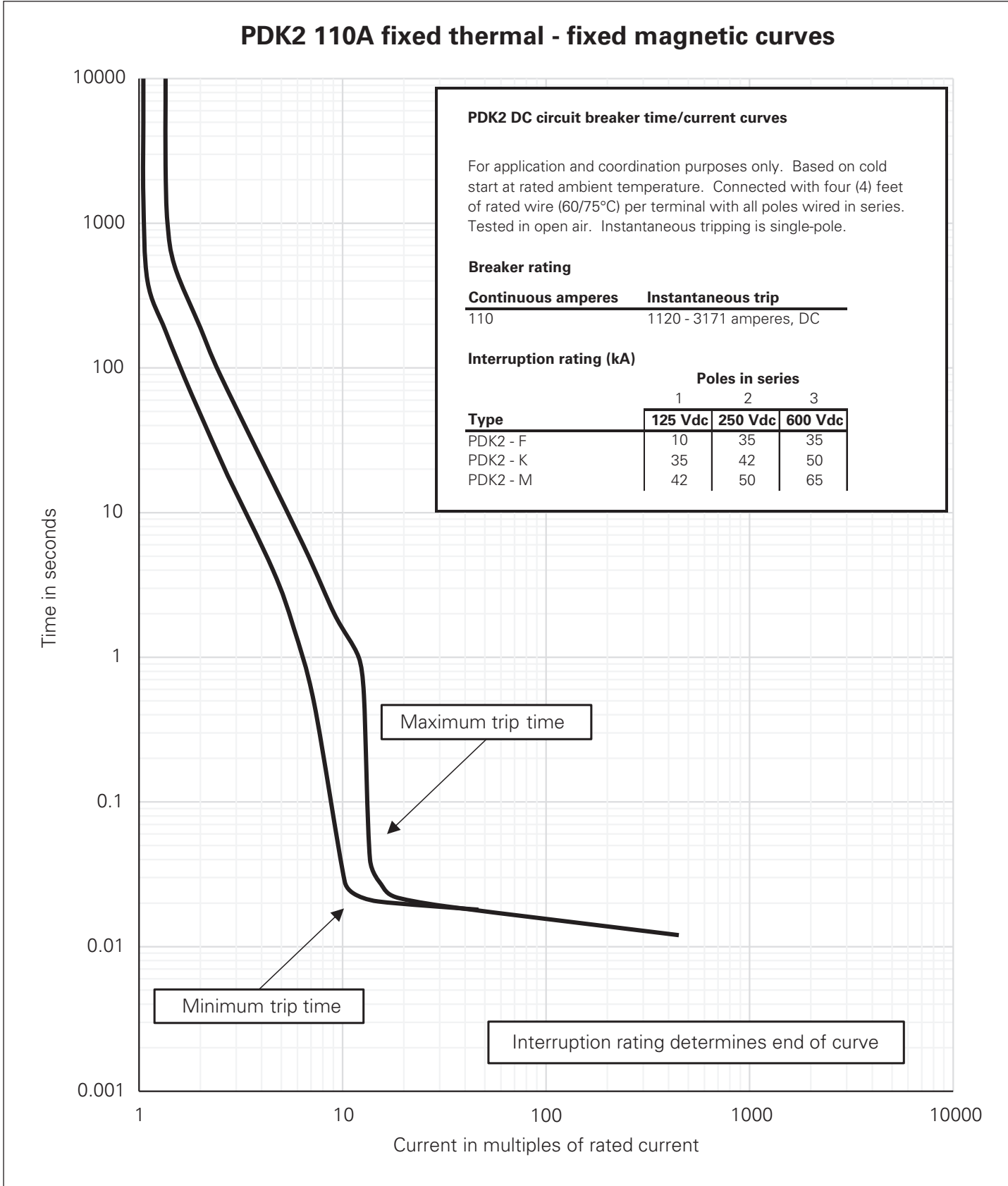


Figure 15. Type PDK2, 110 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

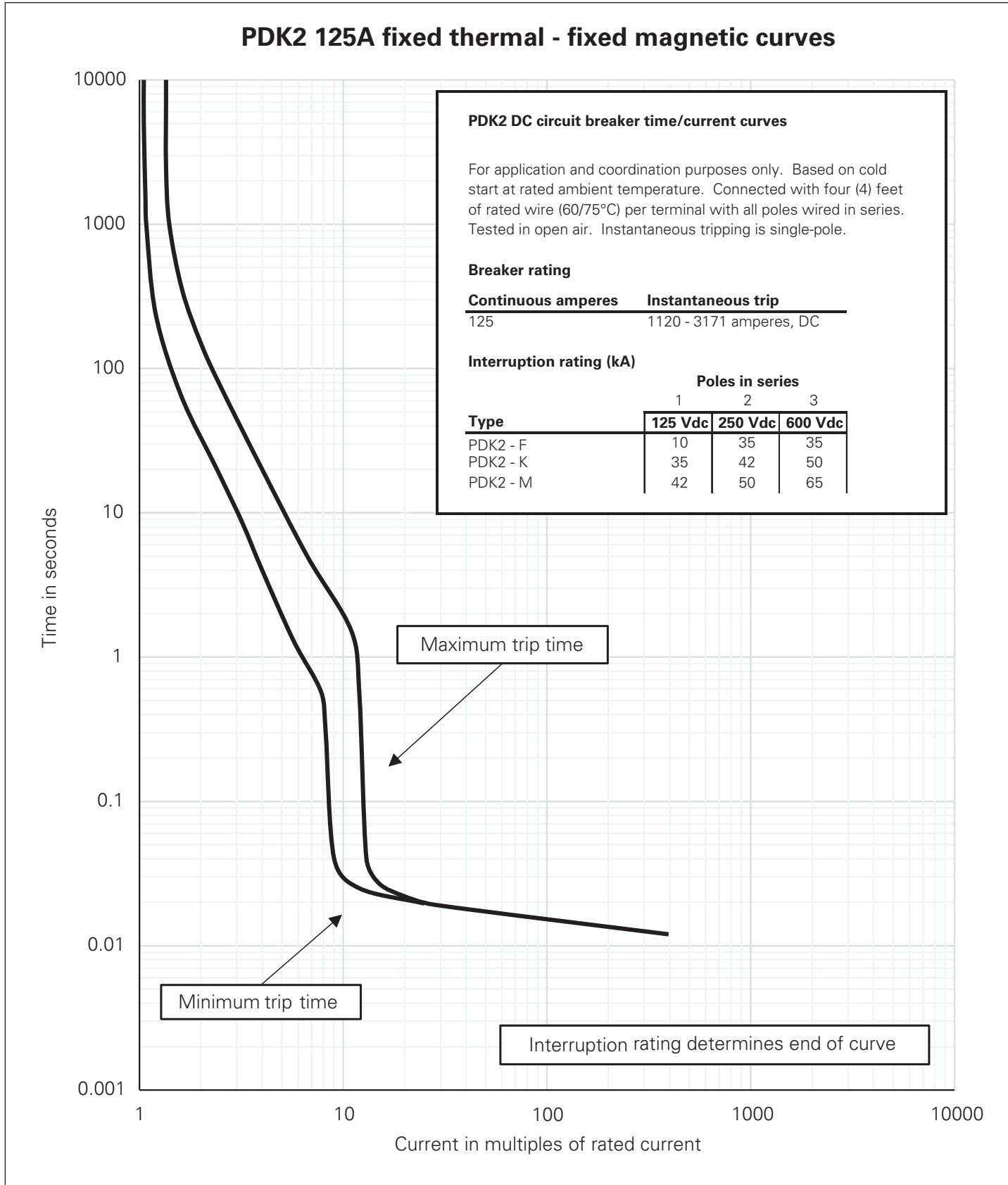


Figure 16. Type PDK2, 125 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

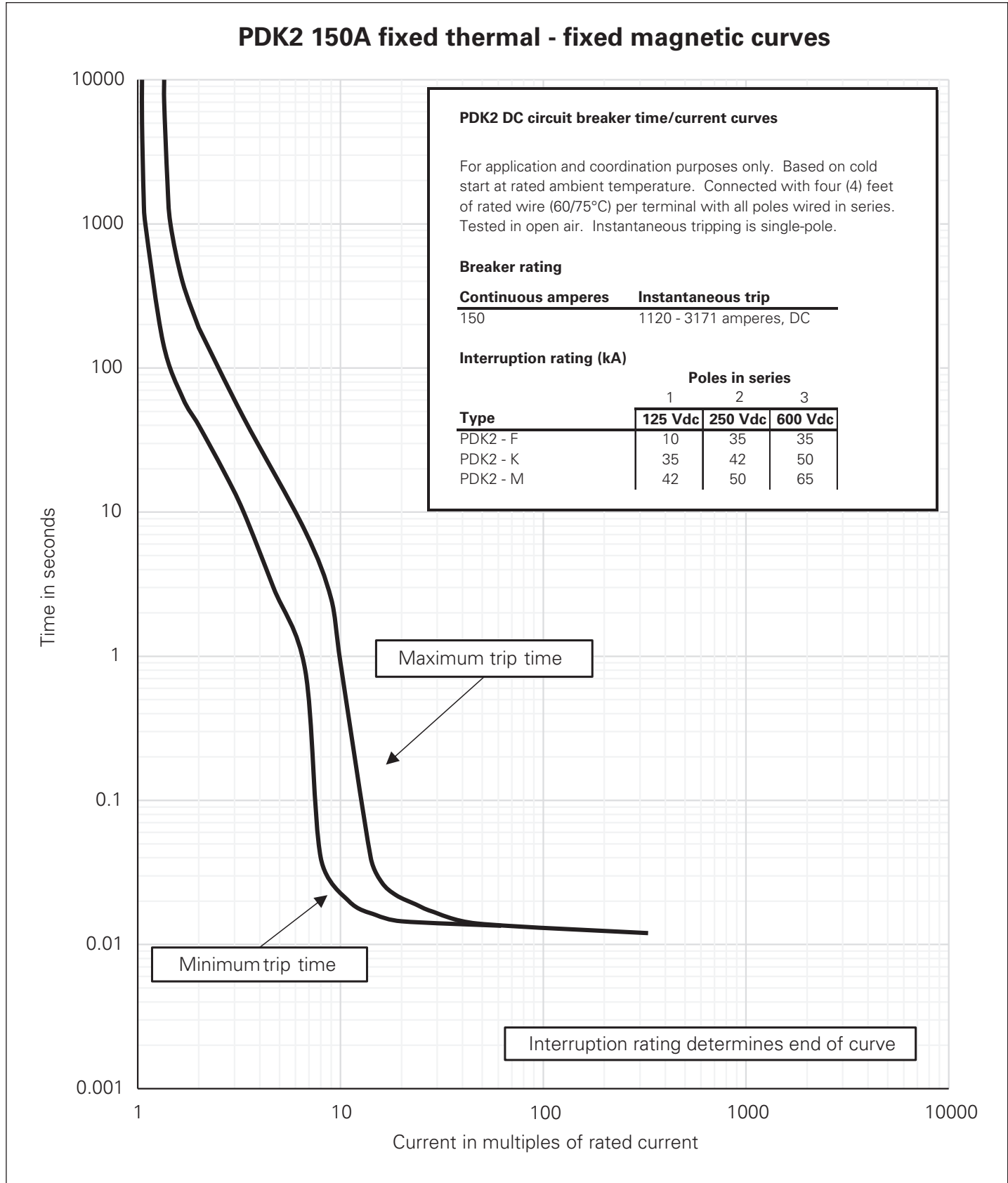


Figure 17. Type PDK2, 150 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

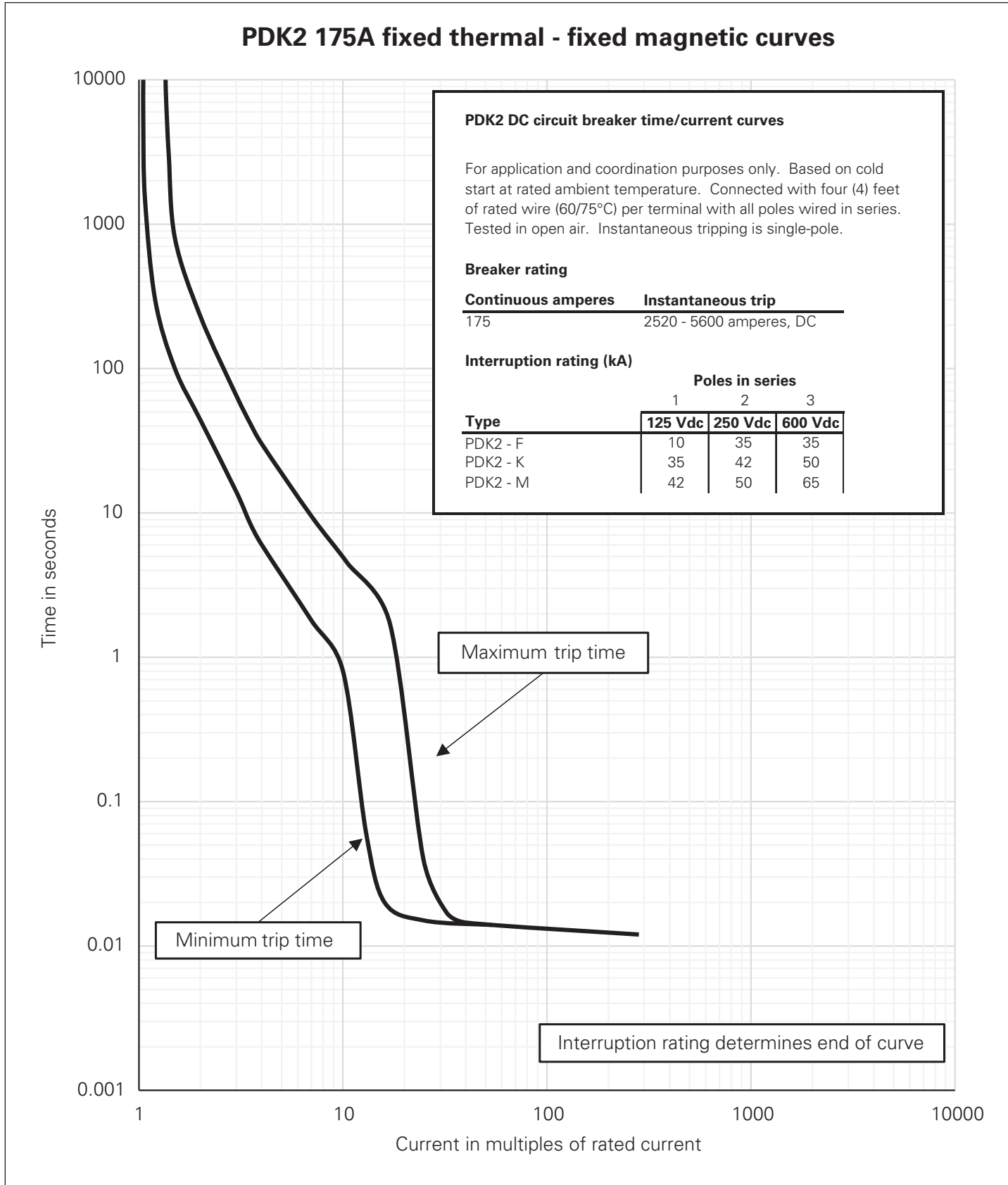


Figure 18. Type PDK2, 175 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

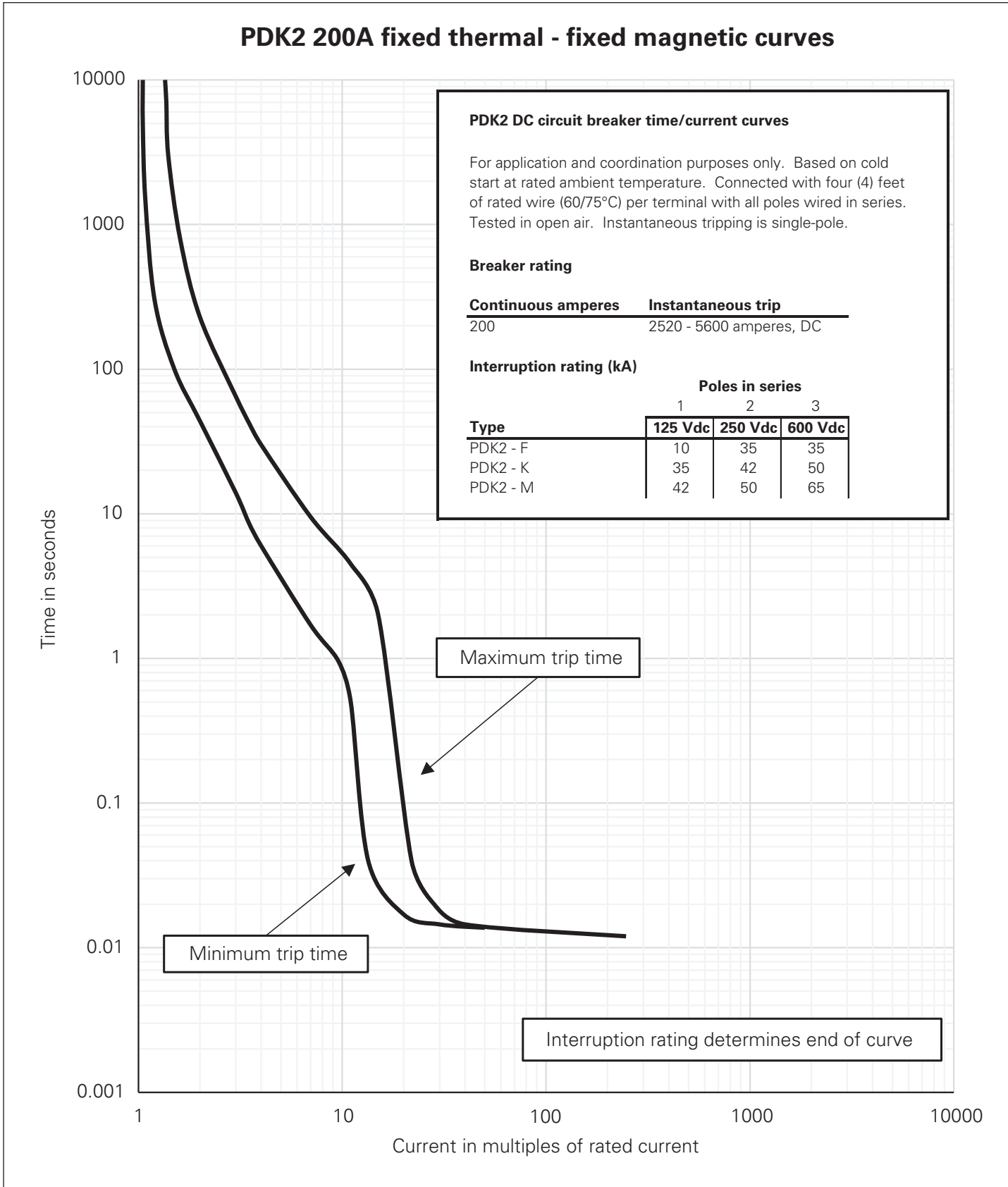


Figure 19. Type PDK2, 200 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

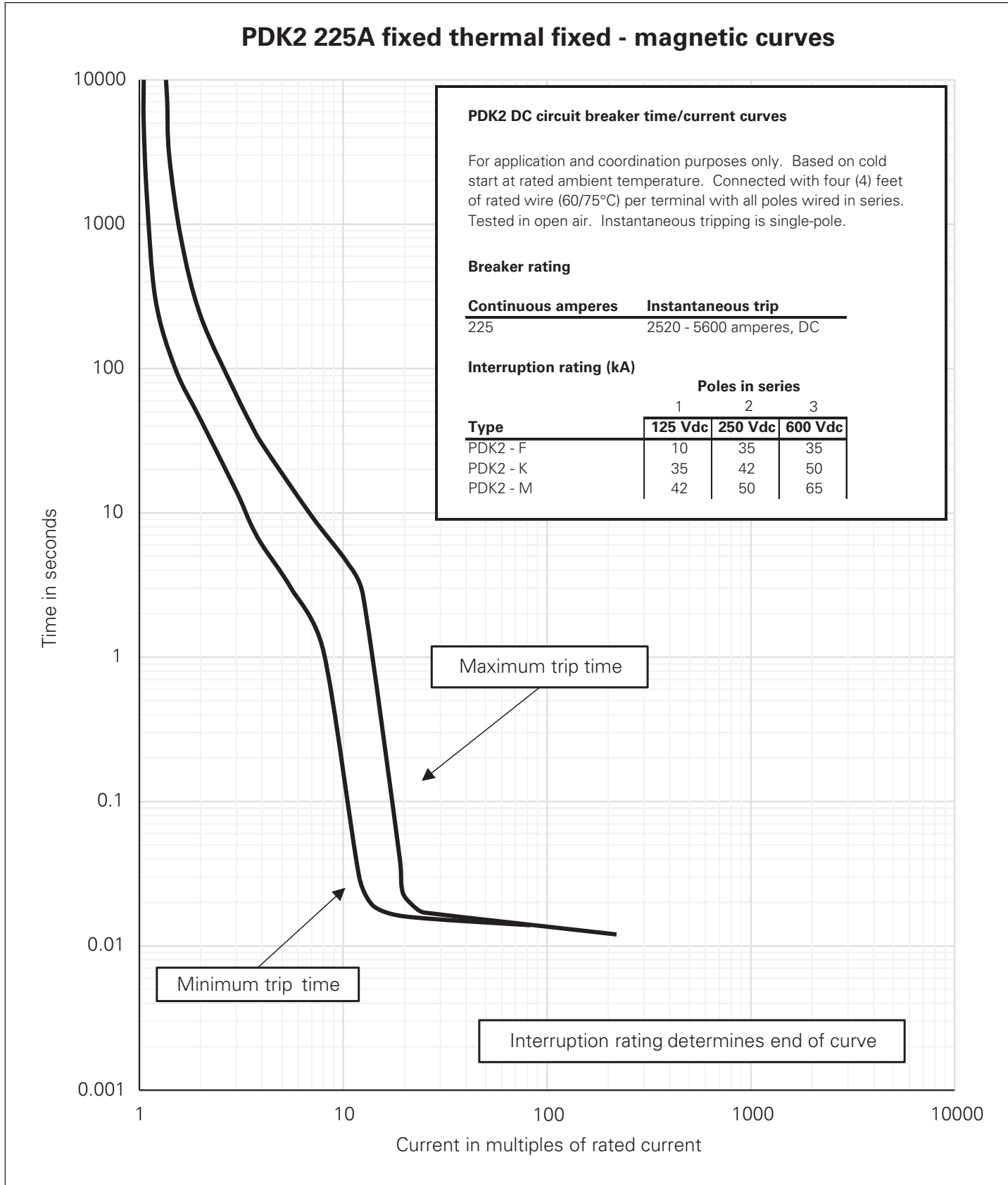


Figure 20. Type PDK2, 225 amperes, fixed thermal – fixed magnetic, curve No. TC012059EN

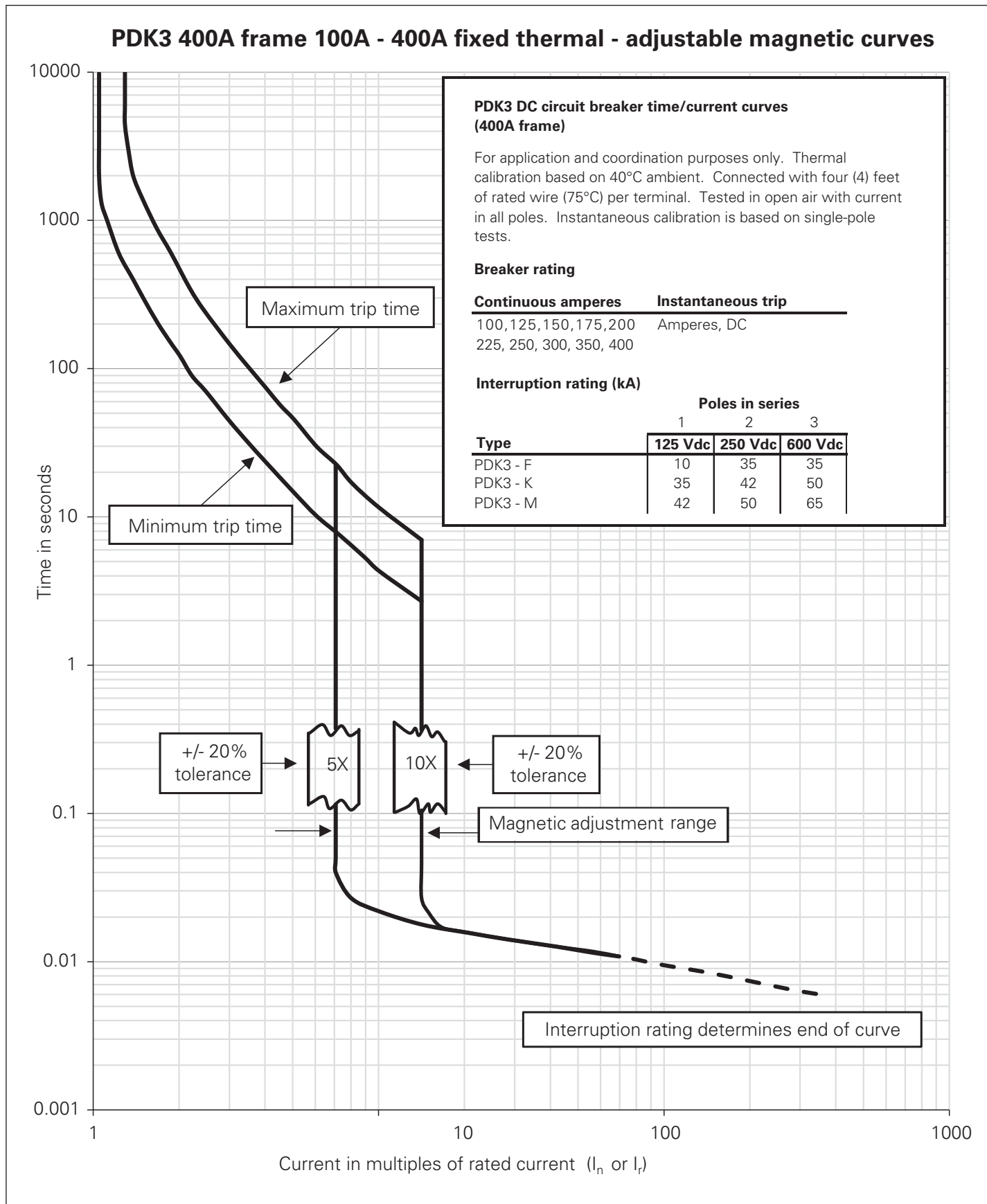


Figure 21. Type PDK3, 400A frame, 100 – 400 amperes, fixed thermal – adjustable magnetic, curve No. TC012060EN

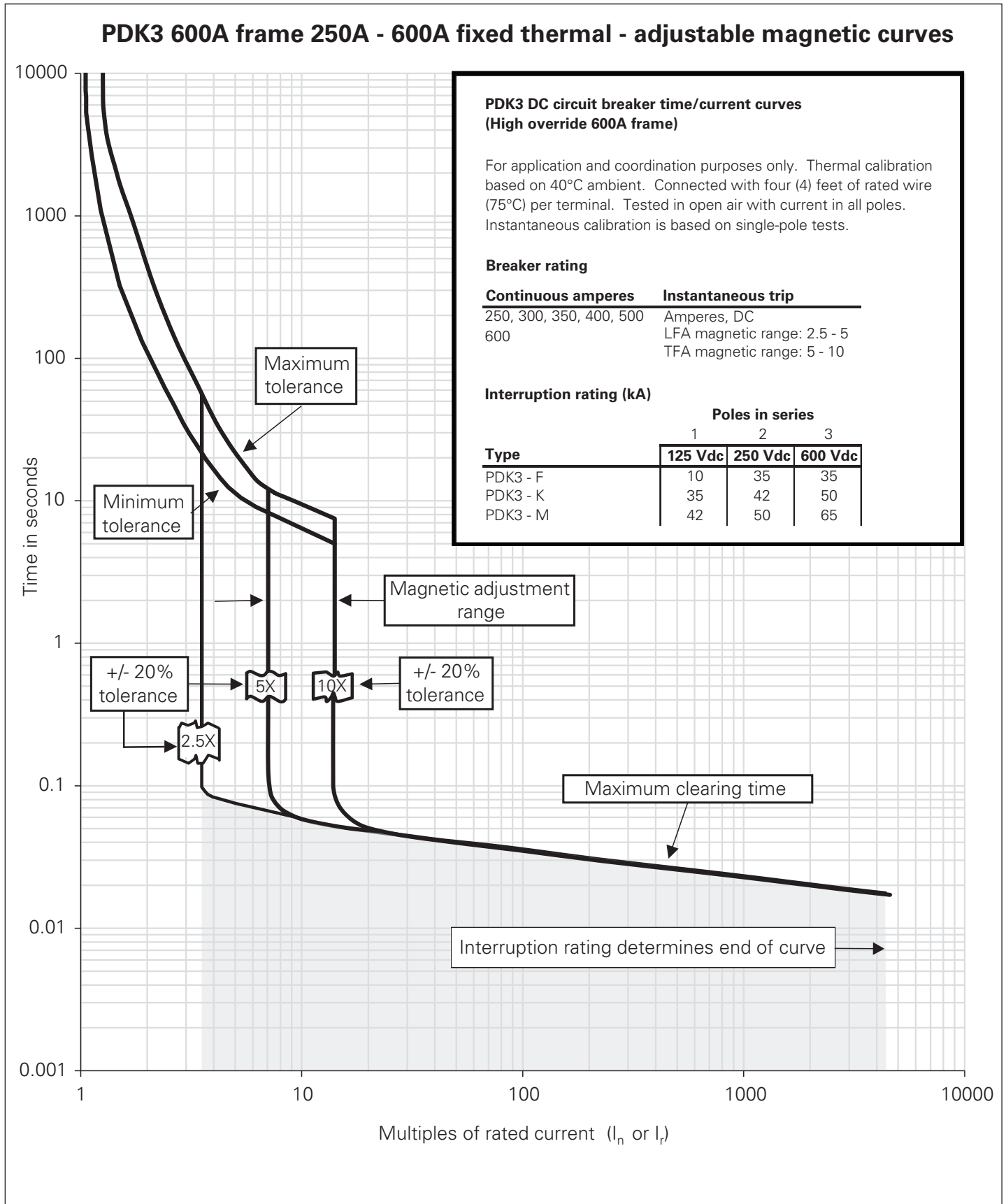


Figure 22. Type PDK3, 600A frame, 250 – 600 amperes, fixed thermal – adjustable magnetic, curve No. TC012060EN

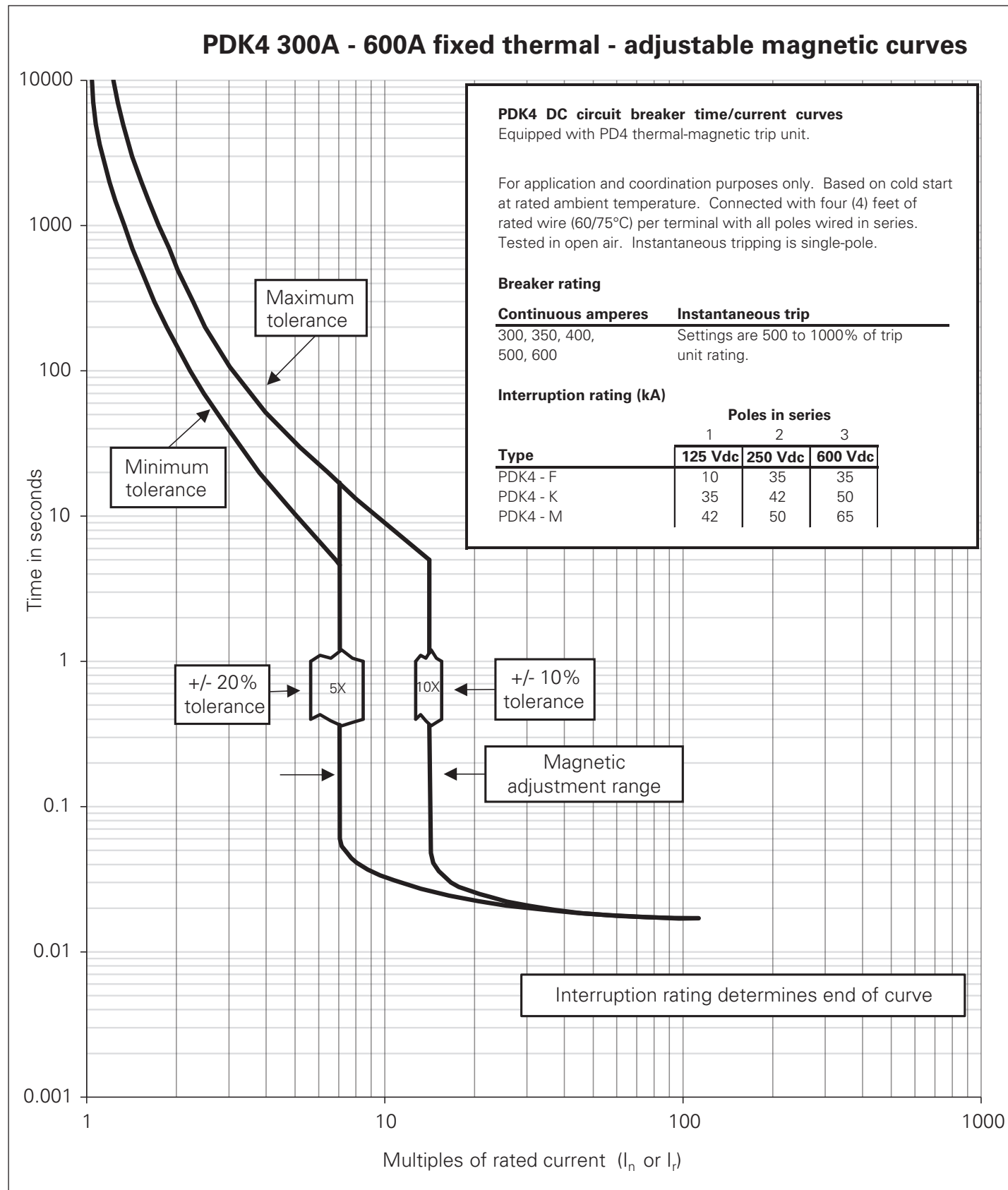


Figure 23. Type PDK4, 300 – 600 amperes, fixed thermal – adjustable magnetic, curve No. TC012061EN

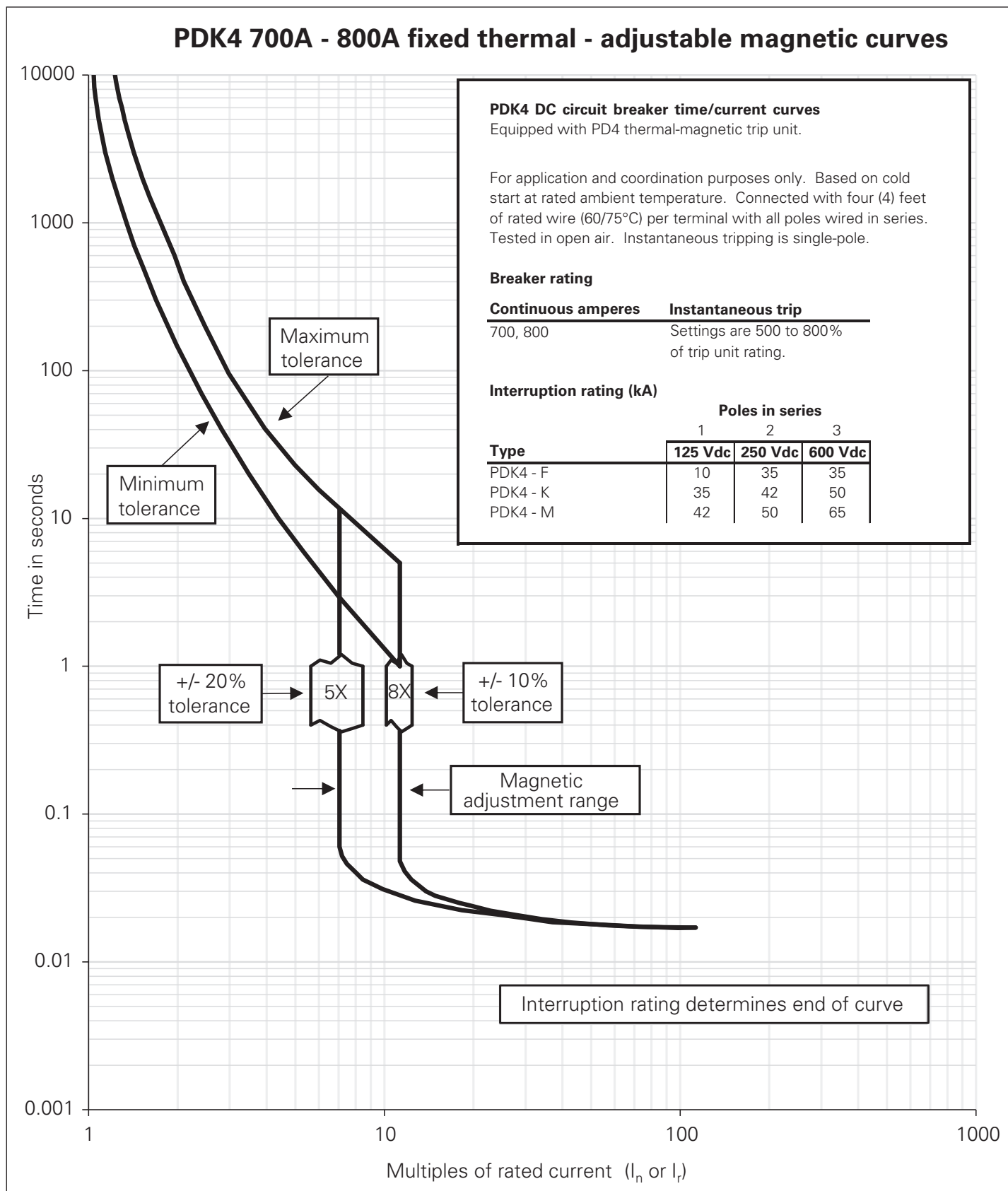


Figure 24. Type PDK4, 700 – 800 amperes, fixed thermal – adjustable magnetic, curve No. TC012061EN

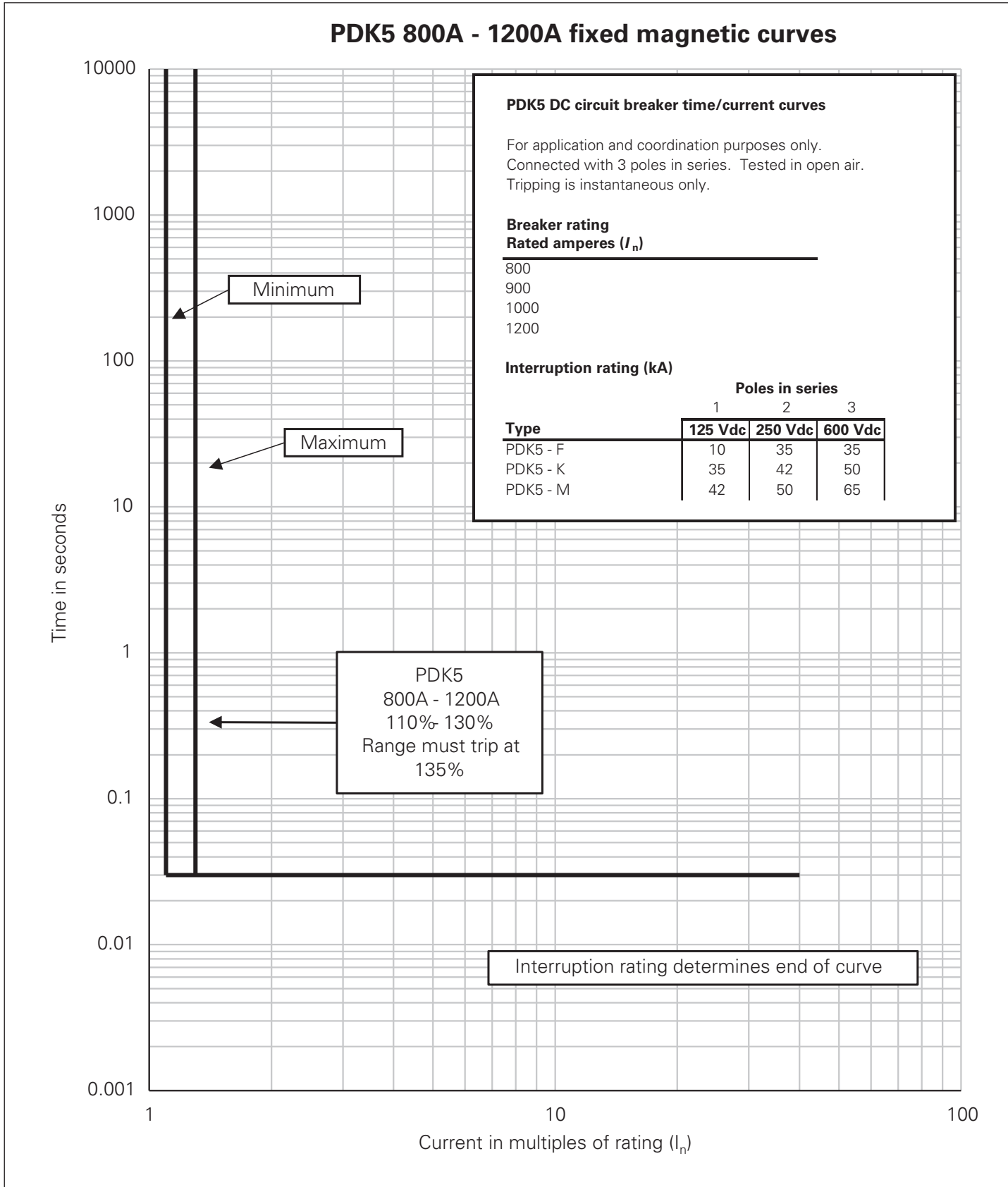


Figure 25. Type PDK5, 800 – 1200 amperes, fixed magnetic, curve No. TC012062EN

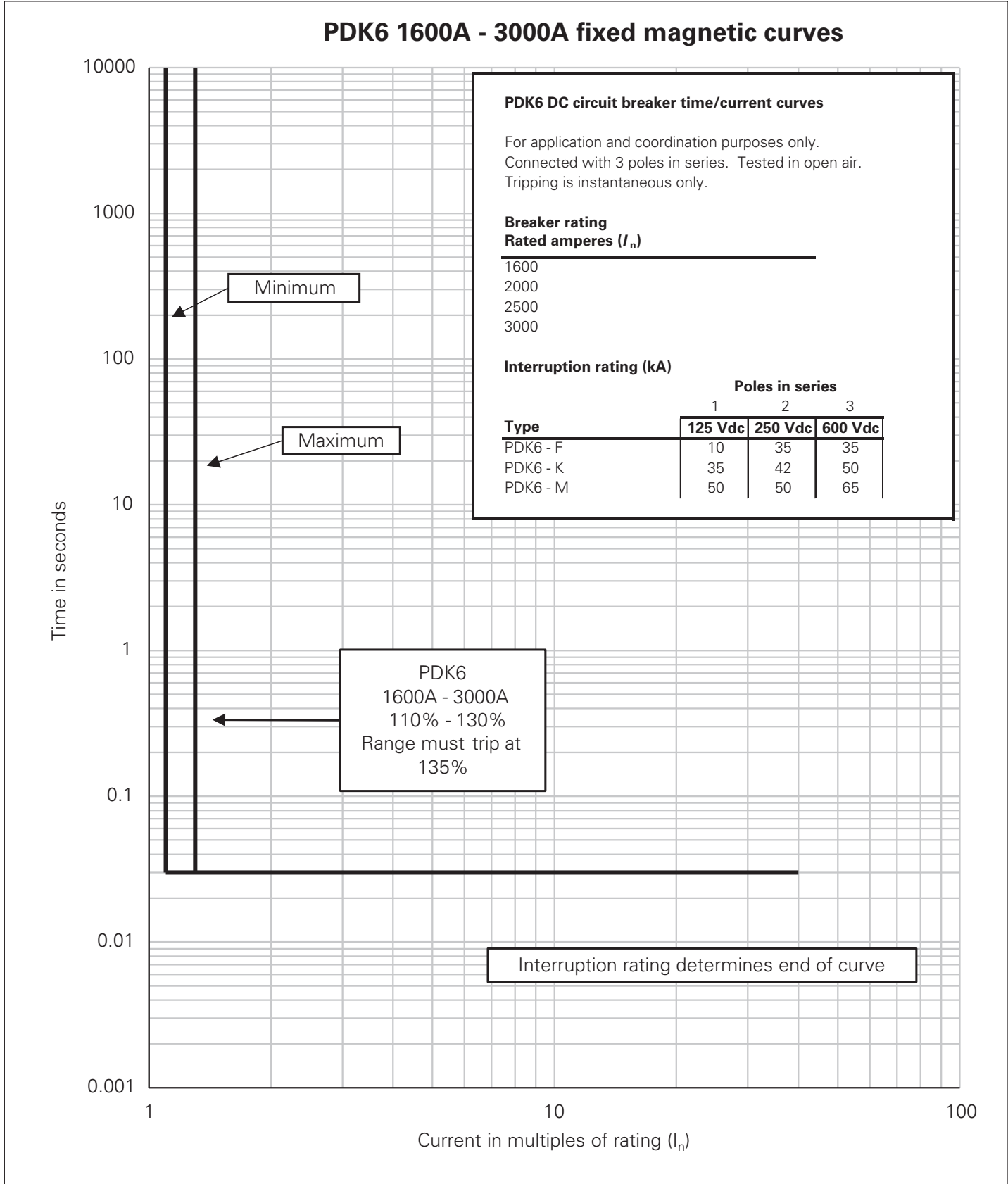


Figure 26. Type PDK6, 1600 – 3000 amperes, fixed magnetic, curve No. TC012063EN

Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
877-ETN-CARE (877-386-2273)
Eaton.com

© 2025 Eaton
All Rights Reserved
Printed in USA
Publication No. TC012057EN / TBG001672
March 2025

Eaton is a registered trademark.

All other trademarks are property of their
respective owners.