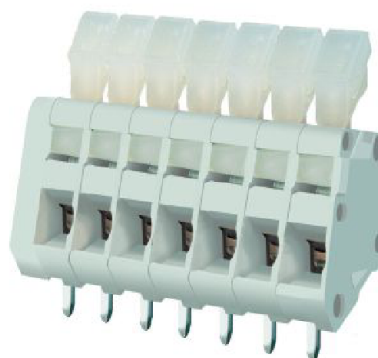


EM2802 Series**EuroMag Terminal Blocks**

30° Entry; Screwless; 2.54 Centers


SPECIFICATIONS**Rating:** 4A, 150V**Center Spacing:** 0.10" (2.54mm)**Wire Range:** #20-28 AWG**Housing Material:** Gray Polyamide Type 6/6, 94V0**Contact Material:** Tin-Plated Brass**Spring Material:** Stainless Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Recommended PCB Hole Diameters:** 0.051" (1.30mm)**Construction:** Mold-to-Length**Agency Information:**  File E62622; CE Certified

EM280207

Dimensions - mm (in)

Poles	L (mm)
2	7.08
3	9.62
4	12.16
5	14.70
6	17.24
7	19.78
8	22.32
9	24.86
10	27.40
11	29.94
12	32.48

To convert to inches, divide by 25.4

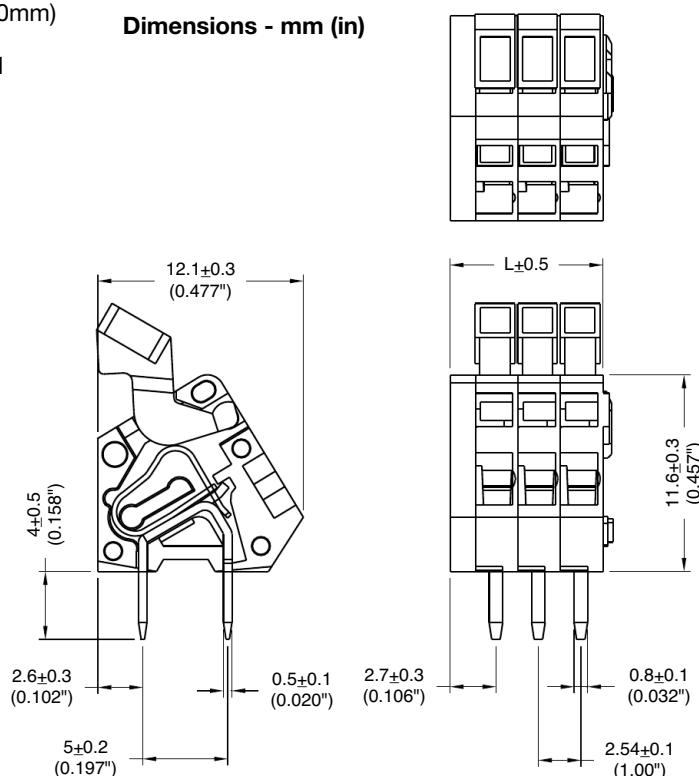**Part Numbering System****Series****# of Poles**

EM2802

□□

02 to 12

Terminal Blocks:
Single RowEuroMag Series
ScrewlessEdge Connectors,
One-Sided BoardsCompliance
References