

## EM3543 Series EuroMag Terminal Blocks

Pluggable Block (Mates with EM3593 Series);  
3.81 Centers

### SPECIFICATIONS

**Rating:** 10A, 300V

**Center Spacing:** 0.15" (3.81mm)

Consult factory for 0.30" (7.62mm)

**Wire Range:** #16-24 AWG

**Housing Material:** UL rated 94V0 Thermoplastic

**Contact Material:** Brass Tin-Plated

**Cage Material:** Brass, Nickel-Plated

**Screw Size:** M2.0 Zinc-Plated Steel

**Operating Temperature:** 105°C (221°F) max., -40°C  
(-40°F) min.

**Torque Rating:** 3.0 lb-in.


**Construction:** Mold-to-Length

**Agency Information:**  File E62622; CE Certified



EM354309

### Dimensions - mm (in)

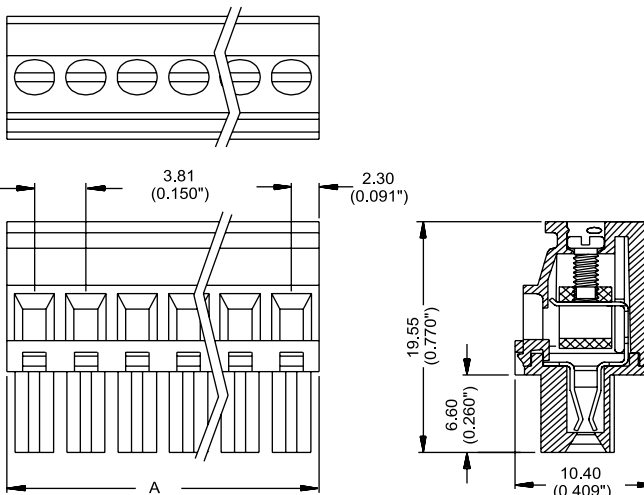

Poles	L (mm)
2	8.41
3	12.22
4	16.03
5	19.84
6	23.65
7	27.46
8	31.27
9	35.08
10	38.89
11	42.70
12	46.51

To convert to inches, divide by 25.4

## Part Numbering System

Series

# of Poles

EM3543

02 to 12

Mating Header: EM3593 pg. 81

Terminal Blocks:  
Single Row

EuroMag Series  
Plug & Header

Edge Connectors,  
One-Sided Boards

Compliance  
References