

PTC resettable devices

BUSSMANN
SERIES



Eaton's Bussmann Series PolyTron™ PTC device cross reference guide



Surface mount PTC device competitive cross reference* guide

1206 Size			
Eaton	Littelfuse	Raychem	Bourns
PTS120660V005			
PTS120660V010			
PTS120630V012	1206L012	nanoSMDC012F	MF-NSMF012
PTS120630V016	1206L016	nanoSMDC016F	
PTS120624V020	1206L020	nanoSMDC020F	MF-NSMF020
PTS120616V025	1206L25		
PTS120616V035	1206L035/16	nanoSMDC035F	MF-NSMF035
PTS12066V050	1206L050		
PTS120615V050	1206L050/15	nanoSMDC50F/13.2	MF-NSMF050
PTS12066V075	1206L075TH	nanoSMDC075F	MF-NSMF075
PTS12066V100			
PTS12066V110	1206L110TH	nanoSMDC110F	MF-NSMF110
PTS12066V150	1206L150TH	nanoSMDC150F	MF-NSMF150
PTS12066V200	1206L200	nanoSMDC200F	MF-NSMF200

1812 Size			
Eaton	Littelfuse	Raychem	Bourns
PTS181230V010	1812L010	miniSMDC010F	MF-MSMF010
PTS181260V014	1812L014	miniSMDC014F	MF-MSMF014
PTS181230V020	1812L020	miniSMDC020F	MF-MSMF020
PTS181216V035	1812L035/30	miniSMDC030F	MF-MSMF035
PTS181216V050	1812L050	miniSMDC050F	MF-MSMF050
PTS181213V075	1812L075	miniSMDC075F	MF-MSMF075
PTS181224V075	1812L075/24	miniSMDC075F/24	MF-MSMF075/24
PTS181233V075	1812L075/33		
PTS18128V110	1812L110	miniSMDC110F	MF-MSMF110
PTS181216V110	1812L110/16	miniSMDC110F/16	MF-MSMF010/16
PTS181224V110	1812L110/24	miniSMDC110F/24	MF-MSMF010/24X
PTS181216V125	1812L125/16	miniSMDC125F/16	
PTS18126V125	1812L125/6	miniSMDC125F	MF-MSMF125
PTS18128V150	1812L150	miniSMDC150F	MF-MSMF150
PTS181212V150	1812L150/12	miniSMDC150F/12	
PTS181224V150	1812L150/24	miniSMDC150F/24	MF-MSMF150/24X
PTS18128V160	1812L160	miniSMDC160F	MF-MSMF160
PTS18128V200	1812L200TH	miniSMDC200F	
PTS18126V260	1812L260TH	miniSMDC260F	MF-MSMF260
PTS18126V300	1812L300	miniSMDC300F	




Powering Business Worldwide

* Cross references shown may differ in specific electrical properties and performance characteristics.

Radial lead PTC device competitive cross reference* guide

16 Volt			
Eaton†	Littelfuse	Raychem	Bourns
PTR016V0090	16R090B	RUSBF090	
PTR016V0110	16R110B	RUSBF110	
PTR016V0135	16R135B	RUSBF135	
PTR016V0160	16R160B	RUSBF160	
PTR016V0185	16R185B	RUSBF185	
PTR016V0250	16R250G	RGEF250	
PTR016V0300	16R300G	RGEF300	MF-RG300
PTR016V0400	16R400G	RGEF400	MF-RG400
PTR016V0500	16R500G	RGEF500	MF-RG500
PTR016V0600	16R600G	RGEF600	MF-RG600
PTR016V0700	16R700G	RGEF700	MF-RG700
PTR016V0800	16R800G	RGEF800	MF-RG800
PTR016V0900	16R900G	RGEF900	MF-RG900
PTR016V1000	16R1000G	RGEF1000	MF-RG1000
PTR016V1100	16R1100G	RGEF1100	MF-RG1100
PTR016V1200	16R1200G	RGEF1200	MF-RG1200
PTR016V1300			
PTR016V1400	16R1400G	RGEF1400	MF-RG1400
PTR016V1500			

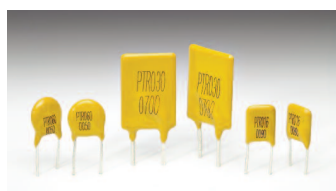

† Basic part number excluding available lead and package code suffixes as follows:

- -TR, Straight leads on a reel
- -TR1, Kinked leads on a reel
- -BK, Straight leads in a poly bag
- -BK1, Kinked leads in a poly bag

30 Volt			
Eaton†	Littelfuse	Raychem	Bourns
PTR030V0090	30R090	RUEF090	MF-R090-0-09
PTR030V0110	30R110	RUEF110	MF-R110
PTR030V0135	30R135	RUEF135	MF-R135
PTR030V0160	30R160	RUEF160	MF-R160
PTR030V0185	30R185	RUEF185	MF-R185
PTR030V0250	30R250	RUEF250	MF-R250
PTR030V0300	30R300	RUEF300	MF-R300
PTR030V0400	30R400	RUEF400	MF-R400
PTR030V0500	30R500	RUEF500	MF-R500
PTR030V0600	30R600	RUEF600	MF-R600
PTR030V0700	30R700	RUEF700	MF-R700
PTR030V0800	30R800	RUEF800	MF-R800
PTR030V0900	30R900	RUEF900	MF-R900

60 Volt			
Eaton†	Littelfuse	Raychem	Bourns
PTR060V0010	60R010	RXEF010	MF-R010
PTR060V0017	60R017	RXEF017	MF-R017
PTR060V0020	60R020	RXEF020	MF-R020
PTR060V0025	60R025	RXEF025	MF-R025
PTR060V0030	60R030	RXEF030	MF-R030
PTR060V0040	60R040	RXEF040	MF-R040
PTR060V0050	60R050	RXEF050	MF-R050
PTR060V0065	60R065	RXEF065	MF-R065
PTR060V0075	60R075	RXEF075	MF-R075
PTR060V0090	60R090	RXEF090	MF-R090
PTR060V0110	60R110	RXEF110	MF-RX110
PTR060V0135	60R135	RXEF135	MF-RX135
PTR060V0160	60R160	RXEF160	MF-RX160
PTR060V0185	60R185	RXEF185	MF-RX185
PTR060V0250	60R250	RXEF250	MF-RX250
PTR060V0300	60R300	RXEF300	MF-RX300
PTR060V0375	60R375	RXEF375	MF-RX375

* Cross references shown may differ in specific electrical properties and performance characteristics.

Technical Application Assistance

Call 636-527-1270

E-mail fusetech@eaton.com

Data Sheets: www.eaton.com/electronics

Order samples on-line: <https://tools.eatonelectronics.com/request-form>

Eaton
Electronics Division
 1000 Eaton Boulevard
 Cleveland, OH 44122
 United States
www.eaton.com/electronics

© 2017 Eaton
 All Rights Reserved
 Printed in USA
 Publication No. PA4071
 December 2017

EATON
 Powering Business Worldwide

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

For more information visit:
www.eaton.com/fuses