


AC trafo

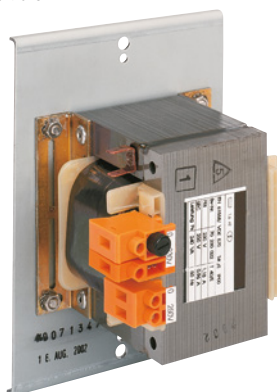

AC trafo

- For mains supply to internal modules
- DEKRA system certification documents product quality and compliance with standards for the entire system
- Functionality for 30 minutes in the event of fire verified in a fire test conducted by an independent materials testing institute
- Conforms to with RoHS and REACH

Degree of protection	IP20
Protection class	II
Ambient temperature range	0°C – +55°C
Relative humidity	10% – 95%, non-condensing
Air pressure	795...1080 hPa
Height	≤ 2000 m
Pollution level	2

Order details

Model	Included with delivery	Order no.
AC trafo	Transformer module AC/AC converter 240VA including mounting adapter for top-hat rail installation	40071347162

