

- Unit with innovative LED technology
- Lithium Batteries 10 years
- Selectable autonomy of 1h, 3h and 8h
- Wall, ceiling, suspension
- Version 20m and 30m visibility
- Available for ceiling mounting and recessed applications

Light Source:

LED strip

Materials:

Polycarbonate

Operation:

Maintained (M)

Adjustable brightness function, standing at 100 % at 1 h; 45 % at 3 h; 25 % at 5 h; 18 % at 8 h

Duration selectable 1h, 3h and 8h

Installation possibilities: Wall, ceiling, recessed, suspended

Maintenance costs reduced, no replacement of spare-parts needed for 10 years

Applications:

Hotels, restaurants, meeting rooms, offices, shops, cinemas, theaters, museums

CrystalWay is a new range of aesthetics self-contained luminaires which fully comply with the latest regulatory requirements and standards.

Its pure forms, the perfectly homogeneous illumination of the pictogram, the small housing and flexible mounting options ensure that CrystalWay's design for an evacuation device is perfect for any project.

Indeed, it can be integrated harmoniously within the architecture of the building, whether it is a large facility (airport, concert hall, etc.) or a smaller one (retail store, sales office, etc.).

The use of LEDs, low consumption, long life components, automatic testing and monitoring devices (CGLine+) significantly reduce the operating and maintenance costs of the installation.

The CrystalWay devices have benefited from an eco-design in order to meet the latest environmental standards.

All devices are supplied with all the accessories and pictograms for a wall or ceiling mounting with single sided signage and most of the usual double sided signage configurations. Consequently, the management of supplies and inventory as well as the necessary studies have been simplified considerably.

The CrystalWay range has been developed to optimize the installation of the products whilst ensuring a flawless finish.




New :


It is now possible to use an Eaton magnet (part number: 40071352379) in order to:

- carry out manual tests
- configure the level of light output in mains mode (30%, 70% or 100%)


Viewing distance

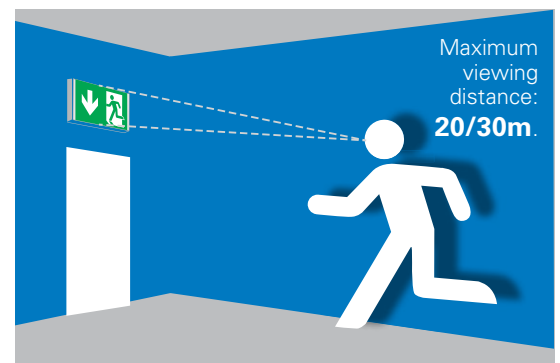


**CrystalWay 20m
Wall-surface mounting**

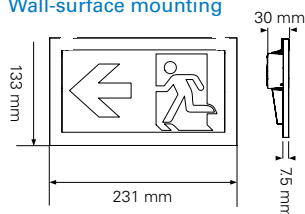


Ceiling-surface mounting 20m

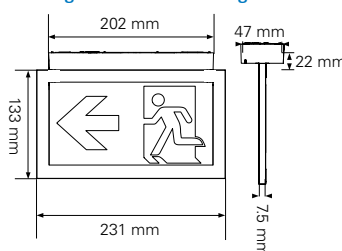

**CrystalWay 30m
Wall-surface mounting**

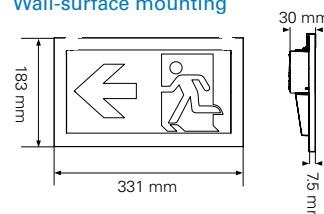

Ceiling-surface mounting 30m

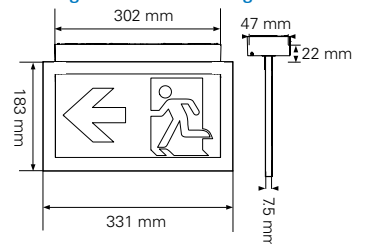

7.5.1

Exit signs - Indoor CrystalWay

Emergency lighting

Ceiling-surface mounting



Recessed mounting option



Suspension kit option



Flag mounting



Wall-surface mounting



Order code	Description	*	⌚	🔋	⚙️	
LUM17122U	CrystalWay 20m CGLine+ 4 Exit legends**	0.45W	2.3W	1-3-5-8h	3.6V-0.6 Ah Li-Ion	Maintained / Non Maintained
LUM17124U	CrystalWay 30m CGLine+ 4 Exit legends**	0.7W	4W	1-3-5-8h	3.6V-1.2 Ah Li-Ion	Maintained / Non Maintained
40071777000	CrystalWay 19821 CGLine+ IA	2.3W	4.1W	1-3-5-8h	3.6V-1.2 Ah Li-Ion	Maintained / Non Maintained
40071777001	CrystalWay 19822 CGLine+ IA	2.5W	5.8W	1-3-5-8h	3.6V-1.2 Ah Li-Ion	Maintained / Non Maintained
LUM22212U	CrystalWay 230V Mains Slave 20m viewing distance					
LUM22214U	CrystalWay 220/230V Mains Slave CG-S 20m viewing distance					
LUM22213U	CrystalWay 230V Mains Slave 30m viewing distance					
LUM22215U	CrystalWay 230V Mains Slave CG-S 30m viewing distance					

*50cd - 500cd

** Exit legends : ISO format - Right, left, down, up

Accessories

CrystalWay 20 m	CrystalWay 30m	Description	
40071352379	40071352379	Magnet	
LUM10560	LUM10560	Wire suspension kit	
LUM10561	LUM10562	Recessed base	
LUM10563	LUM10564	Recessed base with cover	
LUM10563S	LUM10564S	Recessed base with cover for suspension kit	
LUM10565	LUM10566	Recessed box for concrete	
LUM10567		Base for optional cable access	
LUM10573	LUM10587	Pictogram Arrow DOWN, ISO	
LUM10574	LUM10588	Pictogram Arrow LEFT, ISO	
LUM10575	LUM10589	Pictogram Arrow RIGHT, ISO	
LUM10577	LUM10591	Pictogram Arrow UP, ISO	
LUM10584	LUM10592	Vertical pictogram Arrow DOWN, ISO	
LUM10585	LUM10593	Vertical pictogram Arrow LEFT, ISO	
LUM10586	LUM10594	Vertical pictogram Arrow RIGHT, ISO	

Spare parts

Order code	Description
LUM10568	Battery pack Li-Ion 3.6 V/650 mAh for CrystalWay 20m
LUM10569	Battery pack Li-Ion 3.6 V/1300 mAh for CrystalWay 30m
LUM10570	Diffuser kit 24 LEDs for CrystalWay 20m
LUM10571	Diffuser kit 38 LEDs for CrystalWay 30m
LUM10572	Set of 4 hooks for CrystalWay 20m & CrystalWay 30m diffusers

