

Radio door contact



Grade2, radio door contact with configurable second radio channel with wired inputs. For use with HUA (PA), door contact, key switch or other voltage free device. Compact unit with replaceable CR2 lithium battery.

At a glance...

- Choice of finishes for installation on wood or pvc
- Independently certified to EN50131
- Flexible installation choices
- Compatible with radio panels or panels fitted with a radio expander

Available in Brown or White




Powering Business Worldwide

Scantronic product data sheet

Product specification

Product code	734rEUR-00	734rEUR-01	734rEUR-05	734rEUR-06
Free space radio range (M)	800			
Enclosure material	Plastic			
Colour	White		Brown	
Battery type	3V CR123			
Wired input type	CC	FSL	CC	FSL
Typical battery life	14 months			
Environmental class	Class II			
EN 50131 grade	2			
Operating Frequency	868.6625 MHz			
Tamper protection	Yes			
Compliance	Certified to EN50131-2-6			
Dimensions	88mm x 33mm x 27mm			

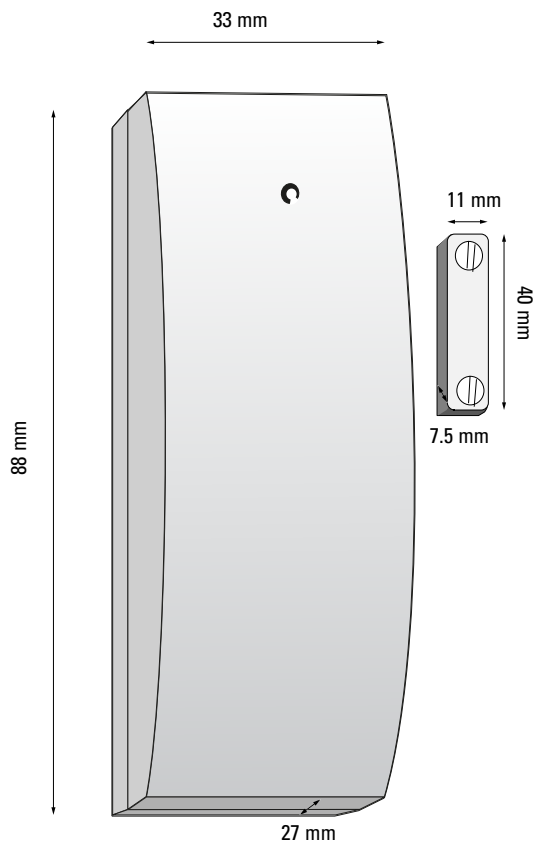

Compare product compatibility with our easy to read chart: www.eaton.com/security-works-with