

MODELS:

# SRW26USDP / SRW26USDPG

## SmartRack® Wall-Mount UPS-Depth Rack Enclosure Cabinets



26 Rack Units



250 lb. Load Rating



Sturdy Steel Construction



Locking Doors & Side Panels



Clear Acrylic Front Window (SRW26USDPG only)



Hinged Wall Bracket



Standard 19" Rack Width



Convenient Cable Access



Adjustable Mounting Rails



Ventilated for Ample Airflow



Reversible Cabinet




Square/Threaded Hole Mounting

- A** Front Door (Lockable/Removable/Reversible. SRW26USDP door is perforated; SRW26USDPG door has a clear acrylic window.)
- B** Adjustable Mounting Rails (4) (Support square and threaded hole mounting options.)
- C** Side Panels (2) (Lockable/Removable)
- D** Cable Access Port Covers (4) (Removable)
- E** Ventilation Fan Ports (4) (Support optional SRFANWM fan kit.)
- F** Hinged Wall Bracket
- G** Keys (2)

Also Includes: Owner's manual, cabinet ground screw, pre-installed front door ground wire and rack-mount equipment mounting hardware (48 cage nuts, 48 M6 mounting screws, 48 #12-24 x 5/8" mounting screws, 48 nylon cup washers).



Floor-Standing Installation: Optional SRCASTER kit adapts cabinet to roll under desks, tables or counters. (Kit includes 4 casters.)

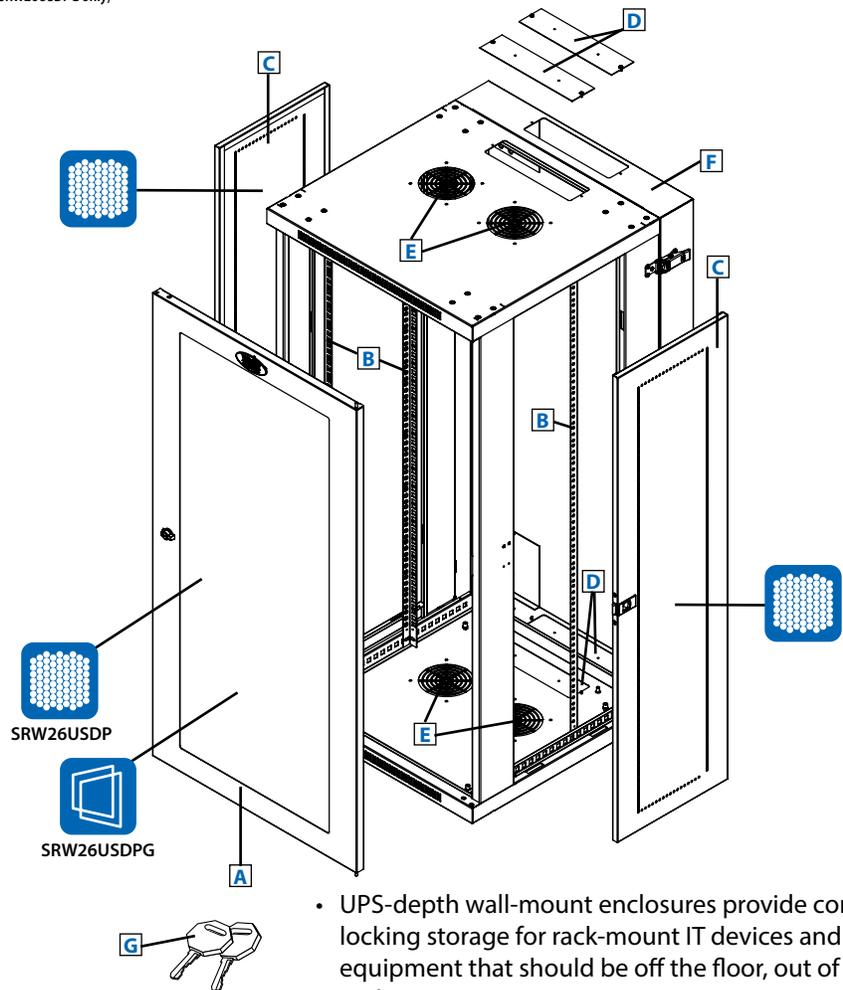

- UPS-depth wall-mount enclosures provide convenient, locking storage for rack-mount IT devices and other equipment that should be off the floor, out of the way and secure
- The cabinet is fully reversible, allowing installers to change door hinges from left to right by simply rotating the unit 180 degrees before mounting
- Hinged wall bracket allows cabinet to swing away from the wall for convenient access to equipment and cabling

**SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS**




1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com

### Specifications


Model	SRW26USDP / SRW26USDPG
Rack Spaces	26U
Equipment Mounting Depth	Up to 24.5 in. / 622 mm
Load Rating*	250 lb. / 113 kg
Unit Dimensions (H x W x D)	49.63 x 23.62 x 25.51 in. / 1260.6 x 600 x 648 mm
Shipping Dimension (H x W x D)	55.12 x 26.77 x 27.56 in. / 1400 x 680 x 700 mm
Unit Weight	124.9 lb. / 57 kg (SRW26USDP) 123.7 lb. / 56 kg (SRW26USDPG)
Standards	Tested to UL/CSA 60950-1, IEC 60297-3-100, RoHS, NOM (Mexico), EIA/ECA-310-E, GOST; PCI Compliant, IP20 Protection Rating

\* The load rating includes the combined weight of the unit and installed equipment. The unit must be mounted to a stable surface with user-supplied anchors capable of bearing the full load.




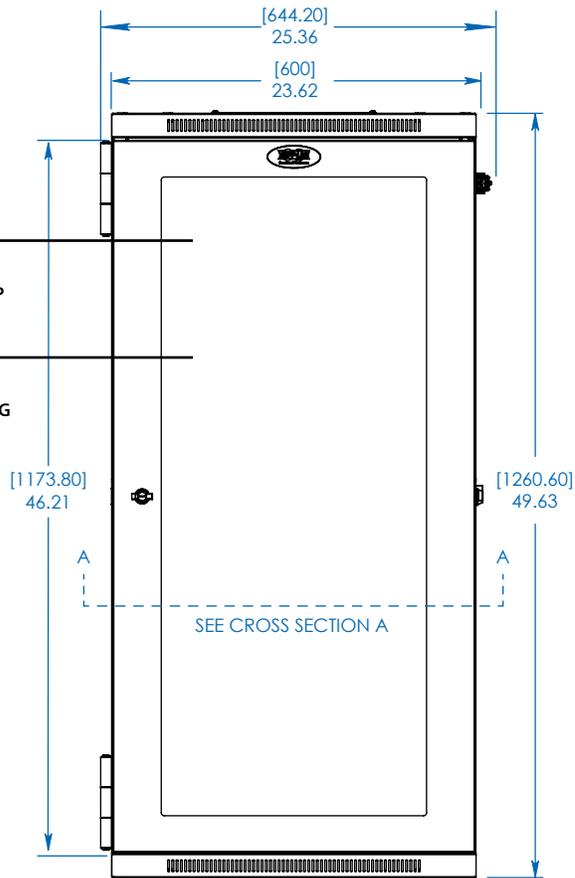


FRONT VIEW

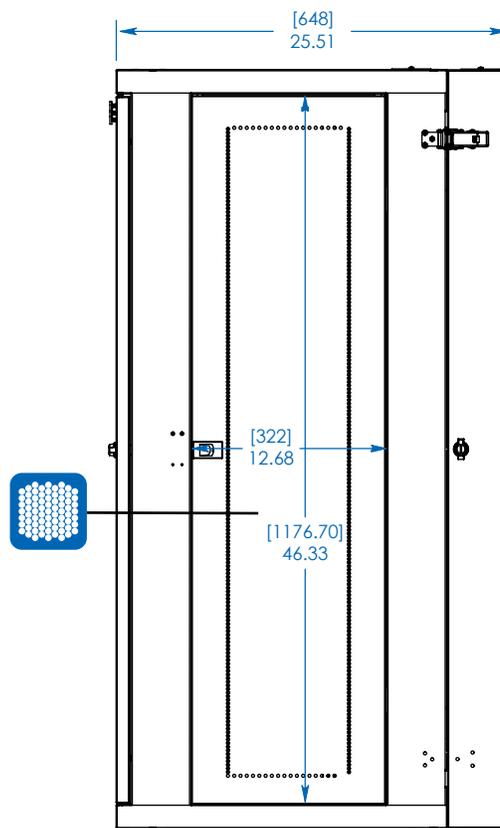

SIDE VIEW

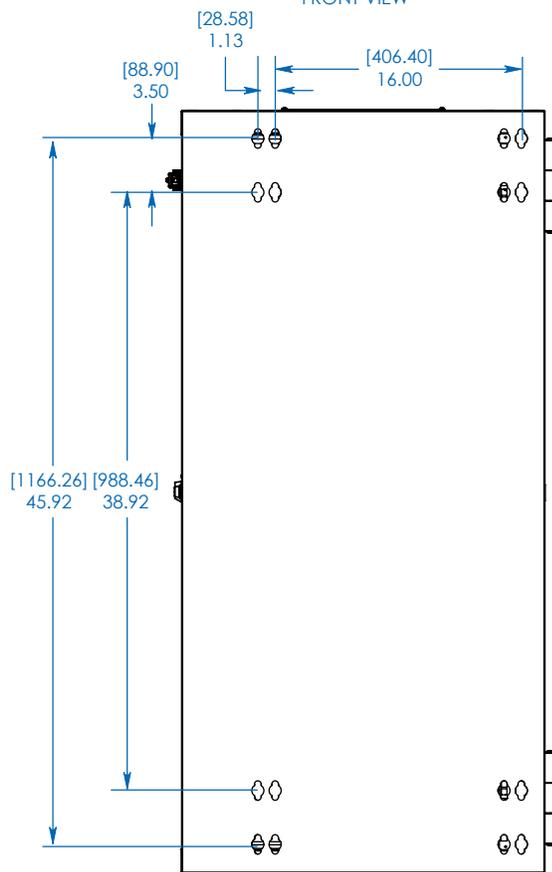

REAR VIEW

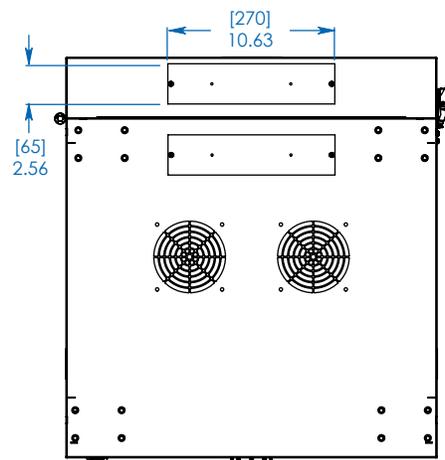



TOP/BOTTOM VIEW

MODELS:  
**SRW26USDP /  
SRW26USDPG**



Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

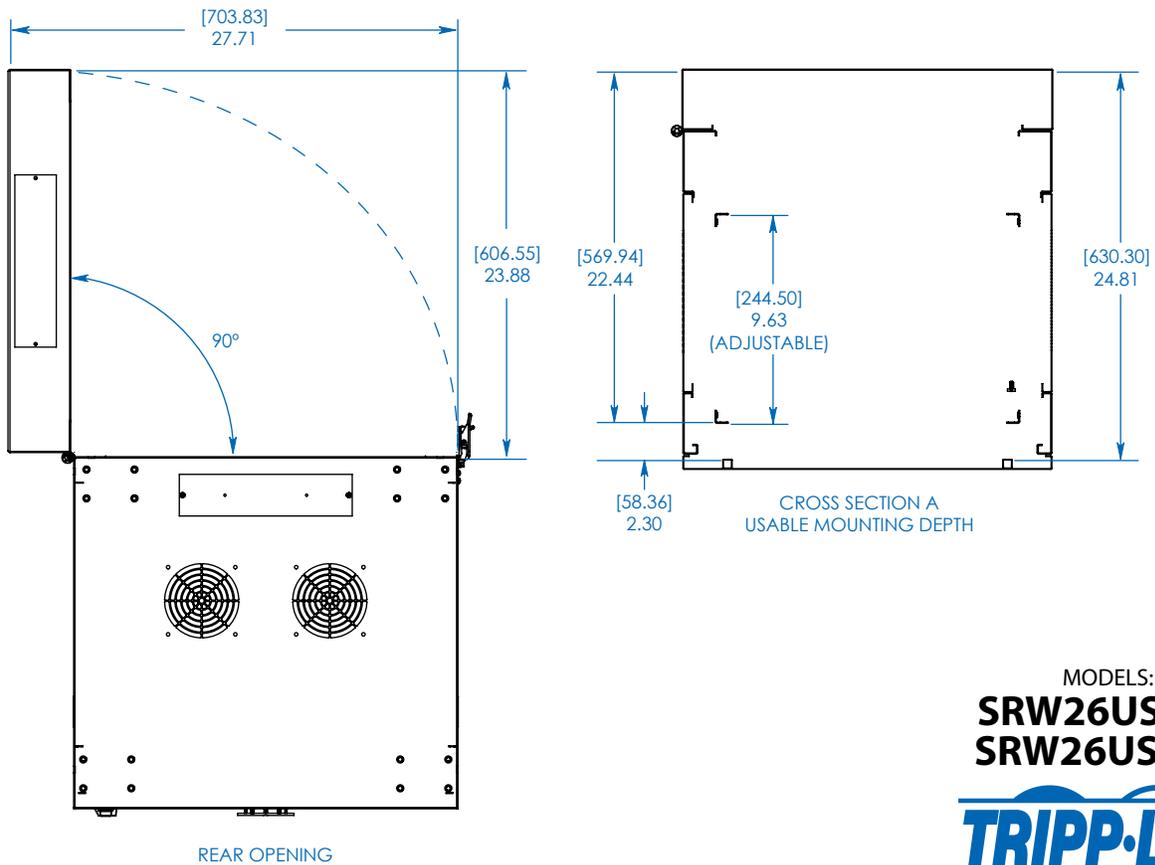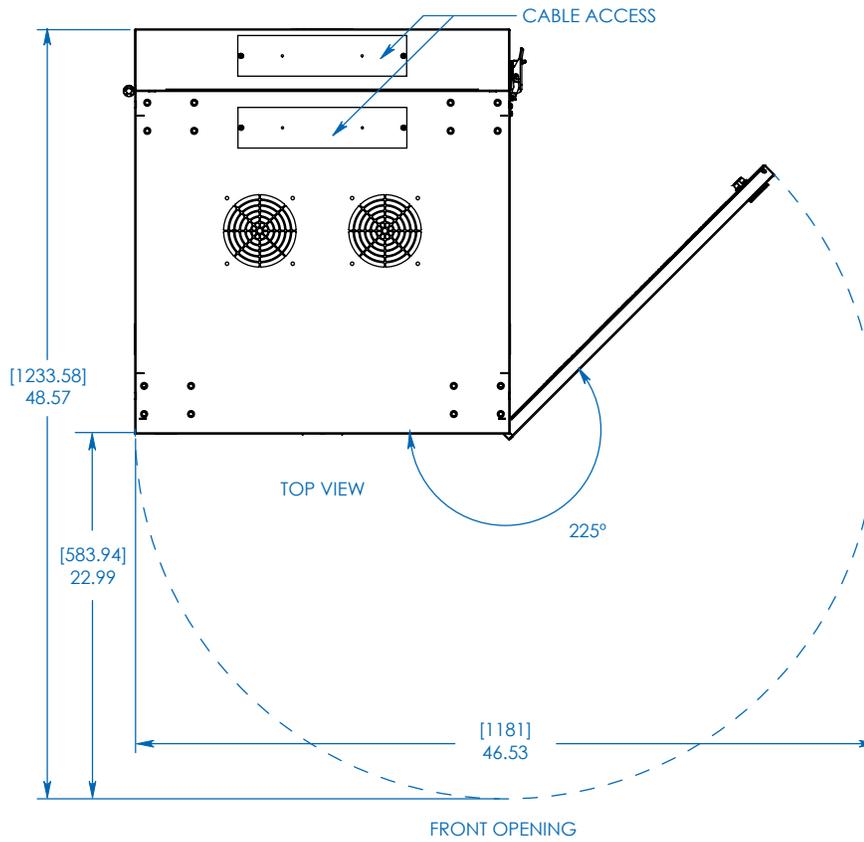

MODELS:  
**SRW26USDP /  
SRW26USDPG**



1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.