


TOLCO Fig. 3000 – CPVC Sway Brace Attachment

The Fig. 3000 is UL Listed as a sway brace to be used with both CPVC and (IPS) steel fire sprinkler pipe.


- Does not compress CPVC pipe
- Designed to allow for offset of brace pipe to reduce harmful residue and oils on CPVC pipe
- Field adjustable, making critical pre-engineering of bracing pipe length unnecessary and requires no threading of bracing pipe
- Comes assembled and ready for installation
- Built-in visual verification of correct installation
- Pipe size to be braced: 1" (25mm) thru 3" (80mm) IPS
- Pipe size used for bracing: 1" (25mm) Schedule 40 IPS
- Used in conjunction with a Fig. 900 Series fitting and joined together with bracing pipe per NFPA 13, forming a complete sway brace assembly

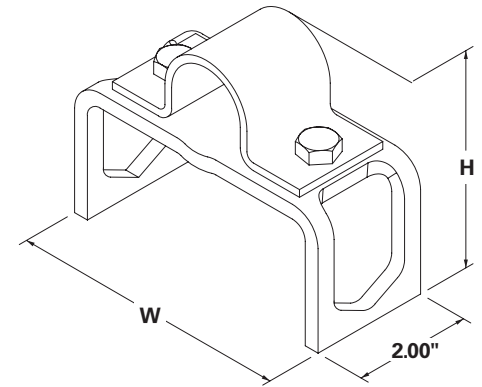

- Underwriters Laboratories Listed in the USA (UL) and Canada (cUL)
 - Electro-Galvanized
- Patent Pending*



Part No.	Pipe Size	Dimensions		Max. Design Loads (UL Listed)
		W Width	H Height	
Fig. 3000-1	1"	4.75"	3.70"	700 lbs
Fig. 3000-1¼	1¼"	5.00"	4.00"	700 lbs
Fig. 3000-1½	1½"	5.25"	4.30"	700 lbs
Fig. 3000-2	2"	6.50"	4.70"	700 lbs
Fig. 3000-2½	2½"	7.00"	5.20"	700 lbs
Fig. 3000-3	3"	7.50"	5.80"	700 lbs

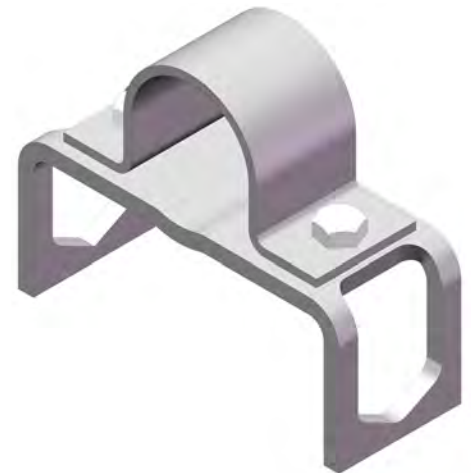

Eaton offers a full line of TOLCO and B-Line series solutions, including hangers, branch line restraints and sway brace attachments.

Contact your local distributor or Eaton customer service for price and availability.