

TOLCO™ Fig. 3000


CPVC or steel sway brace pipe attachment



Installation Instructions: Fig. 3000 is the “braced pipe” attachment component of a lateral brace. It is intended to be used with “bracing pipe” and TOLCO™ transitional and structural attachment component(s) to form a complete bracing assembly. NFPA 13 guidelines should be followed.

For fire sprinkler applications, sway brace assemblies are intended to be installed in accordance with NFPA 13 and the manufacturer’s installation instructions.

| Fig. 3000 NPS | Rated Load |
|----------------------------------|------------|
| 1" - 3" 1" brace member | 1000 lbs. |
| 25mm - 80mm 25mm brace member | 454 kgf |

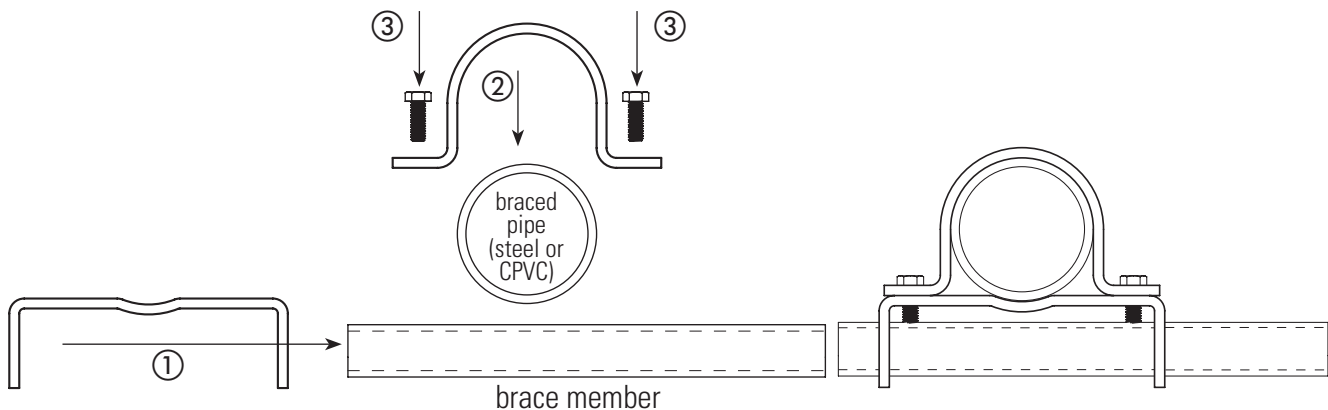

To Install: Slide the Fig. 3000 bracket over the brace member. Place the Fig. 3000 clamp over the pipe being braced, align the holes, and tighten supplied bolts until the underside of the bolt bottoms out against the Fig. 3000 clamp. This sway brace fitting is intended to be used with any TOLCO 900 series transitional attachment and 800 series structural attachment.

Note: Brace member may be over or under the braced pipe.