


Eaton Wiring Devices continuously tests the compatibility between a variety of LED bulbs and our universal dimmers and dimmer sensors to ensure they deliver seamless dimming.

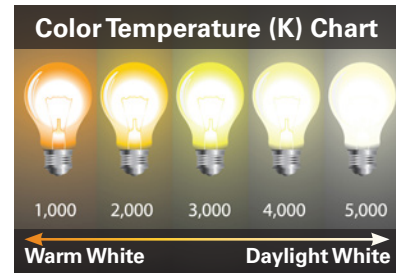

Universal Dimmers - DUL06P, SUL06P, TUL06P | Universal Dimmer Sensors - OSUL06D, VSUL06D

MANUFACTURER	TYPE	MODEL# or PC#	WATTAGE	COLOR (K)	LUMENS
CREE	A19	BA19-045270MF-12DE26-2U_00	6	2700	450
	A19	BA19-045500MB-12DE26-3C	6	5000	460
	A19	BA19-045500MF-12DE26-2U_00	6	5000	450
	A19	BA19-080270MF-12DE26-2U_00	9.5	2700	800
	A19	BA19-110270MF-12DE26-1U_00	13.5	2700	1100
	A21	BA21-160500MF-12DE26-1U_00	18	2700	1600
	BR30	BBR30-06527FLF-12DE26-4U_00	9	2700	655
	BR30	BBR30-06550FLF-12DE26-1U_00	9.5	5000	650
	BR40	BBR40-07627FLF-12DE26-1U_00	9.5	2700	760
	6"RR	DRDL6-06250009-12DE26-1C_00	12.5	5000	625
	6"RR	DRDL6-11027009-12DE26-1C_00	15	2700	1100
	A19	SA19-08127MDFD-12DE26-1	9.5	2700	815
	BR30	SBR30-06550FLFD-12DE26-1	7	5000	670
	6"RR	SRDL6-0652700FH-12DE26-1	10	2700	650
	6"RR	SRDL6-0655000FH-12DE26-1	8.5	5000	650
	6"RR	SRDL6-1102700FH-12DE26-1	16	2700	1100
	A19	TA19-04527MDFH25-12DE26-1-12	5.5	2700	460
	A19	TA19-08027MDFH25-12DE26-1-12	10	2700	815
	DURA	PAR16	3PD9	5	2700
E-COMMERCIAL	6"RR	1001 749 797	10.5	2700	650
	6"RR	145 597	14	3000	861
	4"RR	445 520	9	2700	600
ECOSMART	A19	1000835491	8.5	2700	800
	A19	1001370336	5.7	2700	460
	A19	1001370384	9.5	2700	800
	A19	1001654076	13	5000	900
	BR30	1001654247	9	5000	685
	BR30	1001654525	9	3000	665
	A19	1002459555	7.5	5000	840
	A19	1002459562	7.5	2700	800
	A19	1002459573	8	5000	840
	A19	1002459588	8	2700	840
	6"RR	1002936732	10	5000	650
	EIKO	BR40	08942	17	2700
BR30		09351	11	2700	800

Universal Dimmers - DUL06P, SUL06P,TUL06P | Universal Dimmer Sensors - OSUL06D,VSUL06D

MANUFACTURER	TYPE	MODEL# or PC#	WATTAGE	COLOR (K)	LUMENS
ELCO	4"RR	EL41030W	15	3000	700
FEIT	A19	BPCEAG/500/3	7.5	3000	500
	BR30	BPCEBR30/LED	13	2700	750
	CA	BPCEFC/927/6 (12000264)	3.3	2700	300
	G25	BPCEG25/LED/3	8	3000	500
	PAR38	BPCEPAR38/930/LED	18	3000	950
	BR40	BR40DM/10KLED/2	13	2700	850
	BR30	CEBR30/5K/LED/8	9.5	5000	650
	BR30	CEBR30/927/6 (1200268)	8.3	2700	750
	6"RR	CELEDR6/927/2 (1200274)	9.4	2700	850
	6"RR	CELEDRT56/927/2	21.5	2700	1250
	A21	CEOM100/950/4 (1230351)	17.5	5000	1600
	A19	CEOM60/27/6 (N)	8.8	2700	800
	A19	CEOM60/50/6	8.8	5000	800
	A19	CEOM60/927/LED/6 (1200258)	8.8	2700	800
	4"RR	LEDRA4/5K/CAN	10	5000	500
G7POWER	BR30	G7BR301527D	15	2700	1100
GE	R40	30695	13	2700	1000
	R20	30878	7	2700	450
	A21	33071	15	2700	1600
	A21	33076	15	5000	1600
	A19	33535	6	2200	560
	G40	33548	5.5	2200	400
	A19	33574	5	2000	250
	PAR16	34033	5.5	3000	450
	PAR16	34037	6	3000	330
	A15	36501	3	2000	125
	R30	41382	10	2700	650
	R30	41409	10	5000	650
	R30	41425	10	2700	650
	R30	41427	10	5000	650
	R40	41432	13	2700	900
	R20	41482	7	2700	450
	R20	41496	7	5000	450
	G30	41818	6	2700	500
	G40	41857	6	2700	500
	G25	42256	4.5	2700	350
	G25	42258	5.5	2700	500
	G25	42261	5.5	2700	500
	A15	42402	4.5	2700	290
	A15	42404	4.5	2700	270
	BC	42544	4	2700	240
	G25	42667	4.5	2700	290
	G25	42686	4.5	2700	290
	G25	42698	5.5	2700	400

Universal Dimmers - DUL06P, SUL06P,TUL06P | Universal Dimmer Sensors - OSUL06D,VSUL06D

MANUFACTURER	TYPE	MODEL# or PC#	WATTAGE	COLOR (K)	LUMENS
GE	A19	44780	10	2700	800
	A19	44781	10	2700	800
	A19	44784	4.5	2700	450
	A19	44787	5	2700	450
	A19	44789	5	2700	450
	A19	44792	5	5000	450
	A19	44794	5	5000	450
	A19	44858	5.5	2700	450
	A19	44898	5.5	2700	450
	A19	44899	5.5	5000	450
	A19	44900	5.5	5000	450
	A19	44904	5	2850	350
	A19	44906	5	2850	350
	A19	44909	7	2700	800
	A19	44920	8	2700	800
	A19	44921	8	5000	800
	A19	44923	8	5000	800
	A19	44929	8.5	2700	800
	A19	44930	8.5	2700	800
	A19	44931	8.5	5000	800
	A19	44943	8	2850	610
	A21	44955	10.5	2850	850
	A21	44958	12.5	2850	1140
	PAR20	44972	7	3000	500
	PAR20	44977	7	5000	500
	PAR20	44987	7	3000	500
	R16	44998	6	2700	400
	6"RR	44999	10	2700	700
	PAR20	45023	7	2700	400
	PAR30	45025	10	3000	850
	PAR30	45028	10	5000	850
	PAR30	45035	12	2700	700
	PAR30	45069	11	3000	850
	PAR30	45096	10	5000	850
	PAR30	45106	12	2700	700
	PAR38	45137	13	3000	1200
	PAR38	45139	13	3000	1200
	PAR38	45140	15	3000	1200
	PAR38	45143	13	5000	1200
	BR30	45170	9	2700	700
	PAR20	45890	12	3000	1100
	PAR30	45891	24	3000	2200
	PAR38	45892	16	3000	1400
	PAR38	45893	17	3000	1500
	BR30	46301	8.5	2700	650
	A21	46323	13	5000	1100

Universal Dimmers - DUL06P, SUL06P,TUL06P | Universal Dimmer Sensors - OSUL06D,VSUL06D

MANUFACTURER	TYPE	MODEL# or PC#	WATTAGE	COLOR (K)	LUMENS
GE	A21	46326	17	5000	1600
GLOBE	3"RR	91098	6	3000	300
	3"RR	91099	6	3000	420
	4"RR	91100	9	3000	600
	4"RR	91101	9	3000	600
	4"RR	91102	9	3000	600
	4"RR	91104	9	3000	600
	4"RR	91105	9	3000	600
	6"RR	91106	12	3000	950
	6"RR	91107	12	3000	950
	4"RR	91108	9	3000	540
	4"RR	91109	9	3000	540
	4"RR	91112	9	3000	600
	4"RR	91116	9	3000	600
	4"RR	91130	9	3000	600
	4"RR	91145	9	3000	600
	3"RR	91188	6	3000	420
	3"RR	91189	6	3000	420
	4"RR	91190	9	3000	600
	4"RR	91191	9	3000	600
	4"RR	91192	9	3000	600
Great Value	A19	LED6.5A19DIM0827	6.5	2700	800
Halco	BR30	80977	9.5	3000	750
HALO	4"RR	LT460WH6930	8	3000	560
	4"RR	LT460WH6935	7.8	3500	560
	5"/6"RR	LT560WH6930	10	3000	600
	5"/6"RR	LT560WH6935	10	3500	600
	4"RD	ML4D09FL930E	12.5	3000	900
	5/6"RD	ML5606930	10.2	3000	600
	5/6"RD	ML5609930	13.4	3000	900
	5/6"RD	ML5612935	17.5	3500	1200
	4"RR	RL4069S1EWH	7.6	3000	575
	4"RR	RL460WH930PK	8.6	3000	600
	5/6"RR	RL56069S1EWH	7.6	3000	665
	5"/6"RR	RL56099S1EWH	12.1	3000	940
	5/6"RR	RL560WH12930	17.6	3000	1240
	5/6"RR	RL560WH6930	8.8	3000	645
	6"RR	RL560WH9927	12.6	2700	940
	5/6"RR	RL560WH9930	12.8	3000	930
	4"RS	SLD405835WH	12.2	3500	500
	5/6"RS	SLD606840WH	12.2	4000	600
	5/6"RS	SLD612840WH	14.8	4000	1200
	4"RS	SMD4R6940WH	9.8	4000	760
	5/6"RS	SMD6R12935WH	15.5	3500	1264
	5/6"RS	SMD6R6935WH	9.61	3500	740

Universal Dimmers - DUL06P, SUL06P,TUL06P | Universal Dimmer Sensors - OSUL06D,VSUL06D

MANUFACTURER	TYPE	MODEL# or PC#	WATTAGE	COLOR (K)	LUMENS
LE	MR16	200055-WW-US	6.5	3000	360
	MR16	SKU200039	4	3000	210
LITHONIA	4"RR	236VG2	9.6	3000	675
LUMINUS	A19	PLF104Y	4.5		375
	A19	PLF1142	4.5	2700	450
	A19	PLF1222	7.5	2700	800
	G25	PLF1522	4.5	2700	450
	A19	PLFV1142	4.5	2200	380
	G40	PLFV1552	4.5	2200	380
	ST19	PLFV9022	5	2200	320
	T10	PLFV9032	5	2200	380
	A19	PLYC1132	7.5	7800	480
	A19	PLYC1162	5.5	2700	450
	A19	PLYC1255	9.5	5000	800
	A21	PLYC1412	16	2700	1600
	G25	PLYC1512	6	2700	450
	G25	PLYC1532	6	2700	400
	G25	PLYC1552	6	2700	450
	G25	PLYC1562	6	2700	400
	G16	PLYC1622	5	2700	350
	G16	PLYC1632	5	2700	300
	G16	PLYC1642	5	2700	350
	G16	PLYC1652	5	2700	350
	A19	PLYC1712	11	2700	1100
	PAR16	PLYC2133	5	3000	350
	PAR16	PLYC2333	6.5		500
	PAR16	PLYC2843	5	3000	350
	PAR16	PLYC2933	6.5	3000	500
	PAR20	PLYC3213	7	3000	550
	PAR20	PLYC3223	7	3000	550
	PAR20	PLYC3225	7	5000	550
	R20	PLYC3722	7	2700	575
	R20	PLYC3725	7	5000	575
	PAR30	PLYC4113	12	3000	800
	PAR30	PLYC4133	12	3000	950
	PAR30	PLYC4145	12	5000	1000
	PAR30	PLYC4163	11	3000	850
	PAR30	PLYC4343	11	3000	800
	PAR38	PLYC4543	15	3000	1250
	BR30	PLYC5232	11	2700	850
	BR30	PLYC5235	11	5000	950
	BR30	PLYC5294	8	2700	650
	BR40	PLYC5732	17	2700	1450
BR40	PLYC5735	17	5000	1550	
B11	PLYC6112	4.7	2700	315	

Universal Dimmers - DUL06P, SUL06P, TUL06P | Universal Dimmer Sensors - OSUL06D, VSUL06D

MANUFACTURER	TYPE	MODEL# or PC#	WATTAGE	COLOR (K)	LUMENS
LUMINUS	B13	PLYC6532M	6.5	2700	500
	4"RR	PPD43S	7	3000	500
	6"RR	PPD613	15	3000	1100
	6"RS	PPD63	11.5	3000	740
	4"RR	PPR593	13	3000	850
	6"RR	PPR693	19	3000	1320
Maxim Lighting	7.5"RR	57627WTWT	15	3000	1000
NOMA	A19	299-6009-6	8.5	3000	810
PHILIPS	BR20	9290002192	8	2700	530
	A21	9290002596	19	2700	1680
	A19	9290002709	10.5	5000	800
	A19	9290012894	5.5	2700	450
	PAR16	9290002242 (6PAR16/END/F25 3000 DIM)	6	3000	300
	PAR38	9290002253 (19PAR38/END/F25 3000-1200 DIM SM)	19.5	3000	1200
	A19	9290002267 (8A19/END/2700 DIM)	8	2700	470
	A19	9290002268A	11	2700	880
	A19	9290002268A (BC11A19/AMB/2700 DIM 120V)	11	2700	880
	A19	9290002296A	12	5000	830
	B11	9290002417 (BC3.5B11/AMB/2700 DIM 120V)	3.5	2700	180
	F15	9290002439 (BC4.5F15/AMB/2700 DIM 120V)	4.5	2700	320
	B13	9290002797 (4.5B13/AMB/2700-E26 DIM 120V)	4.5	2700	330
	A15	9290002891 (BC4.5A15/AMB/2700-E12 120V)	4.5	2700	330
	B12	9290011668 (2.7B12/LED/827-22/E12/DIM 120V)	2.7	2700	180
	B12	9290011670A (BC4.5B12/AMB/827-22/E12/DIM 120V)	4.5	2700	330
A19	9290011840B	9.5	2700	800	
PROGRESS	5"RR	P801-28/30K9-AC1-L06	12	3000	600
RAZOR	4"RR	RZR-400-9W-3K	9	600	
SATCO	BR40	S9635	11.5	3000	970
SEAGULL	6"RR	14330S-15	15	3000	1000
	6"RS	14701S-15	14	3000	1000
STAK		PKLGU3B4	6	3000	470
SYLVANIA	6"RR	LED/RT5/6/700/940	10	4000	700
	PAR30	LED13PAR30LN/DIM/830/FL40	13	3000	820
	BR30	LED7.5BR30DIM82710YVGL	7.5	2700	650
TCP	BR30	4R3016TD	16	2700	625
	A22	A19037	15		
	A20	A19050	9		
	A19	A19051	6		
	A21	A19052	11		
	A19	L9A19D1527KUT	9.5	2700	800
	BR30	LED9BR30D27K	9.5	2700	700
TRIANGLE BULBS	MR16	55961	6	3200	550
UBERHAUS	A19	15735016	9.5	2700	800