


Big job? Make it EZ!

Save time and money with
EZ Link modular devices!

Arrow Hart

Revolutionary Design

The EZ Link's thoughtful design allows for efficient, accurate and dependable installation.

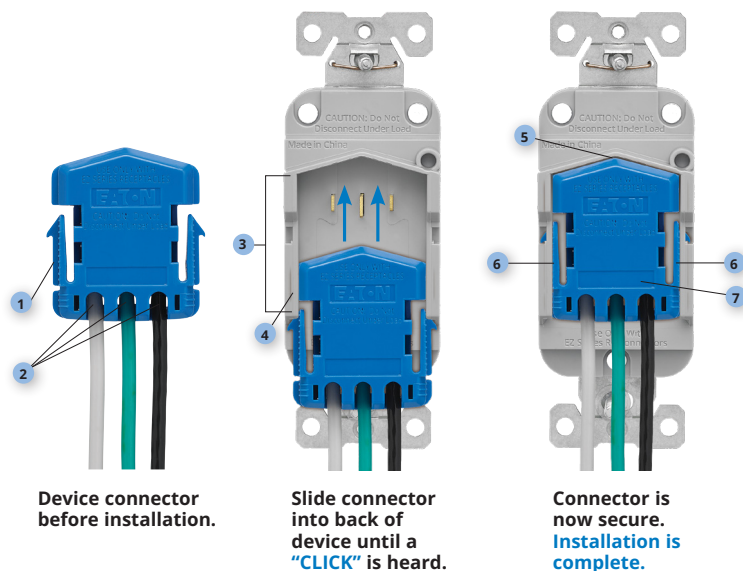

Features & Benefits

- 1 Wire Relief Slots**
Allow sharp bending to make it easier to push all the wires back into the box during final installation.
- 2 Gripping Ridges**
Tactile design incorporated into the connector provides a secure grip for the installers.
- 3 Sliding Installation**
Unique sliding design allows the connector to simply slide into place faster and easier.
- 4 Guide Rails**
Provide accurate and secure alignment during installation.
- 5 Arrow Design**
The design easily identifies the direction to slide in the connector, providing safety against incorrect installation.
- 6 Release Wings**
Wings provide an easy, one-hand release of the device, while providing two points of capture for connection retention.
- 7 Easy Labeling**
A dedicated labeling area adds convenience for special labeling needs.

The EZ Link Advantage

Arrow Hart EZ Link™ modular devices are the most efficient way to wire receptacles and switches for large commercial projects.



Duplex & TR receptacles

Controlled receptacles



Split circuit receptacles

AVAILABLE IN THESE COLORS


*For ordering devices, include Cat. no. followed by the color suffix, for example: TR5262__

B	BK	GN	GY	LA	RD	V	W
Brown	Black	Green	Gray	Light Almond	Red	Ivory	White

Receptacles

DESCRIPTION

2-pole, 3-wire grounding
15A, 125V/AC
20A, 125V/AC

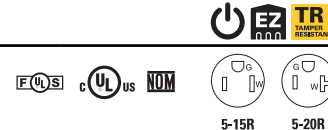

DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Duplex		☐ EZ5262__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZ5362__	B, BK, GY, LA, RD, V, W
15	125	5-15R	Decorator duplex		☐ EZ6262__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZ6362__	B, BK, GY, LA, RD, V, W

TAMPER RESISTANT DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Tamper resistant duplex		☐ EZTR5262__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR5362__	B, BK, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant decorator duplex		☐ EZTR6262__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR6362__	B, BK, GY, LA, RD, V, W

HALF CONTROLLED DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Duplex		☐ EZ5262CH__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZ5362CH__	B, BK, GN, GY, LA, RD, V, W
15	125	5-15R	Decorator duplex		☐ EZ6262CH__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZ6362CH__	B, BK, GN, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant duplex		☐ EZTR5262CH__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR5362CH__	B, BK, GN, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant decorator duplex		☐ EZTR6262CH__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR6362CH__	B, BK, GN, GY, LA, RD, V, W

DUAL CONTROLLED DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Duplex		☐ EZ5262CD__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZ5362CD__	B, BK, GN, GY, LA, RD, V, W
15	125	5-15R	Decorator duplex		☐ EZ6262CD__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZ6362CD__	B, BK, GN, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant duplex		☐ EZTR5262CD__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR5362CD__	B, BK, GN, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant decorator duplex		☐ EZTR6262CD__	B, BK, GN, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR6362CD__	B, BK, GN, GY, LA, RD, V, W

SPLIT CIRCUIT DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Duplex		☐ EZ5262SC__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZ5362SC__	B, BK, GY, LA, RD, V, W
15	125	5-15R	Decorator duplex		☐ EZ6262SC__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZ6362SC__	B, BK, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant duplex		☐ EZTR5262SC__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR5362SC__	B, BK, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant decorator duplex		☐ EZTR6262SC__	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR6362SC__	B, BK, GY, LA, RD, V, W

Compliances, specifications and availability are subject to change without notice.



Hospital Grade receptacles



GFCI receptacles



Toggle switches



Decorator switches

AVAILABLE IN THESE COLORS

*For ordering devices, include Cat. no. followed by the color suffix, for example: TR5262_

B	BK	GY	LA	RD	V	W
Brown	Black	Gray	Light Almond	Red	Ivory	White

Receptacles

DESCRIPTION

2-pole, 3-wire grounding
15A, 125V/AC
20A, 125V/AC



5-15R

5-20R

HOSPITAL GRADE DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Duplex		☐ EZ8200_	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZ8300_	B, BK, GY, LA, RD, V, W
15	125	5-15R	Decorator duplex		☐ EZ8262_	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZ8362_	B, BK, GY, LA, RD, V, W

TAMPER RESISTANT HOSPITAL GRADE DUPLEX RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Tamper resistant duplex		☐ EZTR8200_	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR8300_	B, BK, GY, LA, RD, V, W
15	125	5-15R	Tamper resistant decorator duplex		☐ EZTR8262_	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTR8362_	B, BK, GY, LA, RD, V, W

SLIM GFCI RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Slim GFCI		☐ EZGF15_	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZGF20_*	B, BK, GY, LA, RD, V, W

SLIM TAMPER RESISTANT GFCI RECEPTACLES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	NEMA	Description	Catalog no.	Color suffix
15	125	5-15R	Slim tamper resistant GFCI		☐ EZTRGF15_	B, BK, GY, LA, RD, V, W
20	125	5-20R			☐ EZTRGF20_*	B, BK, GY, LA, RD, V, W

*FedSpec certification on 20A only

Switches

DESCRIPTION

Single pole, 3-way
15A & 20A, 120/277V/AC



TOGGLE SWITCHES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	Description	Catalog no.	Color suffix
15	120/277	Single pole toggle		☐ EZ1201_	B, BK, GY, LA, RD, V, W
20	120/277			☐ EZ1221_	B, BK, GY, LA, RD, V, W
15	120/277	3-way toggle		☐ EZ1203_	B, BK, GY, LA, RD, V, W
20	120/277			☐ EZ1223_	B, BK, GY, LA, RD, V, W


DECORATOR SWITCHES, SEPARABLE TERMINAL TYPE

Rating	A	V/AC	Description	Catalog no.	Color suffix
15	120/277	Single pole decorator		☐ EZ7601_	B, BK, GY, LA, RD, V, W
20	120/277			☐ EZ7621_	B, BK, GY, LA, RD, V, W
15	120/277	3-way decorator		☐ EZ7603_	B, BK, GY, LA, RD, V, W
20	120/277			☐ EZ7623_	B, BK, GY, LA, RD, V, W

Compliances, specifications and availability are subject to change without notice.



Powering Business Worldwide

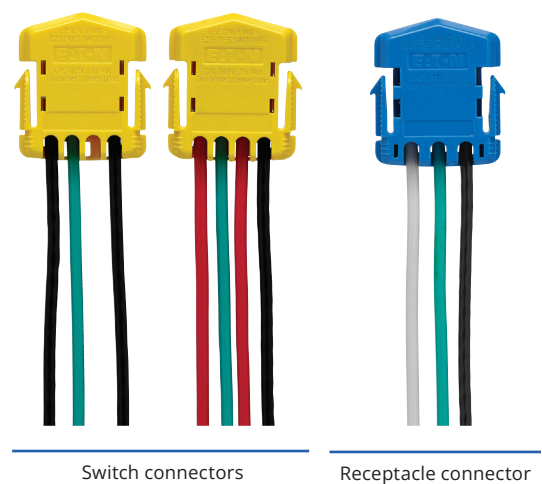

Connectors

DESCRIPTION	
2-pole, 3-wire receptacle connector 20A, 125V/AC	   
Single pole, 3-wire switch connector 3-way, 4-wire switch connector 20A, 120/277VAC	

RECEPTACLE & SWITCH CONNECTORS			
Description	Wire Type	Catalog no.	Color
Receptacle connector	Stranded	☐ EZRCSTR	Blue
Receptacle connector	Solid	☐ EZRC SOL	Blue
Switch single pole connector	Stranded	☐ EZSPSWSTR	Yellow
Switch single pole connector	Solid	☐ EZSPSW SOL	Yellow
Switch 3-way connector	Stranded	☐ EZ3WSWSTR	Yellow
Switch 3-way connector	Solid	☐ EZ3WSW SOL	Yellow

Compliances, specifications and availability are subject to change without notice.



Scan QR code
to access our
EZ Link video.



Scan QR code
to access
additional
EZ Link
resources.

Electrical Sector
1123 Hwy 74 S
Peachtree City, GA 30269
United States
Eaton.com
Eaton.com/EZLink

Electrical Sector
Canada Operations
5925 McLaughlin Road
Mississauga, Ontario, L5R 1B8
Canada
EatonCanada.ca
Eaton.com/EZLink

Electrical Sector
Mexico Operations
Carr. Tlalnepantla -
Cuautitlán Km 17.8 s/n
Col. Villa Jardín esq.
Cerrada 8 de Mayo
Cuautitlán, Mexico CP 54800
México
Eaton.mx
Eaton.com/EZLink