



SL7-CB-D-M12A4


UL:  For use in industrial machinery applications as defined in the Electrical Standard for Industrial Machinery, NFPA 79
 Nur für industrielle Anwendungen, entsprechend NFPA79

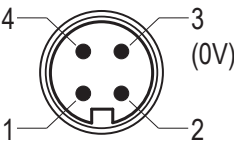

IP66
UL type 1
-30°C .. +45°C
(-22°F .. +113°F)

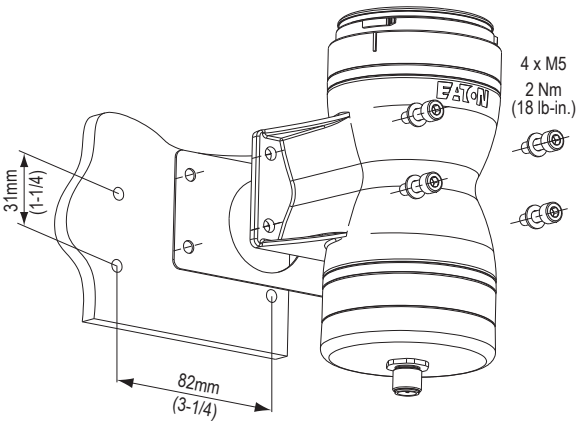

CSDS - 4A4CY22xx, CSDR - 4A4CY22xx (EATON)
SAC-4P-x,x-800/M12FR, SAC-4P-x,x-800/M12FS (Phoenix Contact)

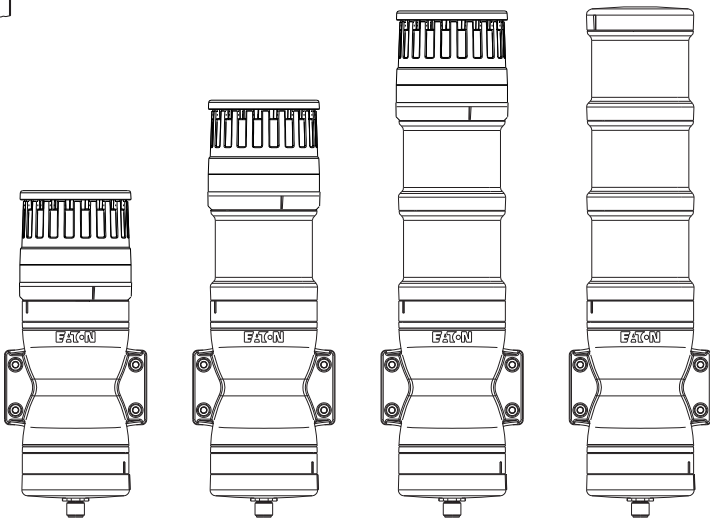

SL7-AP24-E-EV


 


2700Hz
1200 - 500 Hz

1+2
1

2+4
2

4

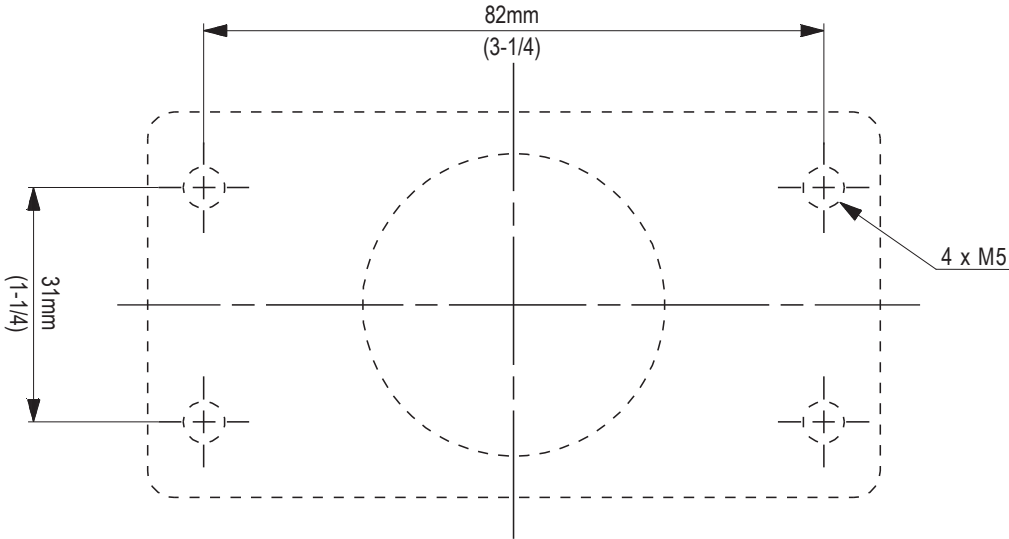

10/21 IL047011ZU

