


12/17 IL014048ZU

Wall fixing W.../... Wandbefestigung W.../... Fixation murale W.../...

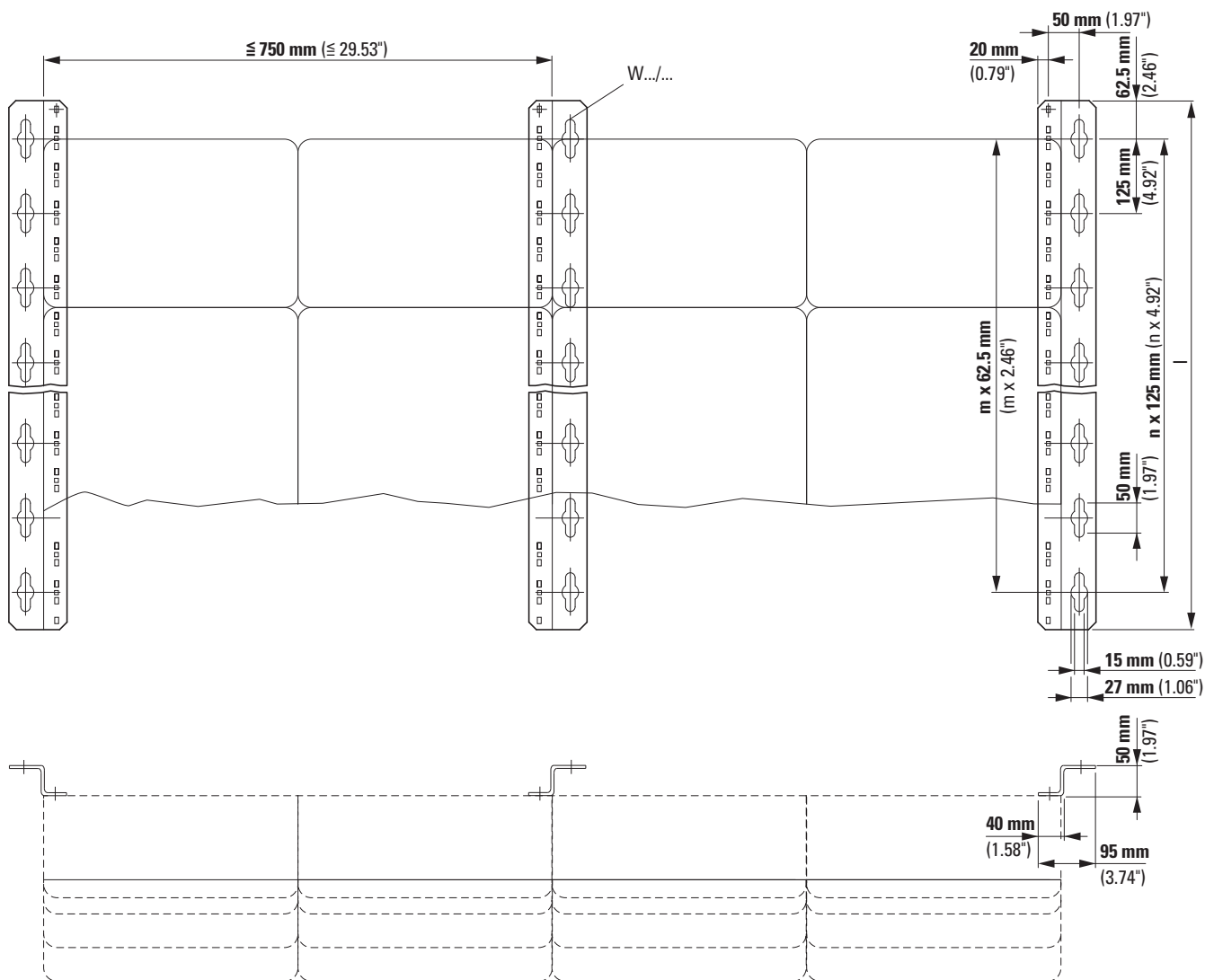

Type Typ Référence	l mm (")	n	m
W4/8...	625 (24.61)	4	8
W6/12...	875 (34.49)	6	12
W8/16...	1125 (44.29)	8	16
W10/20...	1375 (54.13)	10	20
W16/32...	2125 (83.66)	16	32