


Specifikationer

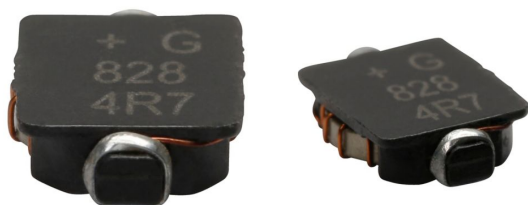

Billedet er repræsentativt



Eaton MP2A-6R8-R

Eaton MP2A inductor, 6.9 μ H, 1.49 A Irms, 1.53 A ISAT, 159 m Ω resistance, SMT mounting, MPP, 2-pins, 3900 qty.

Generelle specifikationer

PRODUCT NAME	Eaton MP2A inductor
CATALOG NUMBER	MP2A-6R8-R
UPC	051712821728
PRODUCT LENGTH/DEPTH	0.295 in
PRODUCT HEIGHT	0.071 in
PRODUCT WIDTH	0.205 in
PRODUCT WEIGHT	0.0002 lb
COMPLIANCES	RoHS Compliant



Powering Business Worldwide

Produktspecifikationer

TYPE	Inductor
MOUNTING	SMT
IRMS	1.49 A
ISAT	1.53 A
PACKAGE QUANTITY	3900
MATERIAL	MPP
FREQUENCY RATING	Up to 500 kHz
CONTACT CONFIGURATION	Two-pin
TEMPERATURE RATING	-40 to 125 °C
RESISTANCE	159 mΩ
SERIES	MP2A

Ressourcer

PROJEKTNAMN:

PROJEKTNUMMER:

KLARGJORT AF:

DATO:



Eaton Corporation plc Eaton House
30 Pembroke Road
Dublin 4, Irland
Eaton.com

© 2026 Eaton. Alle rettigheder forbeholdt.

Følg os på de sociale medier for at få de seneste produkt- og supportnyheder.

