

Directional Valves




Service Parts Information

Spring Offset Solenoid Controlled Directional Valves

XDG4S2-012A-(**AC**-)-50

XDG4S2-01*A-(**AC**-)-50

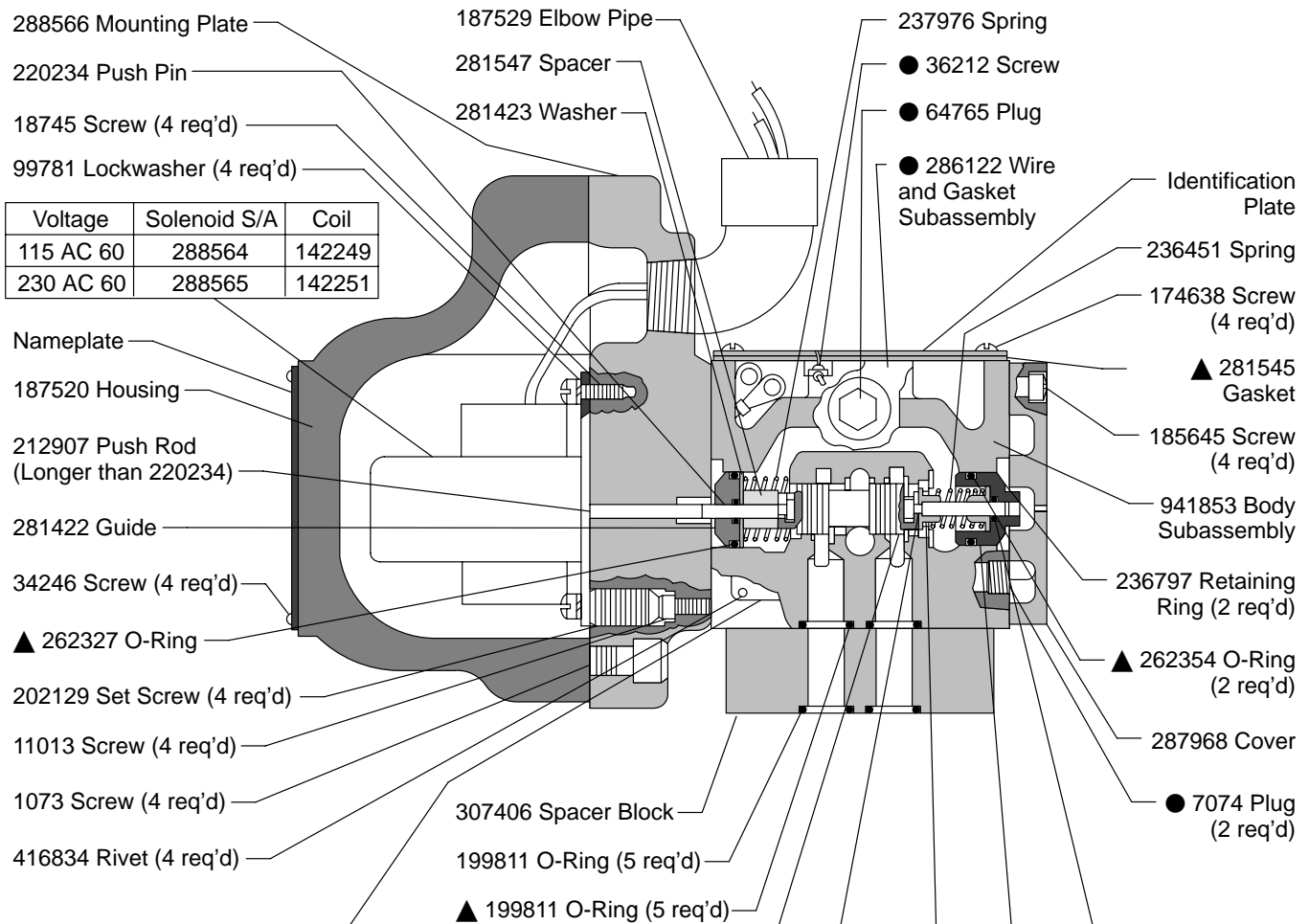

Voltage	Solenoid S/A	Coil
115 AC 60	288564	142249
230 AC 60	288565	142251

Model	Diagram Plate
XDG4S2-012A-*-50	290347
XDG4S2-012A-*-50LH	577488
XDG4S4-01*A-*-50	290348
XDG4S4-01*A-*-50LH	577490

Model	Spool	Push Pin	Limiter 2 (req'd)	Guide	O-Ring
XDG4S2-012A-*-50	220344	—	—	281424	—
XDG4S4-010A-*-50	213230	—	—	—	—
XDG4S4-012A-*-50	213231	220234	294226	284931	▲262327
XDG4S4-016A-*-50	213232	—	—	—	—


R.H assembly shown. In L.H. assembly all parts of valve except body are reversed. Ex. of L.H. model XDG4S4-012A-50-L.H.

Bolt Kit BKDG01-634
● Included in 941853 Body Subassembly

▲ Included in F3 Seal Kit 919214



Model Code

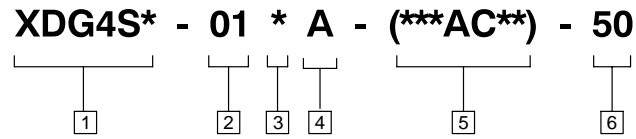

1 Model Series

XDG4S - For use in hazardous areas, Directional valve, Gasket mounted, solenoid operated sliding spool, 4 way

4 Spring Offset

5 Solenoid Voltage and Frequency

Omitted - 115VAC60 standard

6 Design

2 Series

3 Spool type

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 20/18/15 or cleaner. Selections from Eaton OFP, OFR and OFRS filter series are recommended.

Printed in U.S.A.